





# Product Guide

Spring 2020

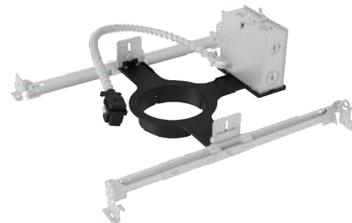

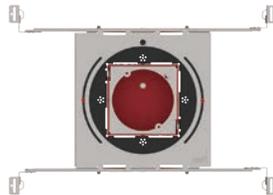

## Downlighting perfected.

Rich, layered light that adds sophistication to any space. A modular system that puts you in control. Ingenious design that's built to last.

This is DMF Lighting.





**Housing** DCD Frame  
**Module** DCD3 Higher-Lumen LED Module  
**Trim** Pinhole

## CONTENTS

### Product Overview

Downlighting Systems .....	4
LED Modules .....	8
Housings .....	14
Trims .....	18
Cylinders .....	20

### Configuration Guide

DRD2 General Downlight .....	24
DRD2X Apex Series Downlight .....	30
DRD3 Adjustable Downlight .....	36
DRD4 Adjustable Downlight .....	38
LD2 2" Recessed Downlight .....	42
DRD5S Surface Mount Downlights .....	44
DCD3 Higher-Lumen Downlight .....	48
DCD4 Adjustable Higher-Lumen Downlight .....	50
DCC Cylinder .....	52
Module Comparison .....	56


# Downlighting Systems



## OneFrame System

Recessed LED Downlighting

The OneFrame® System represents the culmination of decades of engineering experience. We've made every element of this system to work seamlessly with the others, making it truly modular. What's more, it allows you to adapt to changing needs without renovations, putting you in complete control of your light.

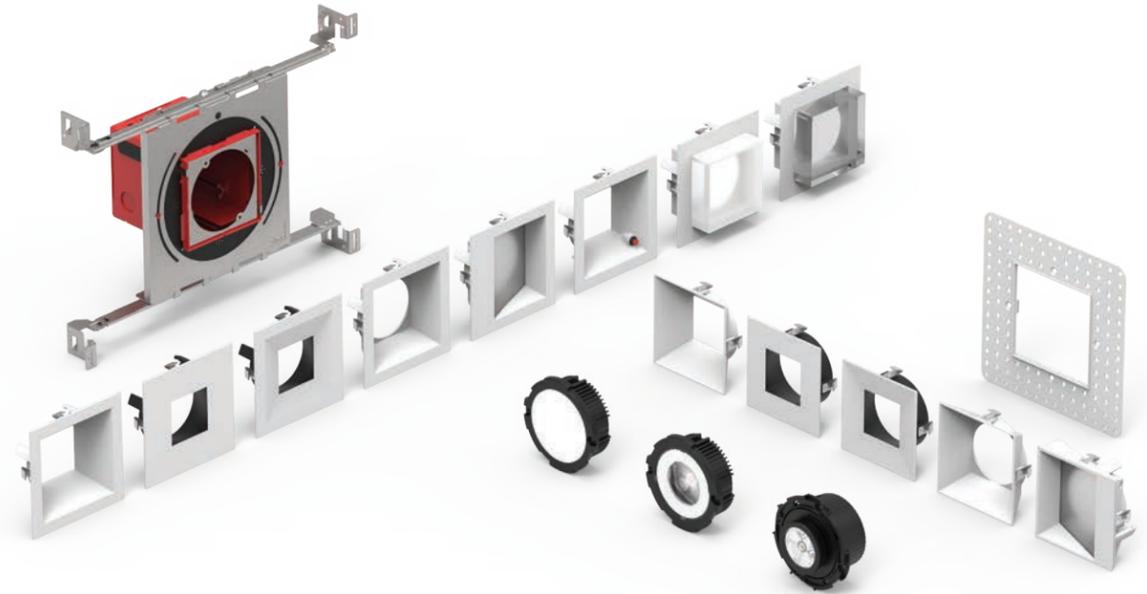

## SquareFrame System

Recessed LED Downlighting

The SquareFrame™ is a breakthrough addition to the DMF downlighting family. It takes the OneFrame's exceptional flexibility, simplicity, and performance and reimagines it in a square format that delivers perfect alignment.


# Downlighting Systems



## DCD Series

Higher-Lumen LED Downlighting System

The DCD Series is a higher-lumen, interoperable downlighting solution that radically simplifies configuration in the field. With just one housing type, you can change beam angles, increase light output, service the driver, and even switch to an adjustable. All without tools.

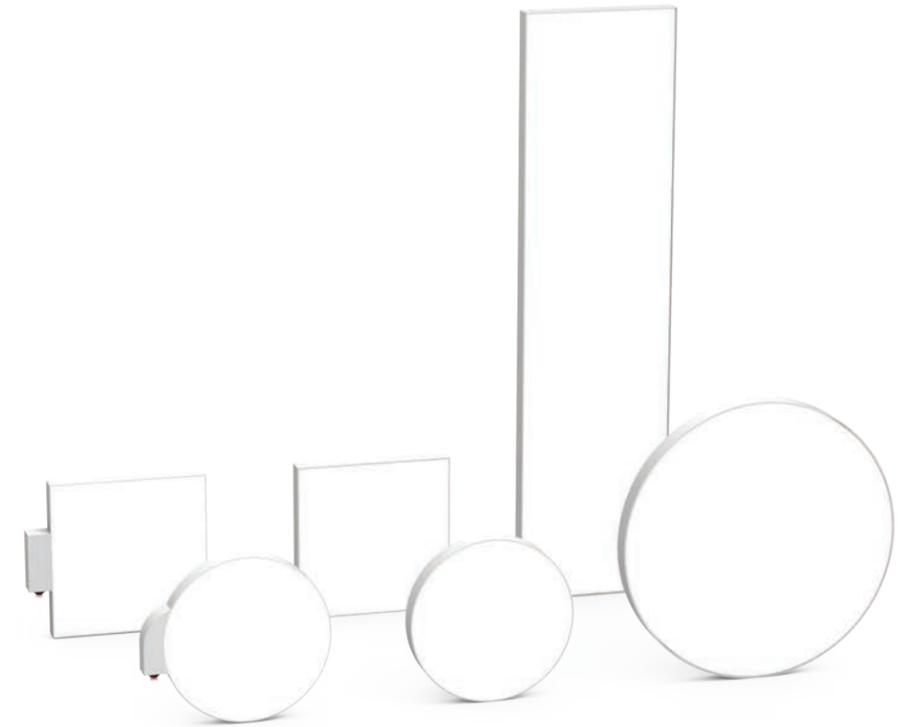

## DRD5S

Surface Mount LED Downlighting

The DRD5S redefines what's possible for a surface mount downlight. Packed with technical breakthroughs, the ultra-thin DRD5S matches the elegance of a high-end recessed downlight. In addition, it's more versatile because it can fit more applications, even those with limited plenum space.

# LED Modules



## DRD2

General LED Downlight

The DRD2 is a compact LED module with an integrated driver that delivers the optimal balance of form and function. It provides outstanding illumination and color consistency while being simple to specify, install, and maintain. The DRD2 truly exemplifies the standard for light quality and value.

# Adjustables



## DRD3

Adjustable LED Downlight

The adjustable DRD3 makes precision directional aim easy and tool-free. Its 40° of tilt and 360° of rotation are perfect for specialized accent designs. The DRD3 provides seamless compatibility with the DMF Classic and industry standard frames.

## DRD2X

Apex Series LED Downlight

An evolution of the DRD2, the DRD2X delivers a precision-targeted beam of high-performance, low-glare illumination precisely where you need it. Merging advanced reflective optics with robust LED technologies and an integrated driver, the DRD2X delivers strong center beam candlepower through 20°, 30°, or 40° beam options. It's a compact light that produces high-end, architectural-grade illumination without sacrificing simplicity.



## DRD4

Adjustable LED Downlight

The adjustable DRD4 brings ultimate flexibility to the OneFrame System. With an integrated driver, 20°, 30°, and 40° beam options, and field changeable accessories, the DRD4 delivers tool-free aimed and lockable light beams for today's lighting designs. Complementary beveled and pinhole trims enhance aesthetics and quiet ceiling designs.




# Surface Mount

## DRD5S

### Surface Mount LED Downlight

The DRD5S's minimal design is available in multiple form factors, with the 4" Round and Square matching the appearance of high-end recessed lights. These models also include optional Integrated EM Test Switch and Non-Conductive Dead Front variants.

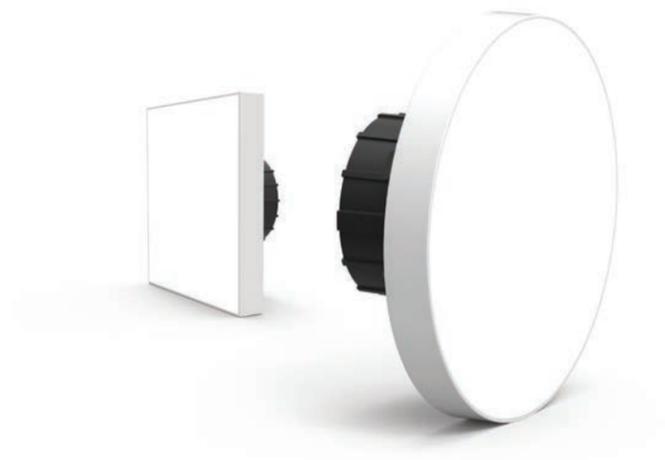

## DRD5S

### 18" Linear Surface Mount

A fresh take on the DRD5S, this linear area light delivers 1500 lumens of 90+ CRI light in a unique form factor. Like our other downlights in this series, the linear version features a proprietary integrated driver and small footprint, making it a great choice for new construction or retrofit applications.



## DRD5S

### 8" Round Surface Mount

This minimalist downlight takes everything that makes the original DRD5S exceptional, and expands on it. This area light can fill a room with inviting, accurate illumination. In addition, its SurfaceFrame compatibility simplifies installation and makes it totally interoperable with the rest of the DRD5S family.

# 2" Recessed



## LD2

### 2" Recessed LED Downlight

With three different beam angles and a wall wash feature, the LD2 provides a host of architectural lighting options from its 2" aperture. And with a compact design that allows for easier installation and maintenance, the LD2 installs in just three simple steps.

# Higher-Lumen



## DCD3

Higher-Lumen LED Module

The DCD3 delivers up to 3000 lm of superior lighting at 90+ CRI, perfect for higher ceiling applications. Its tool-free, field-changeable lenses and trims offer endless lighting customization, allowing you to easily change how your spaces feel and perform with minimal labor. Whether you're lighting a concert hall or a corridor, the DCD3 gives you impressive versatility that's incredibly simple to use.

## DCD4


Adjustable Higher-Lumen LED Module

The DCD4 puts powerful lighting exactly where you want it with 360° of aimable rotation and up to 40° of tilt. Simply unlock a lever and knob to allow precise, infinite adjustments and then lock it back into place. The process is quick, simple, and 100% tool-free. And with field-changeable beam angles and lumen outputs, you can further customize your lighting, even after installation.



“Everything is so plug & play, all you need is a ladder to get up to the light.”


# Housings

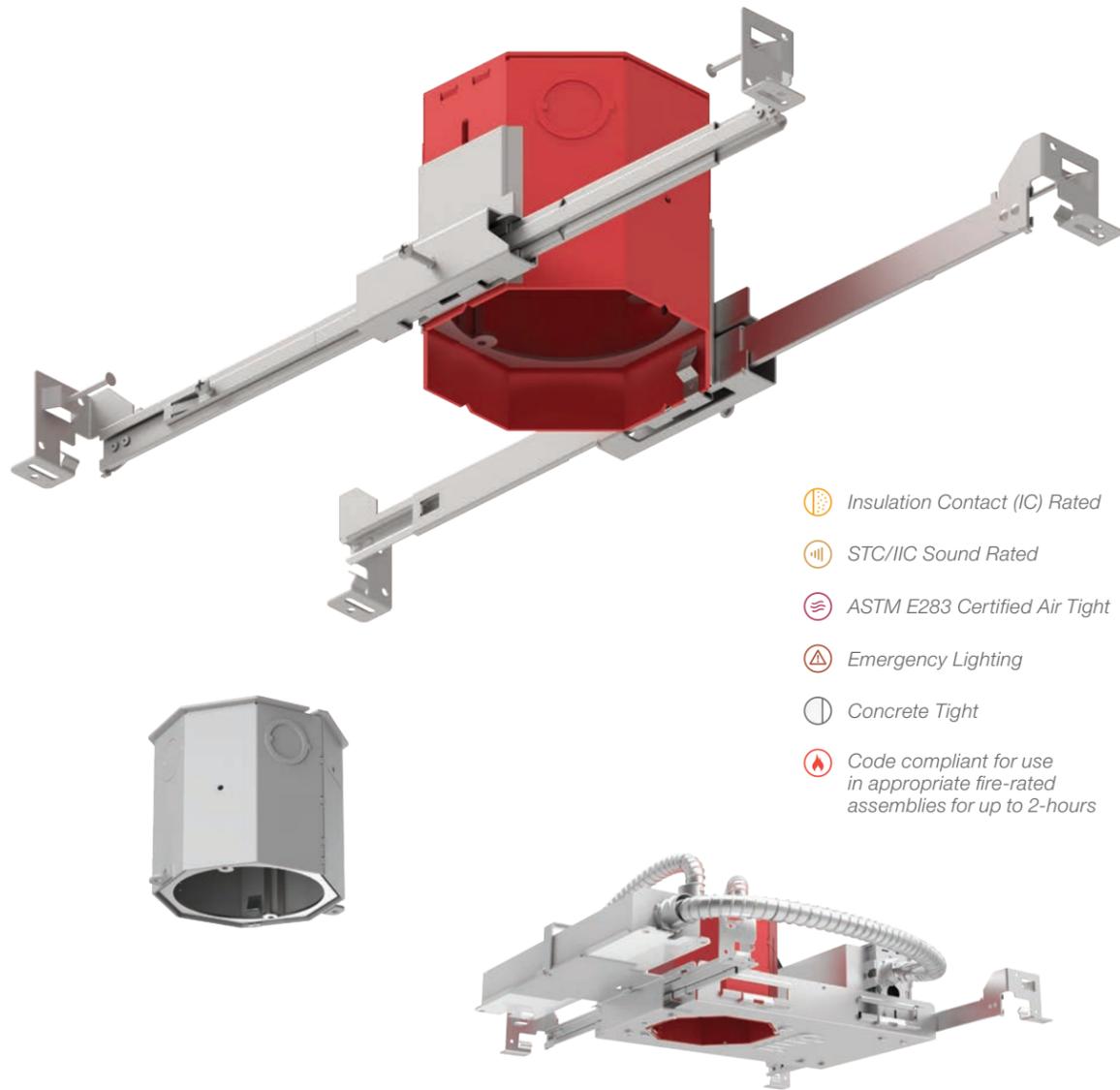

-  Insulation Contact (IC) Rated
-  STC/IIC Sound Rated
-  ASTM E283 Certified Air Tight
-  Emergency Lighting
-  Concrete Tight
-  Code compliant for use in appropriate fire-rated assemblies for up to 2-hours

## OneFrame


The OneFrame® is the first of its kind – a revolutionary LED housing created with multifamily construction in mind. Thanks to its unique low profile and small aperture design, it provides you with high-quality, cost-effective recessed LED lighting that requires less than 4" of ceiling space. Plus, the OneFrame simplifies installation and maintenance and blends into any aesthetic. It's performance and value all in one compact package.

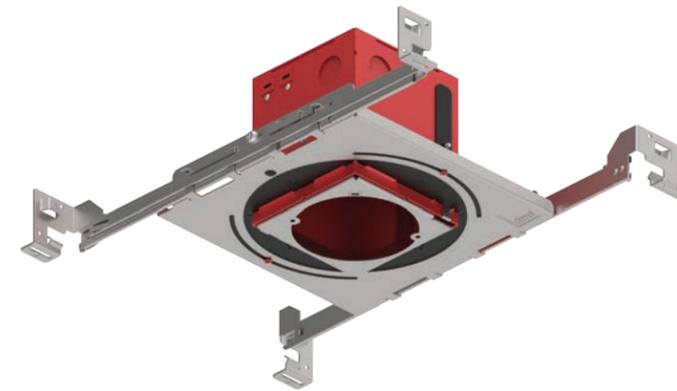

-  Insulation Contact (IC) Rated
-  STC/IIC Sound Rated
-  ASTM E283 Certified Air Tight
-  Emergency Lighting
-  Code compliant for use in appropriate fire-rated assemblies for up to 2-hours

## SquareFrame

The SquareFrame™ offers a suite of features that work together seamlessly to give you a flawless fit more quickly and with less hassle. 90 degrees of rotation, lateral translation and fine-tuning adjustments combine for perfectly straight and perfectly aligned installations.

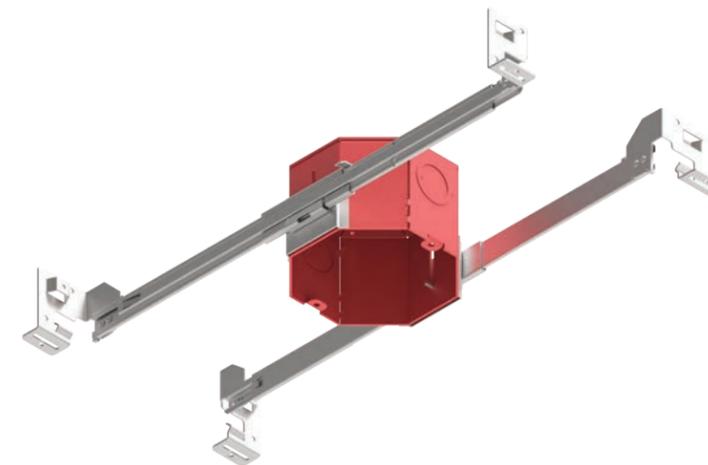


-  Insulation Contact (IC) Rated
-  STC/IIC Sound Rated
-  ASTM E283 Certified Air Tight
-  Emergency Lighting
-  Code compliant for use in appropriate fire-rated assemblies for up to 2-hours

## SurfaceFrame

Based on the award-winning OneFrame, the SurfaceFrame™ is an ultra low-profile housing designed for DMF's surface mount luminaires. Its innovative design requires minimal installation space while preserving key ratings and performance features.

# Housings

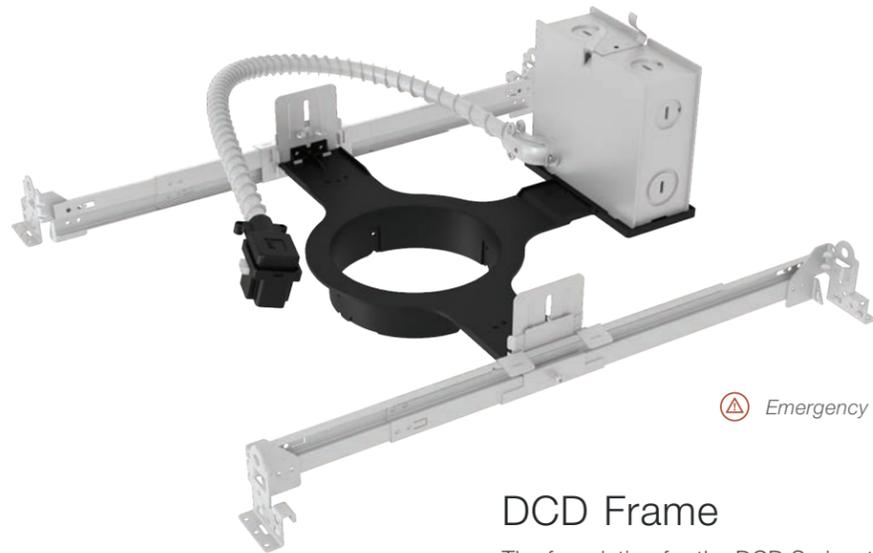

 Emergency Lighting

## DCD Frame

The foundation for the DCD Series, the DCD Frame offers flexibility at every stage. After installation, you can decide to install general downlights or adjustables and even switch to accents, wall washes, or change beam angles.





## Classic Frames

All of our DRDH and DCDH housings are UL Listed approved for use with DMF's advanced LED modules. With new construction or remodel options featuring 4", 5", 6", or 8" apertures, you can choose the housing that best fits your application.

 Insulation Contact (IC) Rated

 ASTM E283 Certified Air Tight

 Emergency Lighting

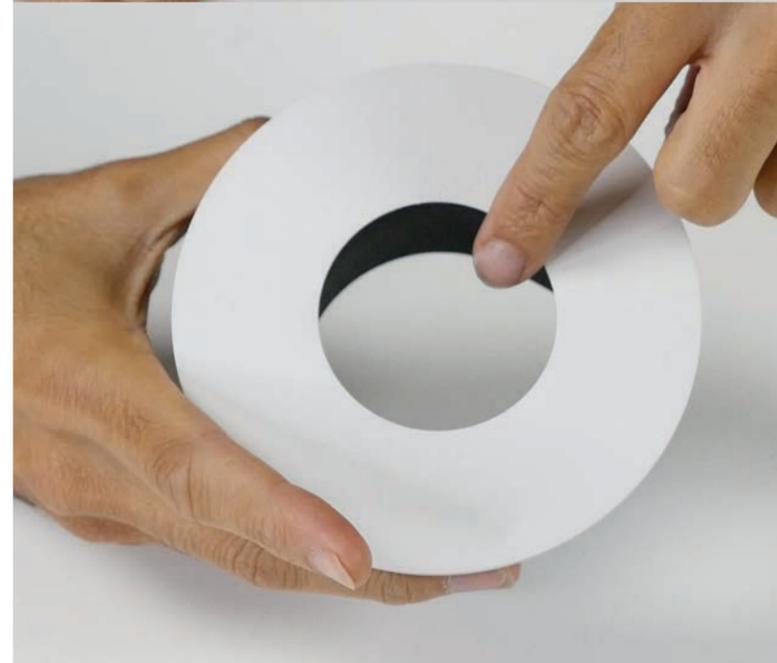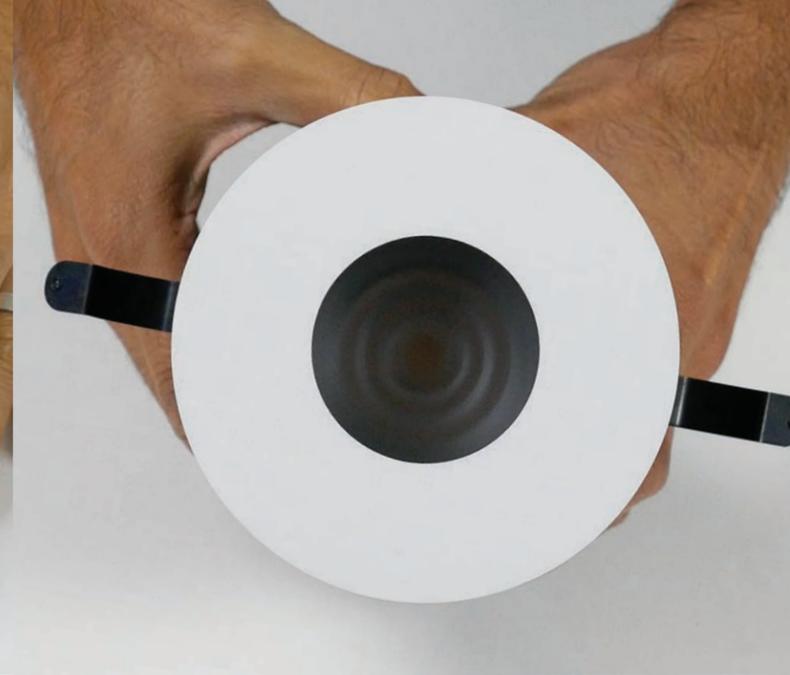


# Trims



## A perfect match

Made with die-cast aluminum, our trims are completely customizable by color, finish, shape, and function. They can blend in, or stand out, depending on your vision. And just like the rest of the DMF system, they're exceptionally easy to install or change.

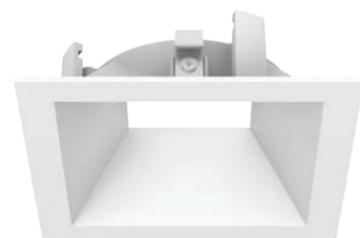

### Square

A modern look that's expertly die cast with sharp edges and precise corners.



### Decorative

Finely crafted acrylic that delivers a subtle, radiant glow. Options include an open or closed bottom, and frosted or clear finish.



### Wall Wash

Perfect for delivering broad, consistent light across a wall surface with an unobtrusive design that stays above the ceiling plane.



### Round on Square

Unobstructed illumination from a square profile.




### Flangeless

Low-profile mud flange installs simply and seamlessly. Available for Round, Square, Hyperbolic, Pinhole, and Wall Wash trims.



### Emergency

Provides emergency functionality with an integrated test switch. Available in round and square.

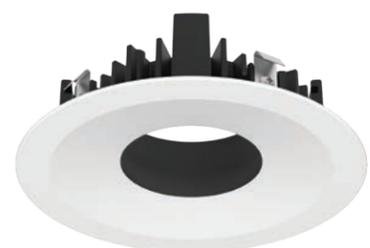

### Pinhole

Accentuates light distribution for a narrow, spotlight effect. Choose between straight or beveled edges.




### Hyperbolic

A unique reflector that provides completely smooth, uniform light and blends into ceilings.



### Diffused Finishes

Diffused finishing options reduce glare even further for soft, comfortable lighting.

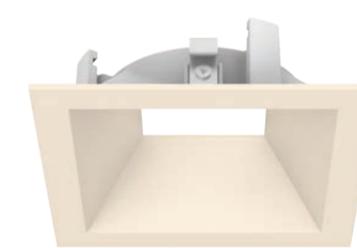

### Custom Colors

Make your project completely your own with fully customizable color options for all trims.

# Cylinders



## DCC

LED Cylinder

By combining a suite of customizable features with our highest performing LED modules yet, the DCC provides brilliant illumination and beautiful design versatile enough for whatever your project needs. The DCC centers around a modular LED lighting system, so it's easy to specify, install and maintain.



**Standard Trim:** Classic design complements the Cylinder with a simple, uniform aesthetic.



**Hyperbolic Trim:** Edgeless trim provides completely smooth, uniform light.



**Snoot:** Channels light source and decreases visual cutoff angle to increase focus and mitigate glare.



**Decorative Trim:** Clear outside, frosted inside decorative piece refracts light for a diffused effect.



**Low-Profile Decorative Trim:** Finely crafted acrylic subtly fills your space with beautiful ambient light.




**Uplight:** Enables light output at elevated levels, while providing glare-free ambiance and the ability to highlight architectural elements.



**Round & Flat Shades:** Re-imagined for more diverse environments while creating a more focused and comfortable general light.


## Interchangeable Trims & Shades

Shades, trims, specialty options, even the light engine can all be swapped out in the field, giving you control during and after the installation.





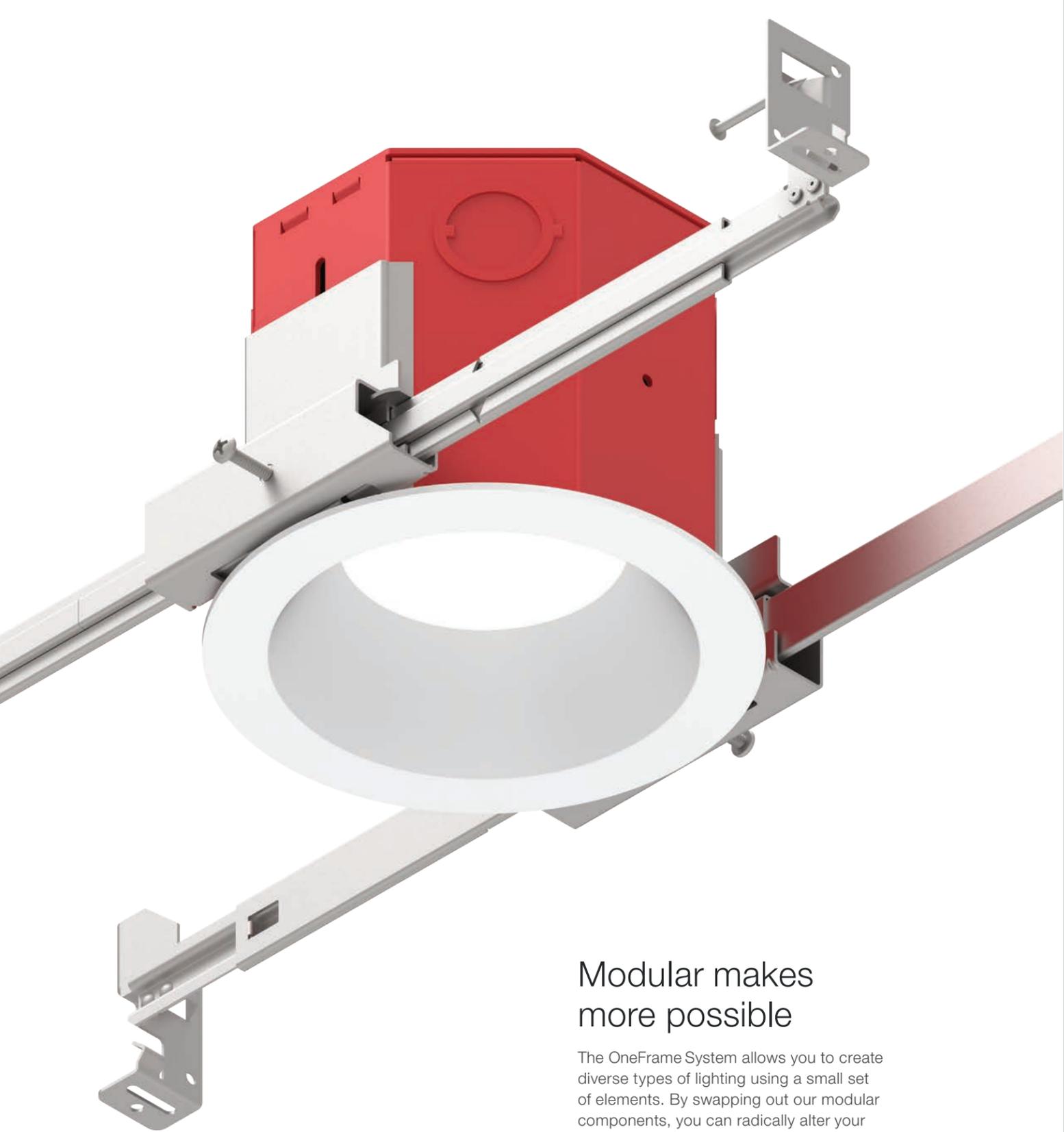


## Modular makes more possible

The OneFrame System allows you to create diverse types of lighting using a small set of elements. By swapping out our modular components, you can radically alter your light without replacing the junction box, drastically reducing costs and labor. That means the people who inhabit your space get exactly the right light, even if their needs change.

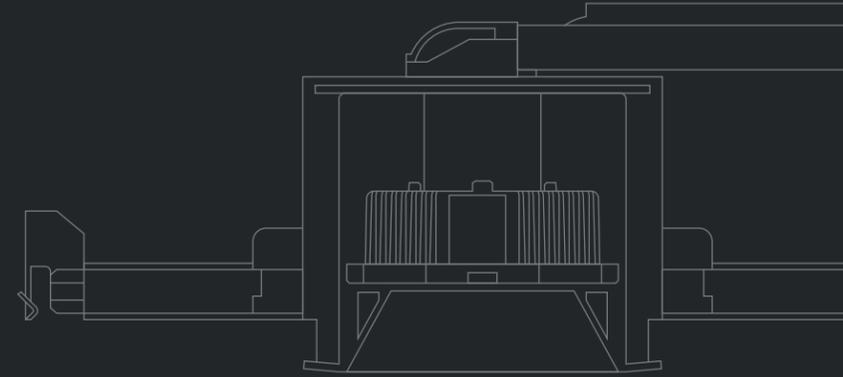

# DMF Product Configuration Guide

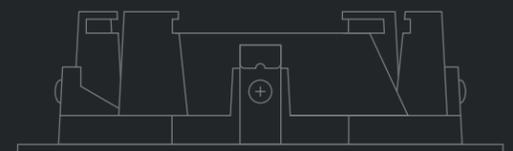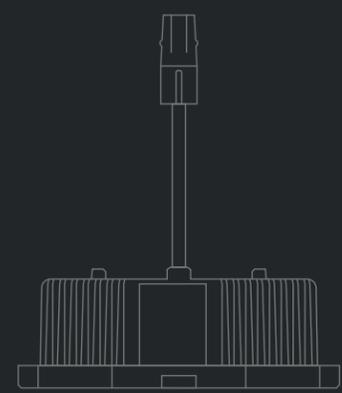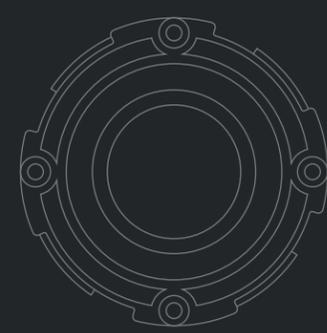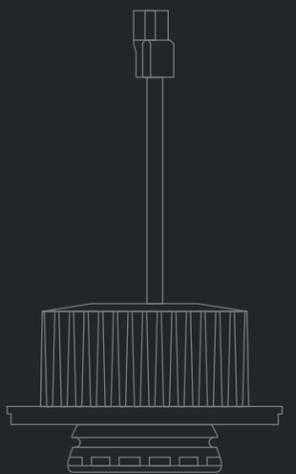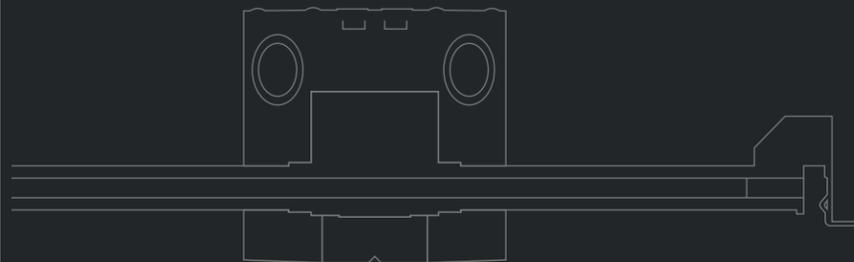

# DRD2

General Recessed LED Downlight



- Compact design with integrated driver
- Delivers up to 1000 lumens of exceptional light
- 93+ CRI and 75 R9 value rated LED for true color every time
- Industry-leading value and efficiency

<b>Application</b> New Construction, Remodel, Retrofit	<b>Compatible Housings</b> OneFrame; SquareFrame; SurfaceFrame; Classic Frames 4", 5", 6", 8"; Surface Mount; Junction Box	
<b>Delivered Lumens</b> 750 lm (10.8W), 1000 lm (12.8W)	<b>Input Voltage</b> 120/277V	<b>Color Quality</b> 93+ CRI, 2-step SDCM
<b>Warm Dim Option</b> ● 3000K - 1800K, 800 lm (12.0W)	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%   Lutron® Hi-lume® 1%	
<b>Color Temperatures</b> ● 2700K ● 3000K ● 3500K ● 4000K	<b>Light Distribution</b> General Wall Wash	
<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure		
<b>Standards</b> 	<b>Ratings</b> ● Wet location	<b>Guarantee</b> 50,000 hrs   5 years

## PRODUCT CODE

PRODUCT	LUMENS	CRI	CCT	DRIVER			
DRD2M	Module	7	750 lm	9 93+ CRI	27 2700K	[Blank]	Integrated TRIAC/ELV
			1000 lm		30 3000K	A	0-10V, Lutron Hi-lume, and/or emergency
					35 3500K		
					40 4000K		

## Warm Dim Option

DRD2M	Module	08	800 lm	9 93+ CRI	3W	Warm Dim	[Blank]	Integrated TRIAC/ELV
							A	0-10V, Lutron Hi-lume, and/or emergency

# DRD2

General Recessed LED Downlight

DRD2  
COMPATIBLE HOUSINGS & TRIMS

## OneFrame System Deep Junction Box

### ONEFRAME HOUSINGS & TRIMS



**DRDHNJD**  
Deep Junction Box



**DRDHNJD**  
Alternate Dimming and/or  
Emergency Driver



**DRDHNJC**  
Concrete Tight

 <b>DRD2TRJDSWH</b> Round	 <b>DRD2TSJDSWH</b> Square	 <b>DRD2TRJDHWH</b> Hyperbolic	 <b>DRD2TRJDPWH</b> Pinhole	 <b>DRD2TRJDBWH</b> Beveled Pinhole
 <b>DRD2TRJDWWH</b> Round Wall Wash	 <b>DRD2TSJDWWH</b> Square Wall Wash	 <b>DRD2TRJDSWHDOF</b> Decorative: Open, Frosted	 <b>DRD2TRJDSWHDCF</b> Decorative: Closed, Frosted	 <b>DRD2TRJDSWHDCC</b> Decorative: Closed, Clear, Frosted Side
 <b>DRD2TRJDSWHDCCF</b> Decorative: Closed, Clear, Frosted Inside	 <b>DRD2TRJDSWHEM</b> Emergency	 <b>DRD2TRJDSWHDF</b> Non-Conductive Dead Front	 <b>DRD2TRJDSWHFL*</b> Round Flangeless	 <b>DRD2TRJDHWHFL*</b> Hyperbolic Flangeless
 <b>DRD2TRJDPWHFL*</b> Pinhole Flangeless	 <b>DRD2TRJDBWHFL*</b> Beveled Pinhole Flangeless	 <b>DRD2TRJDWWHFL*</b> Wall Wash Flangeless	 <b>DRD2HX-MUD-FL</b> Flangeless Mud Plate	


## FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)

\*Requires Flangeless Mud Plate

SquareFrame System Square Junction Box

SQUAREFRAME HOUSINGS & TRIMS

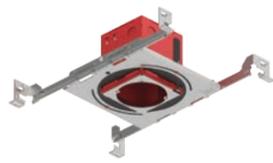

**DRDHNJS**  
Square Junction Box



**DRDHNJS**  
Alternate Dimming and/or  
Emergency Driver

 <b>DRD2TSJSSWH</b> Square ○ ● ● ● ●	 <b>DRD2TSJSQWH</b> Round on Square ○ ● ● ● ●	 <b>DRD2TSJSPWH</b> Pinhole ○ ● ●	 <b>DRD2TSJSBWH</b> Beveled Pinhole ○ ● ●	 <b>DRD2TSJSWWH</b> Wall Wash ○ ● ●
 <b>DRD2TRJDSWHDCF</b> Decorative: Closed, Frosted ○ ● ●	 <b>DRD2TRJDSWHDCCF</b> Decorative: Closed, Clear, Frosted Sides ○ ● ●	 <b>DRD2TSJSSWHEM</b> Emergency ○ ● ●	 <b>DRD2TSJSSWHFL*</b> Square Flangeless ○ ● ●	 <b>DRD2TSJSQWHFL*</b> Round on Square Flangeless ○ ● ●
 <b>DRD2TSJSPWHFL*</b> Pinhole Flangeless ○ ● ●	 <b>DRD2TSJSBWHFL*</b> Beveled Pinhole Flangeless ○ ● ●	 <b>DRD2TSJSWWHFL*</b> Wall Wash Flangeless ○ ● ●	 <b>DRDHX-MUD-SFL</b> Flangeless Mud Plate	

\*Requires Flangeless Mud Plate

FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)

Classic Frames

4" GENERAL HOUSINGS & TRIMS



**DRDHNIC4**  
4" New Construction



**DRDHRIC4**  
4" Remodel



**DRDHNIC4S**  
4" Shallow New Construction



**DRDHRIC4S**  
4" Shallow Remodel

 <b>DRD2TR4SWH</b> 4" Smooth ○ ● ● ● ●	 <b>DRD2TR4BWH</b> 4" Baffle ○ ● ● ● ●	 <b>DRD2TR4WWH</b> 4" Wall Wash ○	 <b>DRD2TS4SWH</b> 4" Square (New Construction only) ○ ● ● ● ●	 <b>DRD2TQ4SWH</b> 4" Round on Square (New Construction only) ○ ● ● ● ●
--	--	---	---	--

5" GENERAL HOUSINGS & TRIMS



**DRDHNIC5**  
5" New Construction



**DRDHRIC5**  
5" Remodel



6" GENERAL HOUSINGS & TRIMS



**DRDHNIC6**  
6" New Construction



**DRDHRIC6**  
6" Remodel



**DRDHNIC6S**  
6" Shallow New Construction



**DRDHRIC6S**  
6" Shallow Remodel

 <b>DRD2TR6SWH</b> 6" Smooth ○ ● ● ● ●	 <b>DRD2TR6BWH</b> 6" Baffle ○ ● ● ● ●	 <b>DRD2TR6WWH</b> 6" Wall Wash ○	 <b>DRD2TD6SWH</b> 6" Deep Smooth ○ ● ● ● ●	 <b>DRD2TD6BWH</b> 6" Deep Baffle ○ ● ● ● ●
--	--	---	---	---

NOTE: Please reference product Spec Sheets for complete ordering information

SurfaceFrame Shallow Junction Box




DRDHS Surface Mount



Classic Commercial Frames

4" COMMERCIAL HOUSINGS & TRIMS

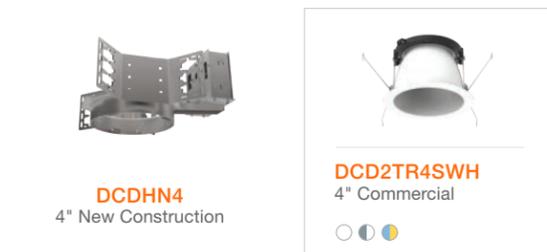


6" COMMERCIAL HOUSINGS & TRIMS



8" COMMERCIAL HOUSINGS & TRIMS



Retrofit

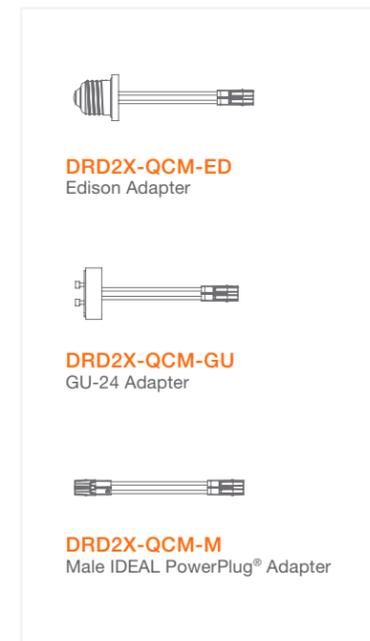

FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)



Comfort without compromise

DMF's Warm Dim technology transforms how your spaces look and feel without sacrificing simplicity or performance. Warm Dim transitions from a bright and inviting 3000K to a warm and intimate 1800K, maintaining a consistent 93+ CRI and Energy Star rating throughout.

# DRD2X

Apex Series Recessed LED Downlight



- Top-tier beam-controlled illumination, delivered with industry-leading value
- 90+ CRI rated LED produces up to 750 lumens and 4000cd of focused light with 20°, 30°, and 40° available optics
- Compact design with integrated driver
- Twist & Lock feature allows for easy, tool-free installation and trim modification

<b>Application</b> New Construction, Remodel, Retrofit	<b>Compatible Housings</b> OneFrame; SquareFrame; SurfaceFrame; Classic Frames 4", 5", 6", 8"; Surface Mount; Junction Box	
<b>Delivered Lumens</b> 600 lm (10W), 750 lm (12.5W)	<b>Input Voltage</b> 120/277V	<b>Center Beam Candlepower</b> 4000cd (Spot 750lm)
<b>Warm Dim Option</b> 3000K – 1800K, 600 lm (12.0W), 93+ CRI, 3000cd	<b>Surround</b> White, Black	<b>Color Quality</b> 90+ CRI, 2-step SDCM
<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%   Lutron® Hi-lume® 1%	
<b>Color Temperatures</b> 2700K 3000K 3500K 4000K	<b>Optics</b> Spot (20°) Narrow Flood (30°) Flood (40°)	
<b>Standards</b> JAB TITLE 24 ENERGY STAR UL LISTED	<b>Ratings</b> Wet location	<b>Guarantee</b> 50,000 hrs   5 years

## PRODUCT CODE

PRODUCT	LUMENS	CRI	CCT	OPTICS	SURROUND	DRIVER
DRD2X	Module	06 600 lm	9 90+ CRI	27 2700K	SP Spot	[Blank] Integrated TRIAC/ELV
		07 750 lm		30 3000K	NF Narrow Flood	0-10V, Lutron Hi-lume, and/or emergency
				35 3500K	FL Flood	
				40 4000K		
				3W Warm Dim*		

\*Warm Dim only available in 600 lm

# DRD2X

Apex Series Recessed LED Downlight

DRD2X  
COMPATIBLE HOUSINGS & TRIMS

## OneFrame System Deep Junction Box

### ONEFRAME HOUSINGS & TRIMS



**DRDHNJD**  
Deep Junction Box



**DRDHNJD**  
Alternate Dimming and/or  
Emergency Driver



**DRDHNJC**  
Concrete Tight

 <b>DRD2TRJDSWH</b> Round	 <b>DRD2TSJDSWH</b> Square	 <b>DRD2TRJDHWH</b> Hyperbolic	 <b>DRD2TRJDPWH</b> Pinhole	 <b>DRD2TRJDBWH</b> Beveled Pinhole
 <b>DRD2TRJDWWH</b> Round Wall Wash	 <b>DRD2TSJDWWH</b> Square Wall Wash	 <b>DRD2TRJDSWHDOF</b> Decorative: Open, Frosted	 <b>DRD2TRJDSWHDCF</b> Decorative: Closed, Frosted	 <b>DRD2TRJDSWHDCC</b> Decorative: Closed, Clear, Frosted Side
 <b>DRD2TRJDSWHDCCF</b> Decorative: Closed, Clear, Frosted Inside	 <b>DRD2TRJDSWHEM</b> Emergency	 <b>DRD2TRJDSWHDF</b> Non-Conductive Dead Front	 <b>DRD2TRJDSWHFL*</b> Round Flangeless	 <b>DRD2TRJDHWHFL*</b> Hyperbolic Flangeless
 <b>DRD2TRJDPWHFL*</b> Pinhole Flangeless	 <b>DRD2TRJDBWHFL*</b> Beveled Pinhole Flangeless	 <b>DRD2TRJDWWHFL*</b> Wall Wash Flangeless	 <b>DRDHX-MUD-FL</b> Flangeless Mud Plate	


\*Requires Flangeless Mud Plate

### FINISH OPTIONS

- White (WH)
- Black (BK)
- ◐ Silver Reflector, White Flange (SW)
- ◑ Low Iridescent Reflector, White Flange (AZ)
- ◒ Custom Color Available (CC)

SquareFrame System Square Junction Box

SQUAREFRAME HOUSINGS & TRIMS

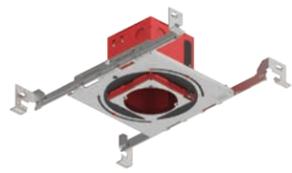

**DRDHNJS**  
Square Junction Box



**DRDHNJS**  
Alternate Dimming and/or  
Emergency Driver

 <b>DRD2TSJSSWH</b> Square ○ ● ● ● ●	 <b>DRD2TSJSQWH</b> Round on Square ○ ● ● ● ●	 <b>DRD2TSJSPWH</b> Pinhole ○ ● ●	 <b>DRD2TSJSBWH</b> Beveled Pinhole ○ ● ●	 <b>DRD2TSJSWWH</b> Wall Wash ○ ● ●
 <b>DRD2TRJDSWHDCF</b> Decorative: Closed, Frosted ○ ● ●	 <b>DRD2TRJDSWHDCCF</b> Decorative: Closed, Clear, Frosted Sides ○ ● ●	 <b>DRD2TSJSSWHEM</b> Emergency ○ ● ●	 <b>DRD2TSJSSWHFL*</b> Square Flangeless ○ ● ●	 <b>DRD2TSJSQWHFL*</b> Round on Square Flangeless ○ ● ●
 <b>DRD2TSJSPWHFL*</b> Pinhole Flangeless ○ ● ●	 <b>DRD2TSJSBWHFL*</b> Beveled Pinhole Flangeless ○ ● ●	 <b>DRD2TSJSWWHFL*</b> Wall Wash Flangeless ○ ● ●	 <b>DRDHX-MUD-SFL</b> Flangeless Mud Plate	

\*Requires Flangeless Mud Plate

FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)

Classic Frames

4" GENERAL HOUSINGS & TRIMS



**DRDHNIC4**  
4" New Construction



**DRDHRIC4**  
4" Remodel



**DRDHNIC4S**  
4" Shallow New Construction



**DRDHRIC4S**  
4" Shallow Remodel

 <b>DRD2TR4SWH</b> 4" Smooth ○ ● ● ● ●	 <b>DRD2TR4BWH</b> 4" Baffle ○ ● ● ● ●	 <b>DRD2TR4WWH</b> 4" Wall Wash ○	 <b>DRD2TS4SWH</b> 4" Square (New Construction only) ○ ● ● ● ●	 <b>DRD2TQ4SWH</b> 4" Round on Square (New Construction only) ○ ● ● ● ●
--	--	---	---	--

5" GENERAL HOUSINGS & TRIMS



**DRDHNIC5**  
5" New Construction



**DRDHRIC5**  
5" Remodel



**DRD2TR5SWH**  
5" Smooth  
○ ● ● ● ●



**DRD2TR5BWH**  
5" Baffle  
○ ● ● ● ●



**DRD2TR5WWH**  
5" Wall Wash  
○

6" GENERAL HOUSINGS & TRIMS



**DRDHNIC6**  
6" New Construction



**DRDHRIC6**  
6" Remodel



**DRDHNIC6S**  
6" Shallow New Construction



**DRDHRIC6S**  
6" Shallow Remodel


 <b>DRD2TR6SWH</b> 6" Smooth ○ ● ● ● ●	 <b>DRD2TR6BWH</b> 6" Baffle ○ ● ● ● ●	 <b>DRD2TR6WWH</b> 6" Wall Wash ○	 <b>DRD2TD6SWH</b> 6" Deep Smooth ○ ● ● ● ●	 <b>DRD2TD6BWH</b> 6" Deep Baffle ○ ● ● ● ●
--	--	---	---	---

# DRD2X


Apex Series Recessed LED Downlight

DRD2X  
COMPATIBLE HOUSINGS & TRIMS

## SurfaceFrame Shallow Junction Box

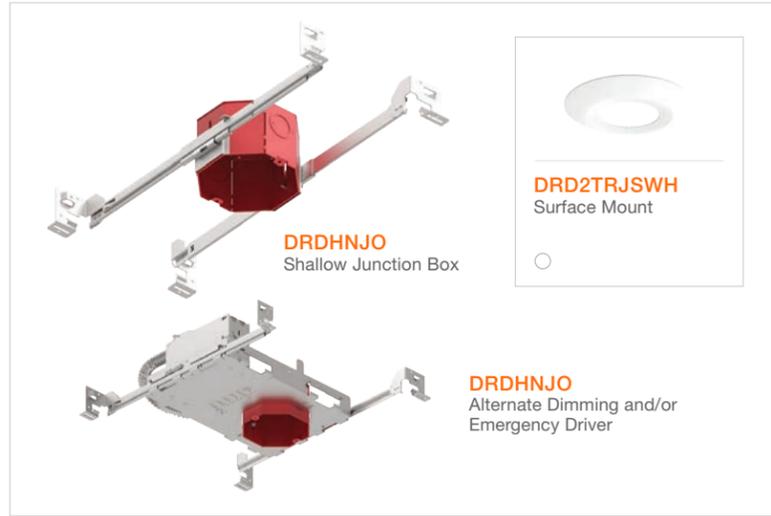


## DRDHS Surface Mount

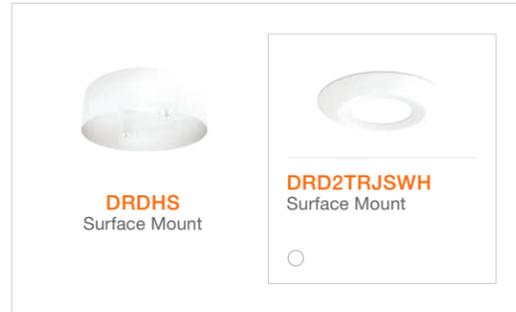

## Classic Commercial Frames

### 4" COMMERCIAL HOUSINGS & TRIMS

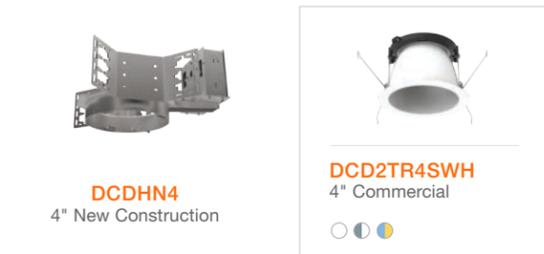


### 6" COMMERCIAL HOUSINGS & TRIMS



### 8" COMMERCIAL HOUSINGS & TRIMS




## Retrofit

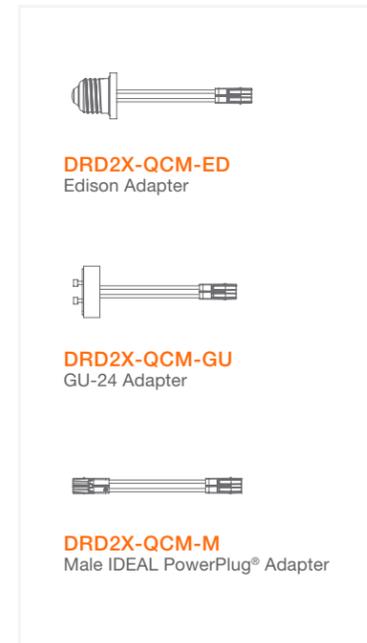

### FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)

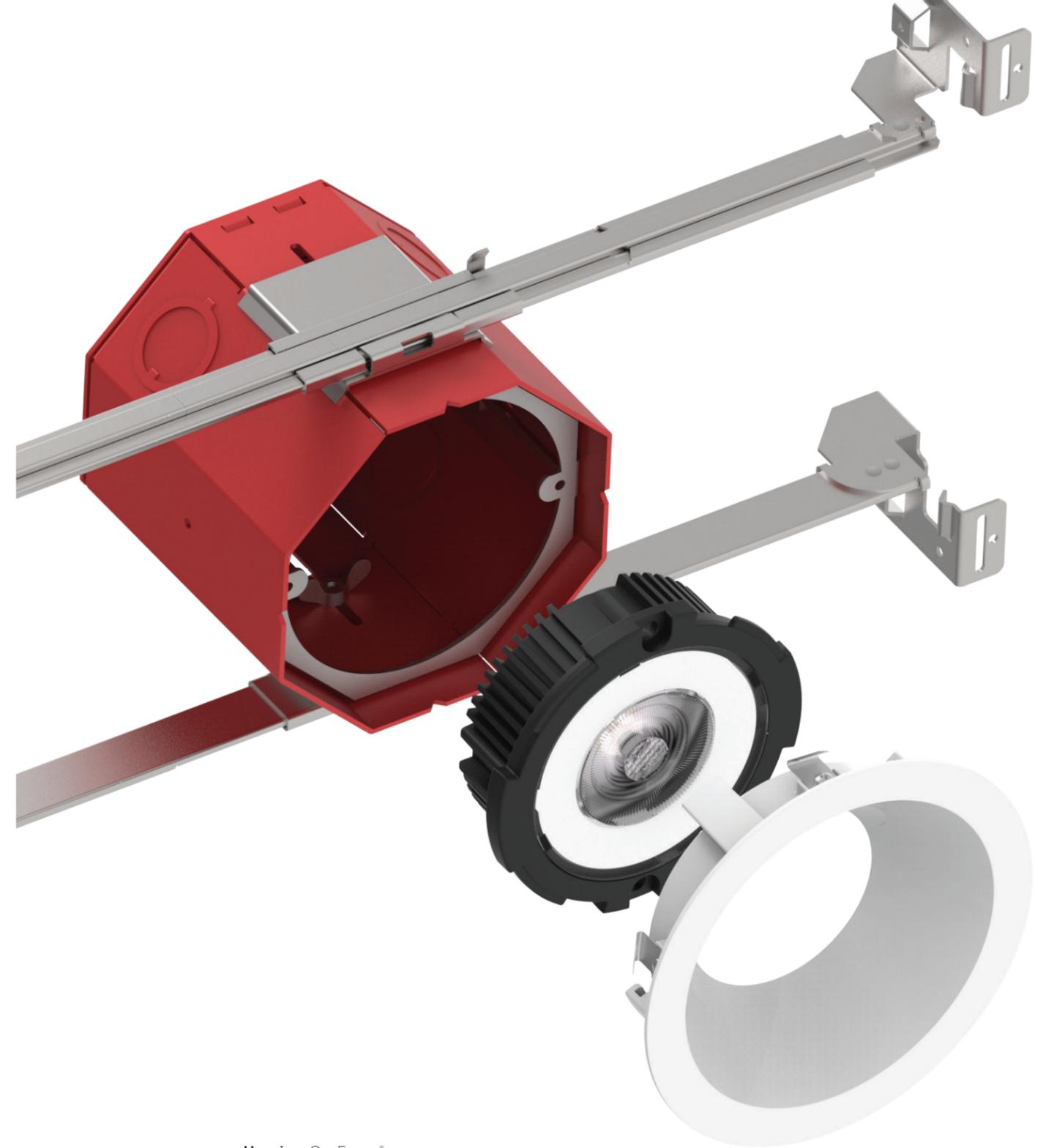

**Housing** OneFrame®  
**Module** DRD2X Apex Series LED Module  
**Trim** Round

# DRD3

Adjustable Recessed LED Downlight



- Perfect for specialized accent-lighting designs when selecting DMF Classic or industry standard frames
- 360° rotation enables precise directional aim
- Won't cross the ceiling plane, even when tilted



<b>Application</b> New Construction, Remodel, Retrofit	<b>Compatible Housings</b> Classic Frames: 4", 5", 6"
<b>Delivered Lumens</b> 750 lm (12.0W), 1000 lm (14.7W)	<b>Input Voltage</b> 120/277V
<b>Adjustment</b> 360° directional aim, 40° tilt	<b>Finish</b> White, Black, Custom
<b>Color Quality</b> 90+ CRI, 2-step SDCM	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%   Lutron® Hi-lume® 1%
<b>Color Temperatures</b> 2700K 3000K 3500K 4000K	<b>Optics</b> Spot (23°) Flood (42°)
<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure	
<b>Standards</b> 	<b>Ratings</b> Damp location
<b>Guarantee</b> 50,000 hrs   5 years	

## PRODUCT CODE

PRODUCT	LUMENS	CRI	CCT	OPTIC	FINISH	DRIVER
<b>DRD3M</b> Module	<b>07</b> 750 lm	<b>9</b> 90+ CRI	<b>27</b> 2700K	<b>SP</b> Spot	<b>WH</b> White	<b>[Blank]</b> Integrated TRIAC/ELV
	<b>10</b> 1000 lm		<b>30</b> 3000K	<b>FL</b> Flood	<b>BK</b> Black	<b>A</b> 0-10V, Lutron Hi-lume, and/or emergency
			<b>35</b> 3500K		<b>CC</b> Custom Color	
			<b>40</b> 4000K			


# DRD3

Adjustable Recessed LED Downlight

DRD3  
COMPATIBLE HOUSINGS & TRIMS

## Classic Frames


### 4" GENERAL HOUSINGS & TRIMS

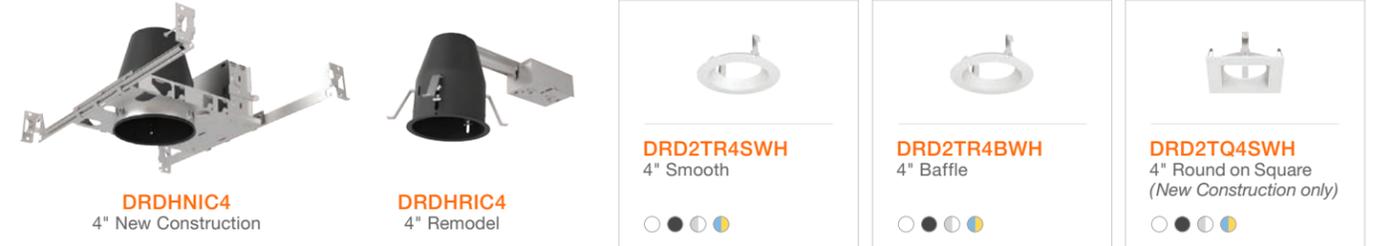

### 5" GENERAL HOUSINGS & TRIMS



### 6" GENERAL HOUSINGS & TRIMS

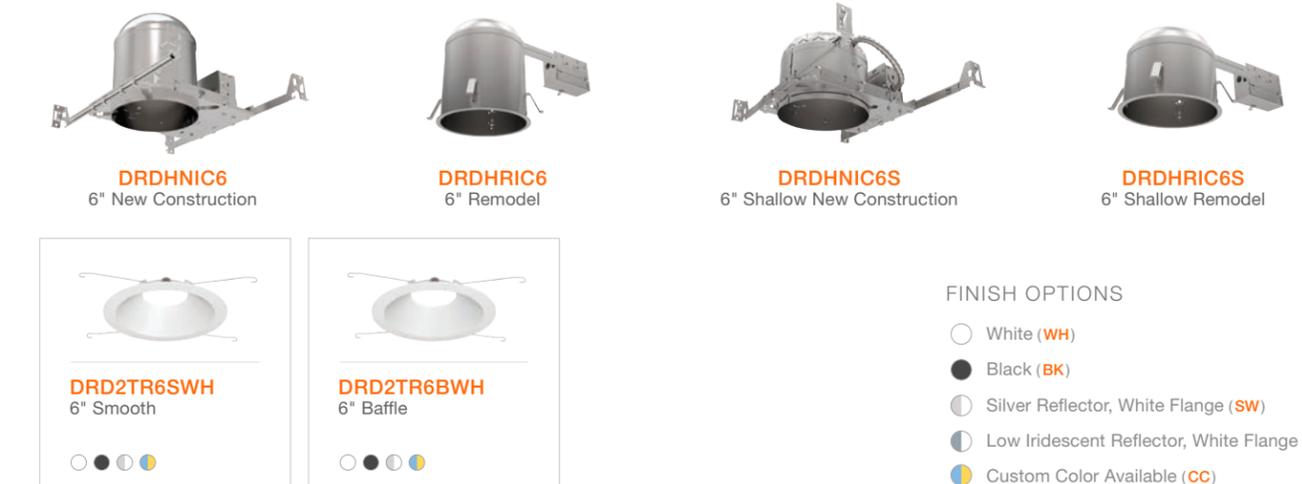

- FINISH OPTIONS**
- White (**WH**)
  - Black (**BK**)
  - Silver Reflector, White Flange (**SW**)
  - Low Iridescent Reflector, White Flange (**AZ**)
  - Custom Color Available (**CC**)

## Retrofit



# DRD4

Adjustable Recessed LED Downlight



- Precise, 360° adjustable downlight with integrated driver
- Tool-free, field-changeable optics and accessories
- Up to 45° tilt without disrupting the ceiling plane
- 5° incremental detents enable tactile feedback and precise control
- Best-in-class efficiency



<b>Application</b> New Construction		<b>Compatible Housings</b> OneFrame, SquareFrame	
<b>Delivered Lumens</b> 750 lm (9.7W), 1000 lm (12.0W)		<b>Input Voltage</b> 120/277V	<b>Center Beam Candlepower</b> 6000cd (Spot 800lm)
<b>Adjustment</b> 360° directional aim, 45° tilt		<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%   Lutron® Hi-lume® 1%	
<b>Warm Dim Option</b> 3000K - 1800K, 800 lm (12.0W) 93+ CRI, 5800cd		<b>Color Quality</b> 90+ CRI, 2-step SDCM	<b>FINISH</b> Black, White
<b>Specialty Lens Option</b> Hexcell Louver   Linear Spread		<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure	
<b>Color Temperatures</b> 2700K   3000K   3500K   4000K		<b>Optics</b> Spot (20°)   Narrow Flood (30°)   Flood (40°)	
<b>Standards</b> JAB THERM 24   ENERGY STAR   UL LISTED		<b>Ratings</b> Damp location	<b>Guarantee</b> 50,000 hrs   5 years

## PRODUCT CODE

PRODUCT CODE	LUMENS	CRI	CCT	OPTICS	FINISH	SPECIALTY LENS	DRIVER								
DRD4M	Module	07	750 lm	9	90+ CRI	27	2700K	SP	Spot	[Blank]	Black	[Blank]	None	[Blank]	Integrated TRIAC/ELV
		10	1000 lm			30	3000K	NF	Narrow Flood	W	White	H	Hexcell Louver	A	0-10V, Lutron Hi-lume, and/or emergency
						35	3500K	FL	Flood			L	Linear Spread		
						40	4000K								
						3W	Warm Dim*								

\* Warm Dim only available in 800 lm

# DRD4

Adjustable Recessed LED Downlight

DRD4  
COMPATIBLE HOUSINGS & TRIMS

## OneFrame System Deep Junction Box

### ONEFRAME HOUSINGS & TRIMS



**DRDHNJD**  
Deep Junction Box



**DRDHNJD**  
Alternate Dimming and/or  
Emergency Driver



**DRDHNJC**  
Concrete Tight

 <b>DRD2TRJDSWH</b> Round	 <b>DRD2TRJDHWH</b> Hyperbolic	 <b>DRD2TRJDPWH</b> Pinhole	 <b>DRD2TRJDBWH</b> Beveled Pinhole	 <b>DRD2TRJDSWHEM</b> Emergency
 <b>DRD2TRJDSWHFL*</b> Round Flangeless	 <b>DRD2TRJDHWHFL*</b> Hyperbolic Flangeless	 <b>DRD2TRJDPWHFL*</b> Pinhole Flangeless	 <b>DRD2TRJDBWHFL*</b> Beveled Pinhole Flangeless	 <b>DRDHX-MUD-FL</b> Flangeless Mud Plate


\*Requires Flangeless Mud Plate

### FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Low Iridescent Reflector, White Flange (AZ)
- Custom Color Available (CC)

## SquareFrame System Square Junction Box


### SQUAREFRAME HOUSINGS & TRIMS

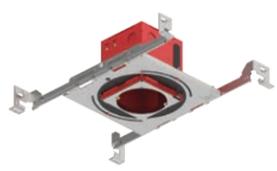


**DRDHNJS**  
Square Junction Box




**DRDHNJS**  
Alternate Dimming and/or  
Emergency Driver

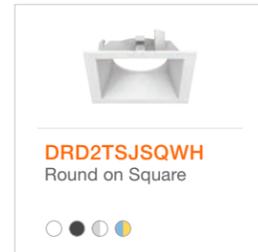

**DRD2TSJSQWH**  
Round on Square  
Pinhole

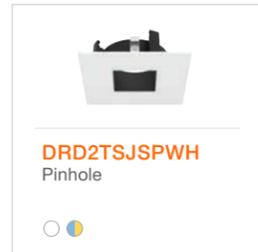

**DRD2TSJSPWH**  
Pinhole

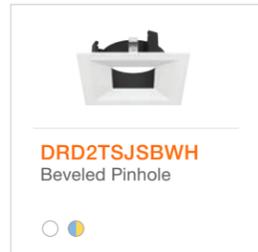


**DRD2TSJSBWH**  
Beveled Pinhole



**DRD2TSJSQWHFL\***  
Round on Square  
Flangeless



**DRD2TSJSPWHFL\***  
Pinhole Flangeless

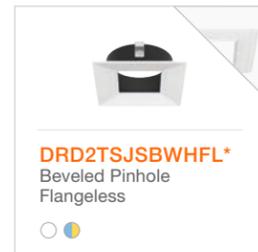

**DRD2TSJSBWHFL\***  
Beveled Pinhole  
Flangeless




**DRDHX-MUD-SFL**  
Flangeless Mud Plate

#### FINISH OPTIONS

- White (WH)
- Black (BK)
- Silver Reflector, White Flange (SW)
- Custom Color Available (CC)

\*Requires Flangeless Mud Plate

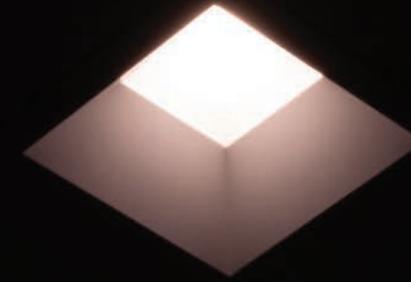

“How easy it is to swap out different products, how easy it is to maintain our products, and how reliable and durable our products are. This is how we make our products unique, and that’s how we make them standard.”

# LD2

2" Recessed LED Downlight



- Slim, 2" aperture
- Installs in three simple steps
- Completely removable for easy maintenance
- High-efficacy LED provides superb color consistency

<b>Application</b> New Construction, Remodel	<b>Compatible Housings</b> LD2NCI, LD2NCN	<b>Aperture</b> 2"
<b>Delivered Lumens</b> 900 lm (16.6W)	<b>Input Voltage</b> 120/277V	
<b>Color Quality</b> 90+ CRI, 2-step SDCM	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%	
<b>Color Temperatures</b>  2700K 3000K 3500K 4000K	<b>Optics</b>  Spot (13°) Narrow Flood (28°) Flood (45°)	
<b>Standards</b> 	<b>Ratings</b>  Wet location available	<b>Guarantee</b> 50,000 hrs   5 years

## PRODUCT CODE

PRODUCT	LUMENS	CRI	CCT	INSTALLATION	OPTICS	DRIVER
LD2	Module 9 900 lm	9 90+ CRI	27 2700K	I IC	SP 13°	T1 TRIAC, 120V
			30 3000K	R Non-IC or Remodel	NF 28°	1010 0-10V, 120V
			35 3500K		FL 45°	2010 0-10V, 277V
			40 4000K			

# LD2

2" Recessed LED Downlight

LD2  
COMPATIBLE HOUSINGS & TRIMS




## LD2 HOUSINGS & TRIMS



LD2NCI  
New Construction, IC



LD2NCN  
New Construction, Non-IC

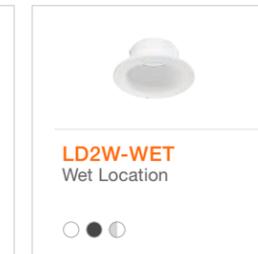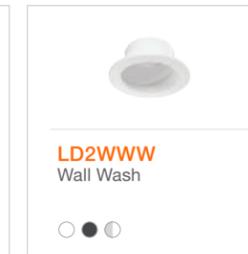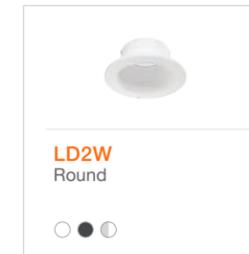

### FINISH OPTIONS

- White (W)
- Black (B)
- Diffused Silver Reflector, White Flange (DW)

# DRD5S

4" Surface Mount LED Downlight



- Thinnest in its class, extends just 0.6" from the ceiling plane
- Clear uniform light, no dark spots
- 90+ CRI LED standard, and produces up to 1000 lumens of exceptional light
- Snaps into place for easy installation and maintenance
- Proprietary-integrated driver with smooth dimming capability down to 5%

<b>Application</b> New Construction, Retrofit	<b>Compatible Housings</b> SurfaceFrame, Metallic Octagonal or Non-Metallic Round Junction Box
<b>Delivered Lumens</b> 750 lm (9.0W), 1000 lm (12.0W)	<b>Input Voltage</b> 120/277V
<b>Color Quality</b> 90+ CRI, < 3-step SDCM	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%
<b>Shape</b> 4" Round, 4" Square	<b>Finish</b> White
<b>Color Temperatures</b>  2700K 3000K 3500K	<b>Emergency Lighting</b> Optional Emergency LED Driver with integrated EM Test Switch for lighting up to 90 minutes in event of power failure
<b>Standards</b> 	<b>Ratings</b>  Wet location
<b>Guarantee</b> 50,000 hrs   5 years	

## PRODUCT CODE

PRODUCT	SIZE	SHAPE	LUMENS	CRI	CCT	DRIVER	OPTION
DRD5S	Module 4 4" Width	R Round	07 750 lm	9 90+ CRI	27 2700K	[Blank] Integrated TRIAC/ELV	[Blank] None
		S Square	10 1000 lm		30 3000K	O Integrated 0-10V	DF Non-Conductive Dead Front
					35 3500K	EM Emergency	

# DRD5S

8" Surface Mount LED Area Light



- 8" round area light for lighting smaller spaces including bathrooms, closets, and kitchens
- Extends just 0.6" below the ceiling plane to minimize visual profile
- Integrated driver provides down to 5% dimming capability and simplifies maintenance

<b>Application</b> New Construction, Retrofit	<b>Compatible Housings</b> SurfaceFrame, Metallic Octagonal or Non-Metallic Round Junction Box
<b>Delivered Lumens</b> 1500 lm (17W)	<b>Input Voltage</b> 120/277V
<b>Color Quality</b> 90+ CRI, < 3-step SDCM	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%
<b>Shape</b> 8" Round	<b>Finish</b> White
<b>Color Temperatures</b>  2700K 3000K 3500K	<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure
<b>Standards</b> 	<b>Ratings</b>  Wet location
<b>Guarantee</b> 50,000 hrs   5 years	

## PRODUCT CODE

PRODUCT	SIZE	SHAPE	LUMENS	CRI	CCT	DRIVER
DRD5S	Module 8 8" Diameter	R Round	15 1500 lm	9 90+ CRI	27 2700K	[Blank] Integrated TRIAC/ELV
					30 3000K	O Integrated 0-10V
					35 3500K	A Alternate

# DRD5S

18" Linear Surface Mount LED Area Light



- 18" x 4" linear area light perfect for narrow applications such as corridors or kitchen islands
- Extends just 0.6" below the ceiling plane to minimize visual profile
- Integrated driver provides down to 5% dimming capability and simplifies maintenance

<b>Application</b> New Construction, Retrofit	<b>Compatible Housings</b> SurfaceFrame, Metallic Octagonal or Non-Metallic Round Junction Box
<b>Delivered Lumens</b> 1500 lm (17W)	<b>Input Voltage</b> 120/277V
<b>Color Quality</b> 90+ CRI, < 3-step SDCM	<b>Dimming</b> TRIAC/ELV 5%   0-10V 1%
<b>Shape</b> 18" x 4" Rectangle	<b>Finish</b> White
<b>Color Temperatures</b>  2700K   3000K   3500K	<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure
<b>Standards</b> 	<b>Ratings</b>  Wet location
<b>Guarantee</b> 50,000 hrs   5 years	

## PRODUCT CODE


PRODUCT	SIZE	SHAPE	LUMENS	CRI	CCT	DRIVER
DRD5S	Module 4 4" Width	L Linear	15 1500 lm	9 90+ CRI	27 2700K	[Blank] Integrated TRIAC/ELV
					30 3000K	O Integrated 0-10V
					35 3500K	A Alternate

# DRD5S

Surface Mount Series

DRD5S  
INSTALLATION OPTIONS

## DRD5S Installation Options

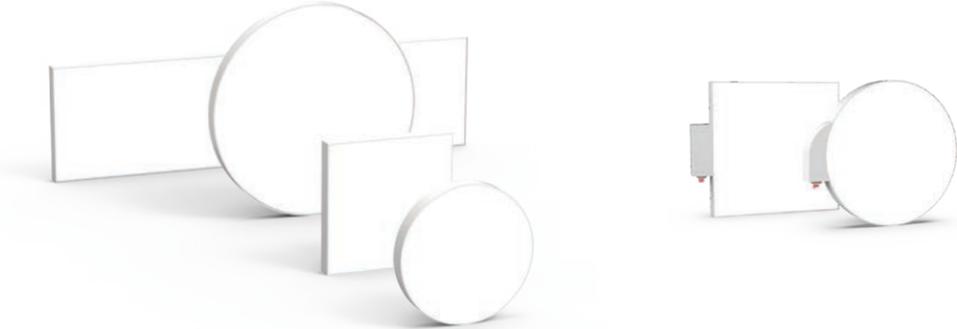


### NEW CONSTRUCTION

#### SurfaceFrame Shallow Junction Box



**DRDHNJO**  
Shallow Junction Box

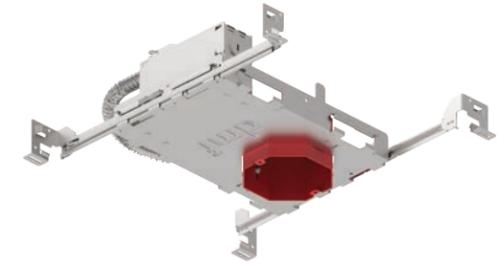

**DRDHNJO**  
Alternate Dimming and/or  
Emergency Driver

### RETROFIT

#### Compatible Junction Boxes



JUNCTION BOX	MIN. DEPTH	MIN. VOLUME	THROUGH-WIRE RATING
4O Octagonal (metallic)	2 1/8"	21.5 in <sup>3</sup>	6 (three in, three out) #12 AWG
3O Round (non-metallic)	2 3/4"	18 in <sup>3</sup>	6 (three in, three out) #12 AWG
4O Round (non-metallic)	2 3/16"	20 in <sup>3</sup>	6 (three in, three out) #12 AWG

# DCD3

Higher-Lumen LED Module



 
- Radically simplifies configuration in the field
- Efficiently produces up to 3000 lm of superior lighting at 90+ CRI
- Wide range of interoperable lighting options including lumen, color temperature, and beam angle
- Integrated Twist & Lock driver for easy maintenance
- Connect the power and driver with a simple snap, no tools required

<b>Application</b> New Construction, Remodel	<b>Compatible Housings</b> DCD Frame	<b>Aperture</b> 4" Commercial
<b>Delivered Lumens</b> 1500 lm (20W), 2000 lm (28W), 2500 lm (37W), 3000 lm (40W)	<b>Input Voltage</b> 120/277V	<b>Dimming</b> 0-10V 1%, Lutron® Hi-lume® 1%
<b>Color Quality</b> 90+ CRI, 2-step SDCM	<b>Center Beam Candlepower</b> 17,500cd (Narrow Spot, 3000 lm)	
<b>Color Temperatures</b> 2700K 3000K 3500K 4000K	<b>Optics</b> NS (15°) S (25°) NF (35°) F (50°) WF (65°)	
<b>Specialty Lens Option</b> Hexcell Louver Linear Spread	<b>Emergency Lighting</b> Optional Emergency LED Driver for lighting up to 90 minutes in event of power failure	

**Standards**



**Ratings**



**Guarantee**

50,000 hrs | 5 years

**PRODUCT CODE**

PRODUCT	LUMENS	CRI	CCT	OPTICS	SPECIALTY LENS	DRIVER						
DCD3M	Module	9	90+ CRI	27	2700K	NS	Narrow Spot	[Blank]	None	[Blank]	Integrated 0-10V	
	20			2000 lm	30	3000K	SP	Spot	H	Hexcell Louver	A	Lutron Hi-lume and/or emergency
	25			2500 lm	35	3500K	NF	Narrow Flood				
	30			3000 lm	40	4000K	FL	Flood				
							WF	Wide Flood				
				LS	Linear Spread							

# DCD3

Higher-Lumen LED Module

DCD3  
COMPATIBLE HOUSINGS & TRIMS

## DCD Frame

DCD FRAME HOUSINGS & TRIMS



**DCDHNR4**  
New Construction




**DCDHNR4**  
New Construction, Alternate Dimming, and/or Emergency Driver




**DCDHRR4**  
Remodel




**DCDHRR4**  
Remodel, Alternate Dimming, and/or Emergency Driver

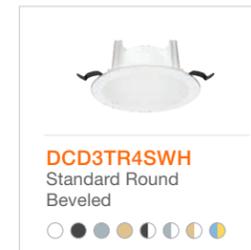


**DCD3TR4SWH**  
Standard Round Beveled

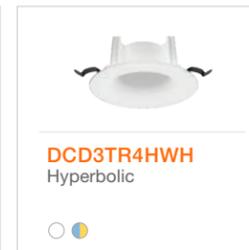

**DCD3TR4HWH**  
Hyperbolic

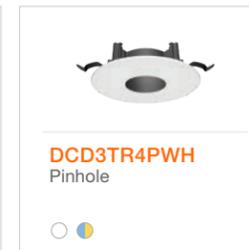

**DCD3TR4PWH**  
Pinhole

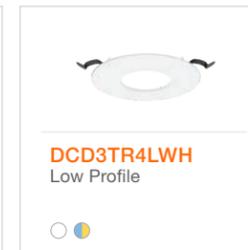


**DCD3TR4LWH**  
Low Profile




**DCD3TR4WWH**  
Wall Wash




**DCD3TR4SWHEM**  
Emergency

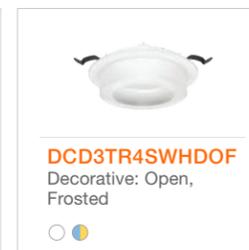


**DCD3TR4SWHDOF**  
Decorative: Open, Frosted

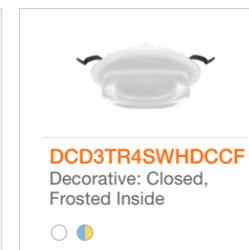

**DCD3TR4SWHDCCF**  
Decorative: Closed, Frosted Inside

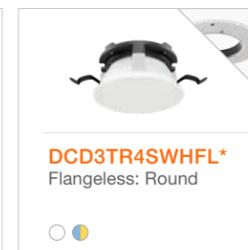


**DCD3TR4SWHFL\***  
Flangeless: Round

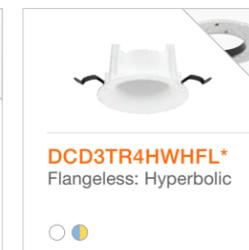


**DCD3TR4HWHFL\***  
Flangeless: Hyperbolic



**DCD3TR4PWHFL\***  
Flangeless: Pinhole

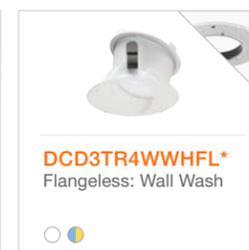

**DCD3TR4WWHFL\***  
Flangeless: Wall Wash

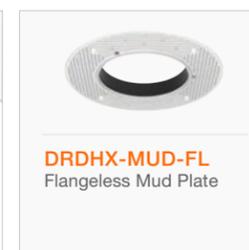

**DRDX-MUD-FL**  
Flangeless Mud Plate

**FINISH OPTIONS**

- White (WH)
- Black (BK)
- Clear Diffuse (CD)
- Warm Diffuse (WD)
- Black, White Flange (BW)
- Clear Diffuse, White Flange (CW)
- Warm Diffuse, White Flange (WW)
- Custom (CC)

 
\*Requires Flangeless Mud Plate

# DCD4

Adjustable Higher-Lumen LED Module



- Radically simplifies configuration in the field
- 360° rotation and 40° tilt for precise, aimable lighting
- Wide range of interoperable lighting options including lumen, color temperature, and beam angle
- Integrated Twist & Lock driver for easy maintenance
- Connect the power and driver with a simple snap, no tools required



<b>Application</b> New Construction, Remodel	<b>Compatible Housings</b> DCD Frame	<b>Aperture</b> 4" Commercial
<b>Delivered Lumens</b> 1500 lm (21W), 2000 lm (37W), 2500 lm (40W)	<b>Input Voltage</b> 120/277V	<b>Dimming</b> 0-10V 1%, Lutron® Hi-lume® 1%
<b>Color Quality</b> 90+ CRI, 2-step SDCM	<b>Center Beam Candlepower</b> 20,500cd (NS, 2500 lm)	
<b>Color Temperatures</b> 2700K 3000K 3500K 4000K	<b>Optics</b> NS (15°) S (25°) NF (35°) F (50°) WF (65°)	
<b>Specialty Lens Option</b> Hexcell Louver Linear Spread	<b>Adjustment</b> 360° directional aim, 40° tilt	
<b>Standards</b> ENERGY STAR LISTED	<b>Ratings</b> Damp location	<b>Guarantee</b> 50,000 hrs   5 years

## PRODUCT CODE

PRODUCT	LUMENS	CRI	CCT	OPTICS	SPECIALTY LENS	DRIVER							
DCD4M	Module	15	1500 lm	9	90+ CRI	27	2700K	NS	Narrow Spot	[Blank]	None	[Blank]	Integrated 0-10V
		20	2000 lm			30	3000K	SP	Spot	H	Hexcell Louver	A	Lutron Hi-lume
		25	2500 lm			35	3500K	NF	Narrow Flood				
						40	4000K	FL	Flood				
								WF	Wide Flood				
								LS	Linear Spread				

# DCD4

Adjustable Higher-Lumen LED Module

DCD4  
COMPATIBLE HOUSINGS & TRIMS

## DCD Frame

DCD FRAME HOUSINGS & TRIMS



 



\*Requires Flangeless Mud Plate

### FINISH OPTIONS

- White (WH)
- Black (BK)
- Clear Diffuse (CD)
- Warm Diffuse (WD)
- Black, White Flange (BW)
- Clear Diffuse, White Flange (CW)
- Warm Diffuse, White Flange (WW)
- Custom (CC)



- Customize your cylinder with over one million configurations
- Powered by DMF's advanced LED technology
- Modular Twist & Lock trims and Plug & Play light engines for easy maintenance and onsite modifications
- Shadowless pendant uplight allows for direct and indirect lighting from a single cylinder
- Die-cast aluminum with no visible hardware for a sleek, symmetrical design
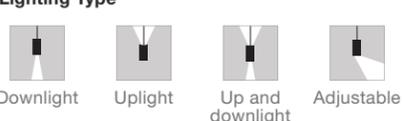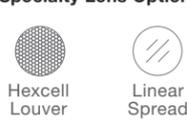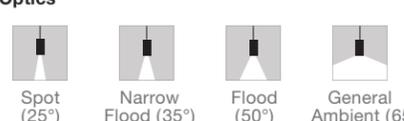
<b>Lumen Output</b> 750 lm (10W), 1000 lm (12W), 1500 lm (20W), 2000 lm (28W)		<b>Mount</b> Surface, Cord, Stem, Wall	
<b>Color Quality</b> 90+ CRI, 2-step SDCM		<b>Size</b> Length: Small (4"), Medium (8"), Large (12") Diameter: 4"	
<b>Color Temperature</b>  2700K 3000K 3500K 4000K		<b>Finish</b> White, Black, Brushed Aluminum, Bronze, Custom Color	
<b>Lighting Type</b>  Downlight Uplight Up and downlight Adjustable		<b>Stem/Cord Length</b> 24" or 48" (standard), Up to 96" (custom)	
<b>Input</b> 120/277V		<b>Dimming</b> TRIAC/ELV 5%, 0-10V 1%, Lutron Hi-lume® 1%	
<b>Specialty Lens Option</b>  Hexcell Louver Linear Spread		<b>Emergency Lighting</b> Optional Remote Inverter or Emergency LED Driver for lighting up to 90 minutes in event of power failure	
<b>Standards</b>  JA8 TIME 24 ENERGY STAR UL LISTED		<b>Warm Dim</b>  3000K - 1800K	
<b>Ratings</b>  Wet location available		<b>Guarantee</b> 50,000 hrs   5 years	
<b>Optics</b>  Spot (25°) Narrow Flood (35°) Flood (50°) General Ambient (65°)		<b>Trims and Shades</b> Round Beveled Trim, Hyperbolic Trim, Snoot, Decorative Trim, Low-Profile Decorative Trim, Round Shade, Flat Shade	


PRODUCT CODE

CYLINDER	DCC Cylinder			
MOUNT	<b>SM</b> Surface Mount <b>CC</b> Cord Mount, Custom <b>TC</b> Stem Mount, Custom	<b>C2</b> Cord Mount, 24" <b>T2</b> Stem Mount, 24" <b>WM</b> Wall Mount	<b>C4</b> Cord Mount, 48" <b>T4</b> Stem Mount, 48"	
CYLINDER OPTIONS	<b>S</b> Standard	<b>W</b> Wet Location		
SIZE	<b>S</b> Small	<b>M</b> Medium	<b>L</b> Large	
DIAMETER	4 4" Diameter			
LIGHT OPTIONS	<b>D</b> Down/Uplight	<b>A</b> Adjustable		
LUMENS DOWN	<b>07</b> 750 lm <b>15</b> 1500 lm	<b>10</b> 1000 lm <b>20</b> 2000 lm		
OPTICS DOWN	<b>G</b> General Ambient <b>F</b> Flood	<b>S</b> Spot <b>L</b> Linear Spread	<b>N</b> Narrow Flood	
SPECIALTY LENS DOWN	<b>0</b> None	<b>H</b> Hexcell		
LUMENS UP	<b>00</b> None <b>10</b> 1000 lm	<b>07</b> 750 lm <b>15</b> 1500 lm		
OPTICS UP	<b>0</b> None <b>N</b> Narrow Flood	<b>G</b> General <b>F</b> Flood	<b>S</b> Spot	
CCT	<b>27</b> 2700K <b>40</b> 4000K	<b>30</b> 3000K <b>3W</b> Warm Dim	<b>35</b> 3500K	
FINISH	<b>W</b> White <b>Z</b> Bronze	<b>B</b> Black <b>C</b> Custom Color	<b>A</b> Brushed Aluminum	
DRIVER	<b>T</b> TRIAC/ELV <b>L</b> Lutron LTEA2W	<b>O</b> 0-10V	<b>C</b> Lutron LDE1	
SPECIALTY OPTIONS	<b>00</b> None	<b>E1</b> EM, Remote Test Switch		
TRIM SHADE	<b>R</b> Round Beveled Trim <b>L</b> Low Profile Decorative Trim <b>RBW</b> Round Shade: Black, Warm <b>FWW</b> Flat Shade: White, Warm <b>FCC</b> Flat Shade: Custom Color	<b>H</b> Hyperbolic Trim <b>RWC</b> Round Shade: White, Clear <b>RAC</b> Round Shade: Aluminum, Clear <b>FBC</b> Flat Shade: Black, Clear	<b>S</b> Snoot <b>RWW</b> Round Shade: White, Warm <b>RCC</b> Round Shade: Custom Color <b>FBW</b> Flat Shade: Black, Warm	<b>D</b> Decorative Trim <b>RBC</b> Round Shade: Black, Clear <b>FWC</b> Flat Shade: White, Clear <b>FBW</b> Flat Shade: Black, Warm

ACCESSORIES

<b>DCCX-CC</b>	Custom Length Cord Mount (up to 96")
<b>DCCX-TC</b>	Custom Length Stem Mount (up to 96")
<b>DCCX-RW</b>	Round Beveled Trim, White
<b>DCCX-RB</b>	Round Beveled Trim, Black
<b>DCCX-RA</b>	Round Beveled Trim, Brushed Aluminum
<b>DCCX-RZ</b>	Round Beveled Trim, Bronze
<b>DCCX-RC</b>	Round Beveled Trim, Custom
<b>DCCX-HW</b>	Hyperbolic Trim, White
<b>DCCX-HB</b>	Hyperbolic Trim, Black
<b>DCCX-HA</b>	Hyperbolic Trim, Brushed Aluminum
<b>DCCX-HZ</b>	Hyperbolic Trim, Bronze
<b>DCCX-HC</b>	Hyperbolic Trim, Custom
<b>DCCX-S</b>	Snoot
<b>DCCX-D</b>	Decorative Trim

<b>DCCX-L</b>	Low-Profile Decorative Trim
<b>DCCX-RWC</b>	Round Shade: White Outside, Clear Diffused Inside
<b>DCCX-RWW</b>	Round Shade: White Outside, Warm Diffused Inside
<b>DCCX-RBC</b>	Round Shade: Black Outside, Clear Diffused Inside
<b>DCCX-RBW</b>	Round Shade: Black Outside, Warm Diffused Inside
<b>DCCX-RAC</b>	Round Shade: Brushed Aluminum Outside, Clear Diffused Inside
<b>DCCX-RCC</b>	Round Shade: Custom Color
<b>DCCX-FWC</b>	Flat Shade: White Outside, Clear Diffused Inside
<b>DCCX-FWW</b>	Flat Shade: White Outside, Warm Diffused Inside
<b>DCCX-FBC</b>	Flat Shade: Black Outside, Clear Diffused Inside
<b>DCCX-FBW</b>	Flat Shade: Black Outside, Warm Diffused Inside
<b>DCCX-FAC</b>	Flat Shade: Brushed Aluminum Outside, Clear Diffused Inside
<b>DCCX-FCC</b>	Flat Shade: Custom Color

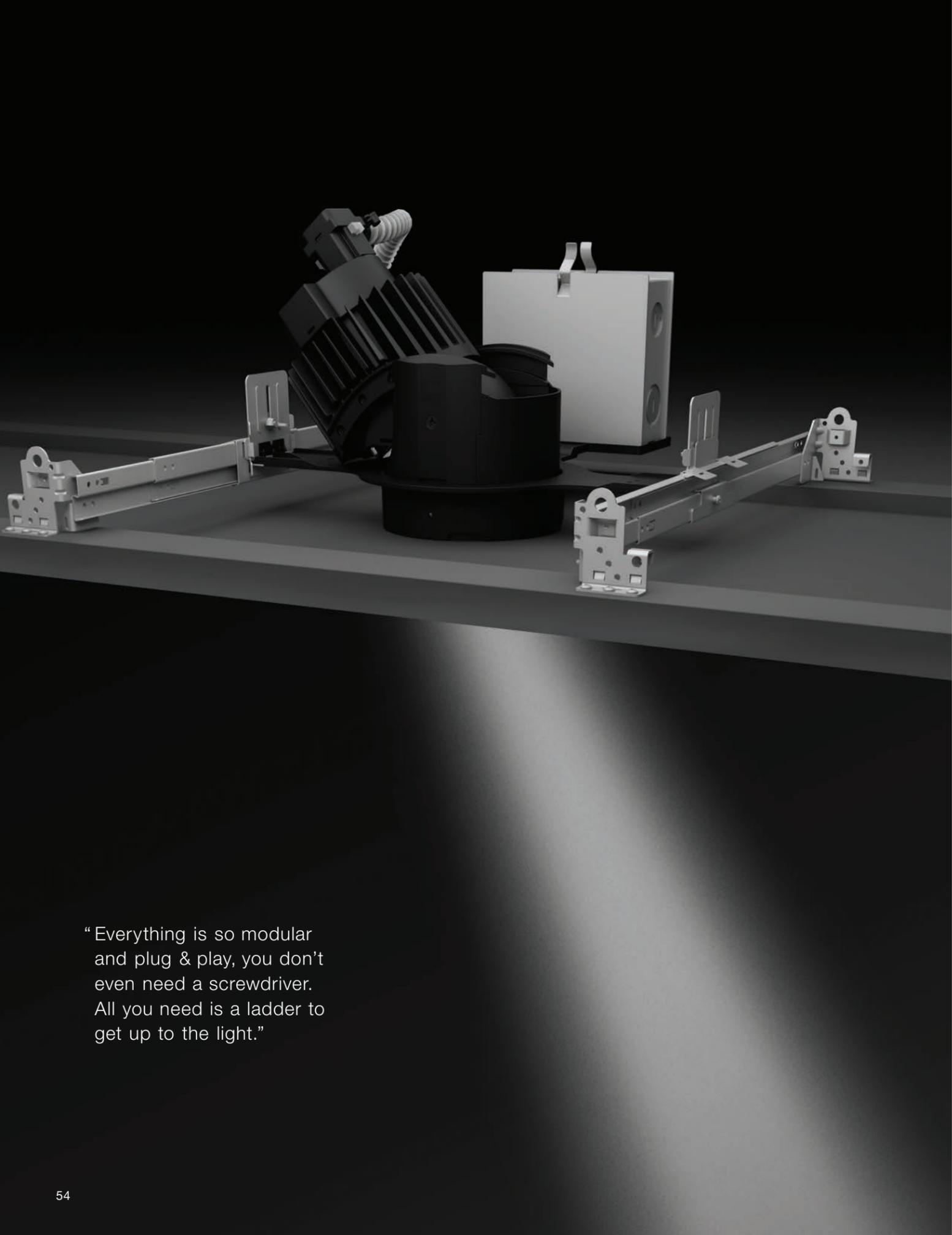

“Everything is so modular and plug & play, you don't even need a screwdriver. All you need is a ladder to get up to the light.”

## Brilliance engineered

Our in-house R&D lab is filled with brilliant engineers always at work improving our products and inventing new ones. They understand that light is more than illumination, it's what makes a space beautiful, useful, and ultimately, livable.

DMF engineers create products that deliver exceptional performance and aesthetics, while also saving you time and money year after year. That same ethos animates every part of our company, from our tireless customer service to our fast, intelligent distribution.

If you want lighting that's not just built better, but built smarter, DMF is the lighting partner for you.

# Module Comparison



**DRD2**  
General



**DRD2X**  
Apex Series



**DRD3**  
Adjustable



**DRD4**  
Adjustable



**DRD5S**  
Surface Mount Series



**DCD3**  
Higher-Lumen









**DCD4**  
Adjustable Higher-Lumen



**LD2**  
2" LED

	<b>DRD2</b> General	<b>DRD2X</b> Apex Series	<b>DRD3</b> Adjustable	<b>DRD4</b> Adjustable	<b>DRD5S</b> Surface Mount Series	<b>DCD3</b> Higher-Lumen	<b>DCD4</b> Adjustable Higher-Lumen	<b>LD2</b> 2" LED
<b>Application</b>	New Construction, Remodel, Retrofit	New Construction, Remodel, Retrofit	New Construction, Remodel, Retrofit	New Construction	New Construction, Retrofit	New Construction, Remodel	New Construction, Remodel	New Construction, Remodel
<b>Housing</b>	OneFrame; SquareFrame; SurfaceFrame; Classic Frames 4", 5", 6", 8"; Surface Mount; Junction Box	OneFrame; SquareFrame; SurfaceFrame; Classic Frames 4", 5", 6", 8"; Surface Mount; Junction Box	Classic Frames: 4", 5", 6"	OneFrame; SquareFrame	SurfaceFrame, Metallic Octagonal, or Non-Metallic Round Junction Box	DCD Frame	DCD Frame	LD2NCI, LD2NCN
<b>Adjustment</b>	-	-	360° directional aim, 40° tilt	360° directional aim, 45° tilt	-	-	360° directional aim, 40° tilt	-
<b>Delivered Lumens</b>	750 lm (10.8W), 1000 lm (12.8W)	600 lm (10.0W), 750 lm (12.5W)	750 lm (12.0W), 1000 lm (14.7W)	750 lm (9.7W), 1000 lm (12.0W)	4": 750 lm (9.0W), 1000 lm (12.0W) 8" / 18": 1500 lm (17.0W)	1500 lm (20W), 2000 lm (28W), 2500 lm (37W), 3000 lm (40W)	1500 lm (21W), 2000 lm (37W), 2500 lm (40W)	900 lm (16.6W)
<b>Efficacy</b>	69 lm/W, 78 lm/W	60 lm/W	63 lm/W, 68 lm/W	67 lm/W	83 lm/W	86 lm/W, 79 lm/W, 72 lm/W, 82 lm/W	70 lm/W, 60 lm/W, 67 lm/W	54 lm/W
<b>Color Quality</b>	93+ CRI, 2-step SDCM	90+ CRI, 2-step SDCM	90+ CRI, 2-step SDCM	90+ CRI, 2-step SDCM	90+ CRI, < 3-step SDCM	90+ CRI, 2-step SDCM	90+ CRI, 2-step SDCM	90+ CRI, 2-step SDCM
<b>Color Temperature</b>	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K, 4000K	2700K, 3000K, 3500K, 4000K
<b>Warm Dim</b>	3000K - 1800K, 800 lm (12.0W)	3000K - 1800K, 600 lm (12.0W)	-	3000K - 1800K, 800 lm (12.0W)	-	-	-	-
<b>Optics</b>	Flood	Spot (20°), Narrow Flood (30°), Flood (40°)	Spot (23°), Flood (42°)	Spot (20°), Narrow Flood (30°), Flood (40°)	Flood	Narrow Spot (15°), Spot (25°), Narrow Flood (35°), Flood (50°), Wide Flood (65°)	Narrow Spot (15°), Spot (25°), Narrow Flood (35°), Flood (50°), Wide Flood (65°)	Spot (13°), Narrow Flood (28°), Flood (45°)
<b>Options</b>	-	White, Black Surround	White, Black, Custom Finish	Hexcell Louver, Linear Spread, Black, White Surround	4" Round, 4" Square, 8" Round, 18" Linear	Hexcell Louver, Linear Spread	Hexcell Louver, Linear Spread	-
<b>Center Beam Candlepower</b>	-	4000cd (Spot 750 lm)	3000cd (Spot 1000 lm)	6000cd (Spot 800 lm)	-	18,500cd (Narrow Spot 3000 lm)	20,500cd (Narrow Spot, 2500 lm)	-
<b>Input Voltage</b>	120/277V	120/277V	120/277V	120/277V	120/277V	120/277V	120/277V	120/277V
<b>Dimming</b>	TRIAC/ELV 5%, 0-10V 1%, Lutron® Hi-lume® 1%	TRIAC/ELV 5%, 0-10V 1%, Lutron® Hi-lume® 1%	TRIAC/ELV 5%, 0-10V 1%, Lutron® Hi-lume® 1%	TRIAC/ELV 5%, 0-10V 1%, Lutron® Hi-lume® 1%	TRIAC/ELV 5%, 0-10V 1%	0-10V 1%, Lutron® Hi-lume® 1%	0-10V 1%, Lutron® Hi-lume® 1%	TRIAC/ELV 5%, 0-10V 1%
<b>Emergency Lighting</b>	Optional Emergency Driver	Optional Emergency Driver	Optional Emergency Driver	Optional Emergency Driver	Optional Emergency Driver	Optional Emergency Driver	-	-
<b>Standards</b>	JA8 Title 24, cULus Listed, Energy Star	JA8 Title 24, cULus Listed, Energy Star	JA8 Title 24, cULus Listed, Energy Star	JA8 Title 24, cULus Listed, Energy Star	JA8 Title 24, cULus Listed, Energy Star	cULus Listed, Energy Star	cULus Listed, Energy Star	JA8 Title 24, cULus Listed, Energy Star
<b>Ratings</b>	Wet location	Wet location	Damp location	Damp location	Wet location	Wet location	Damp location	Wet location available
<b>Lifetime (L70)</b>	50,000 hrs	50,000 hrs	50,000 hrs	50,000 hrs	50,000 hrs	50,000 hrs	50,000 hrs	50,000 hrs
<b>Warranty</b>	5 years	5 years	5 years	5 years	5 years	5 years	5 years	5 years

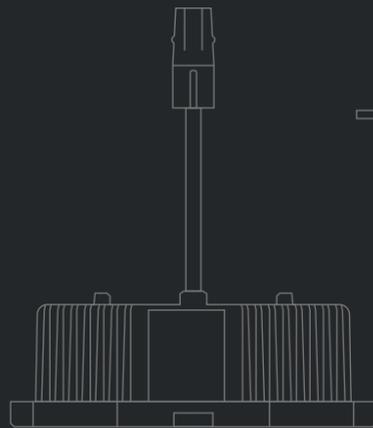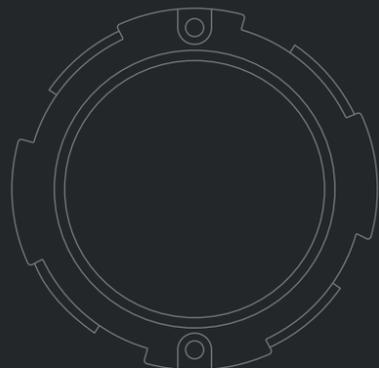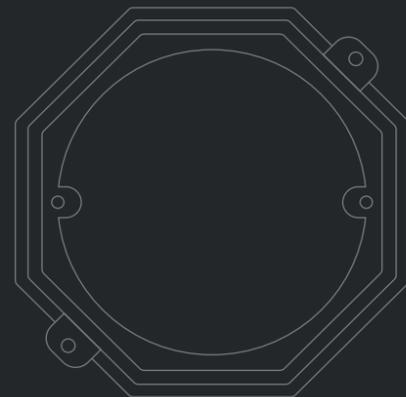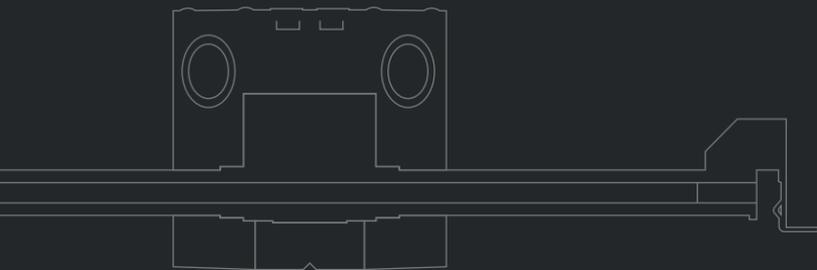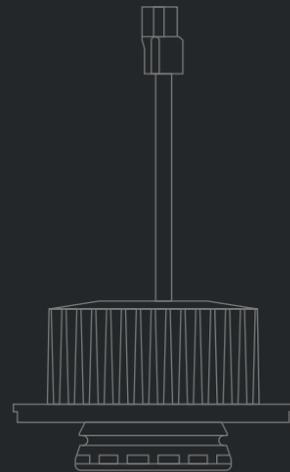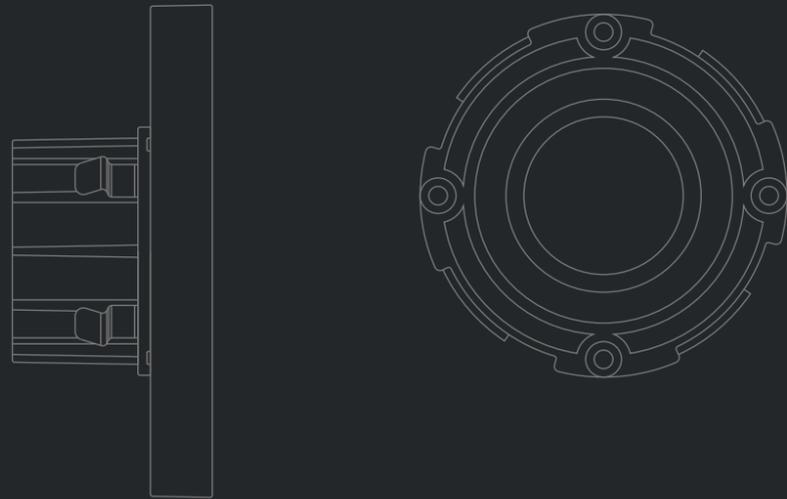

DMF Lighting  
1118 East 223rd Street,  
Carson, California 90745  
800.441.4422  
info@dmflighting.com  
dmflighting.com

© 2019 DMF Lighting. All Rights Reserved. Specifications subject to change without notice.  
MDMFGUIDE V-11.01.19

