



High Performance | Architectural | Lighting Solutions

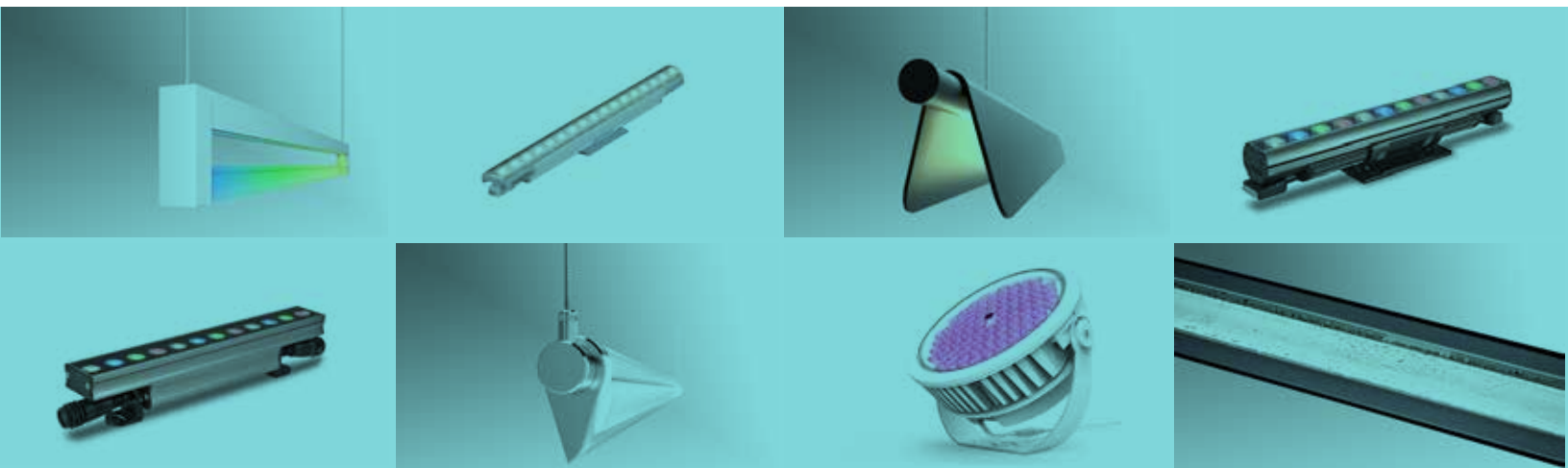

2020 I D E A B O O K

SPACE

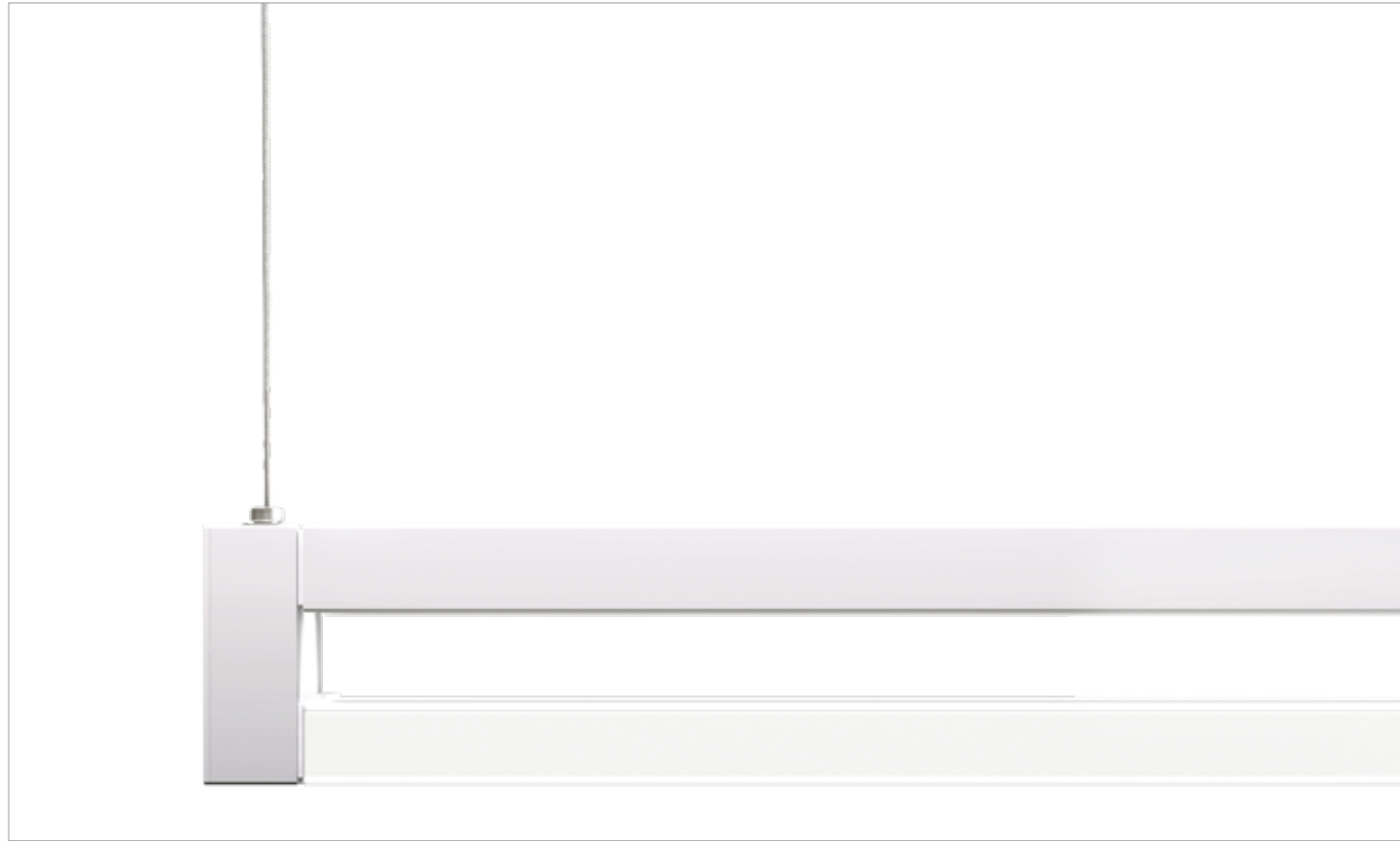

A re-imagining of the traditional linear fixture. Space balances light, dark, and the open air to create an extraordinary lighting tool.

OVERVIEW

A LINEAR LIGHTING SYSTEM THAT USES AN INNOVATIVE OPTICAL APPROACH TO CREATE NEGATIVE SPACE AS A VISUAL ELEMENT

WATTAGES

UP TO 12W/FT DIRECT/INDIRECT

CCT

2700K, 3000, 3500, 4000K, RGBW AND ACTIVE WHITE

FIXTURE SIZES




24" - 96"

CERTIFICATIONS

ETL AND CETL APPROVED FOR DRY LOCATION



2019
WINNER
LIGHTING
DESIGN
AWARDS

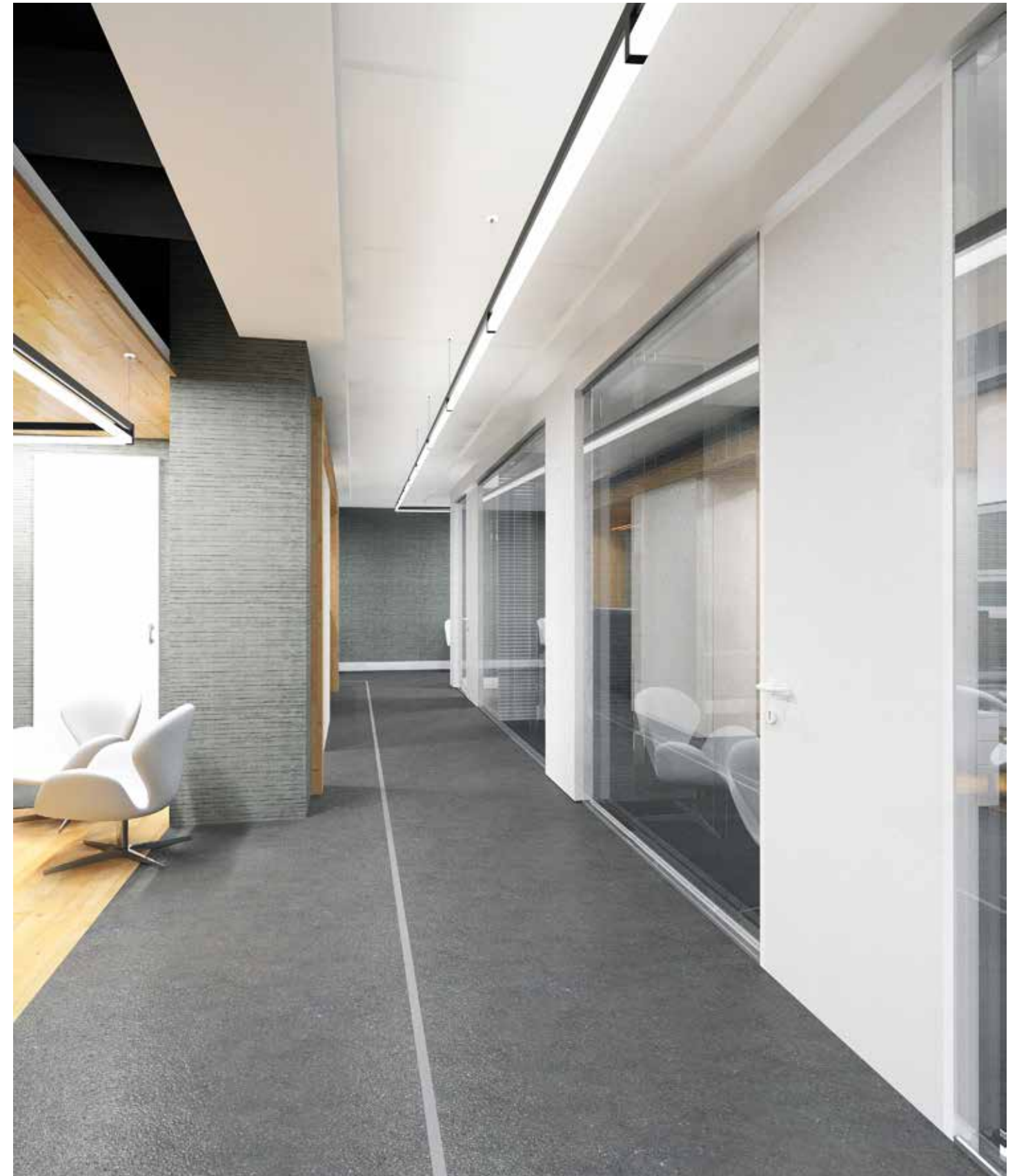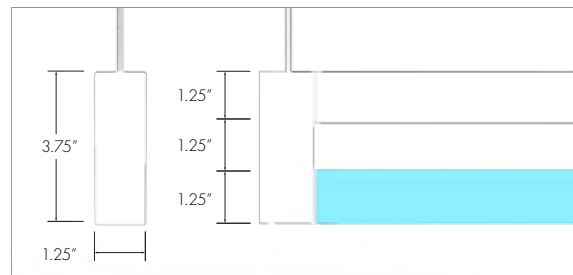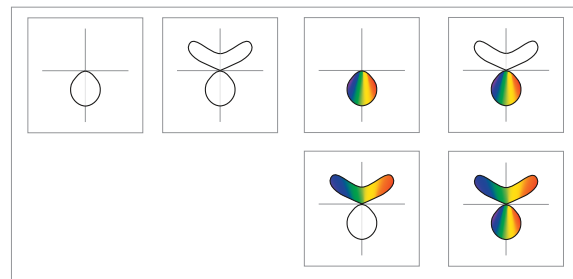

ADOBE



A versatile pendant light inspired by the simple forms of adobe architecture, crafted and manufactured with pride in New Mexico.



OVERVIEW

ARCHITECTURAL DIRECT AND INDIRECT LINEAR LIGHTING

WATTAGES

3.5W/FT, 7W/FT, 11W/FT

CCT

2700K, 3000K, 3500K, 4000K

FIXTURE LENGTHS

34", 46", 58"

MOUNTING




POWERED SUSPENSION CABLES

DIMMING

0-10V AND LUTRON HI-LUME ECOSYSTEM

CERTIFICATIONS

ETL AND CETL APPROVED FOR DRY LOCATION

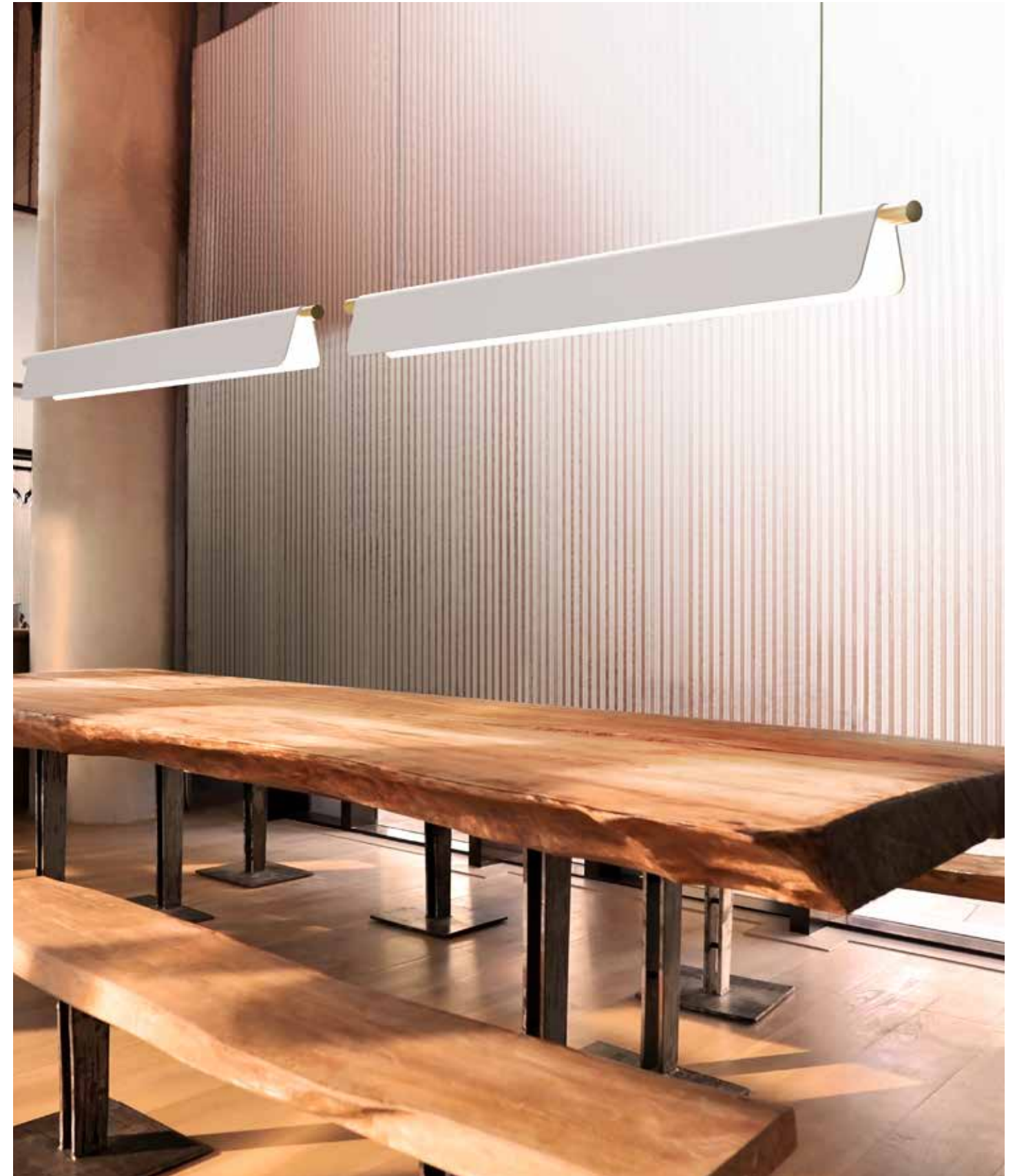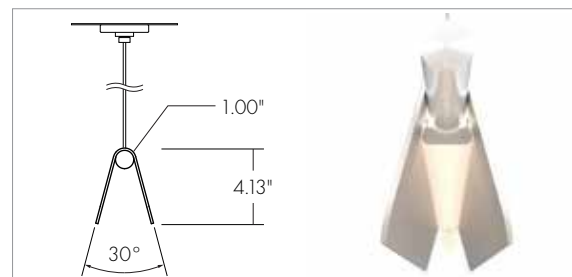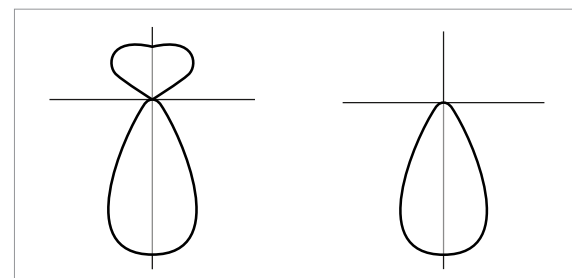

C5X



An ultra-compact wall wash fixture available in a variety of mounting configurations designed to fit seamlessly into any environment.

OVERVIEW

ULTRA COMPACT WALL WASH

WATTAGES

3.5W/FT, 9W/FT, 17W/FT

CCT

2700K, 3000K, 3500K, 4000K

FIXTURE LENGTHS

24", 36", 48", 60", 72", 96" AND CONTINUOUS RUNS

MOUNTING




SURFACE, EXTENDED ARM, PENDANT, POWERED SUSPENSION CABLES

DIMMING

0-10V AND LUTRON HI-LUME ECOSYSTEM

CERTIFICATIONS



ETL AND CETL APPROVED FOR DRY LOCATION

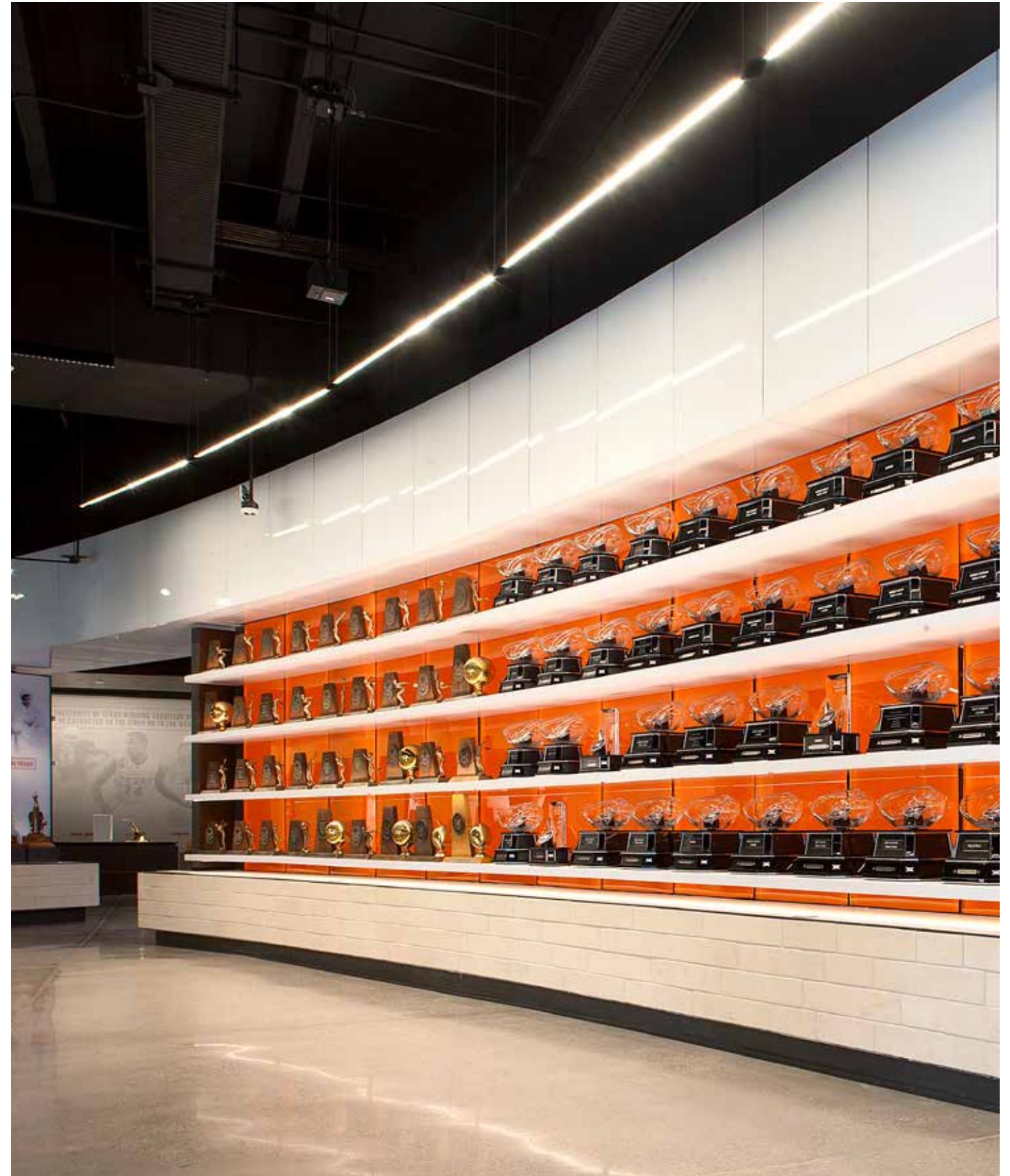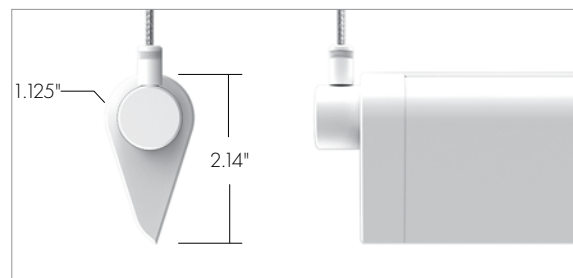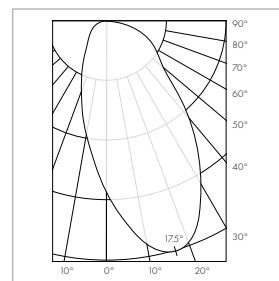

D2 SERIES



Ideal for interior and exterior applications with high ceilings such as lobbies, libraries natatoriums or atrium spaces.

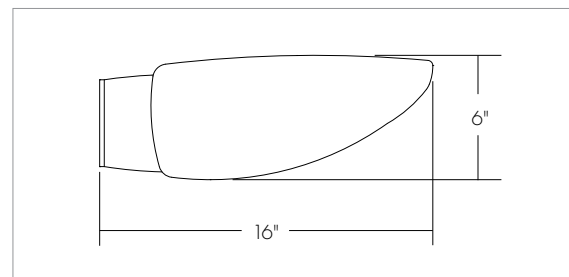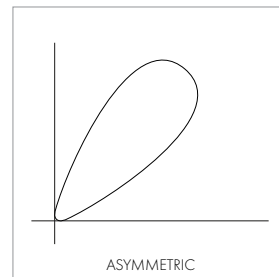

OVERVIEW

HIGH PERFORMANCE ASYMMETRIC INDIRECT LED LUMINAIRE FOR INTERIOR AND EXTERIOR USE

WATTAGES

60W, 100W, 150W, 200W, 300W & 380 IN TWO LOW PROFILE HOUSING SIZES

CCT

2700K, 3000K, 3500K, 4000K

POWER

INTEGRAL POWER SUPPLY (LINE VOLTAGE, 120V - 277V)

MOUNTING


WALL AND PENDANT

DIMMING

0-10V

CERTIFICATIONS

D2X: ETL /CETL APPROVED FOR WET LOCATION,
D2I: ETL AND CETL APPROVED FOR DAMP LOCATION

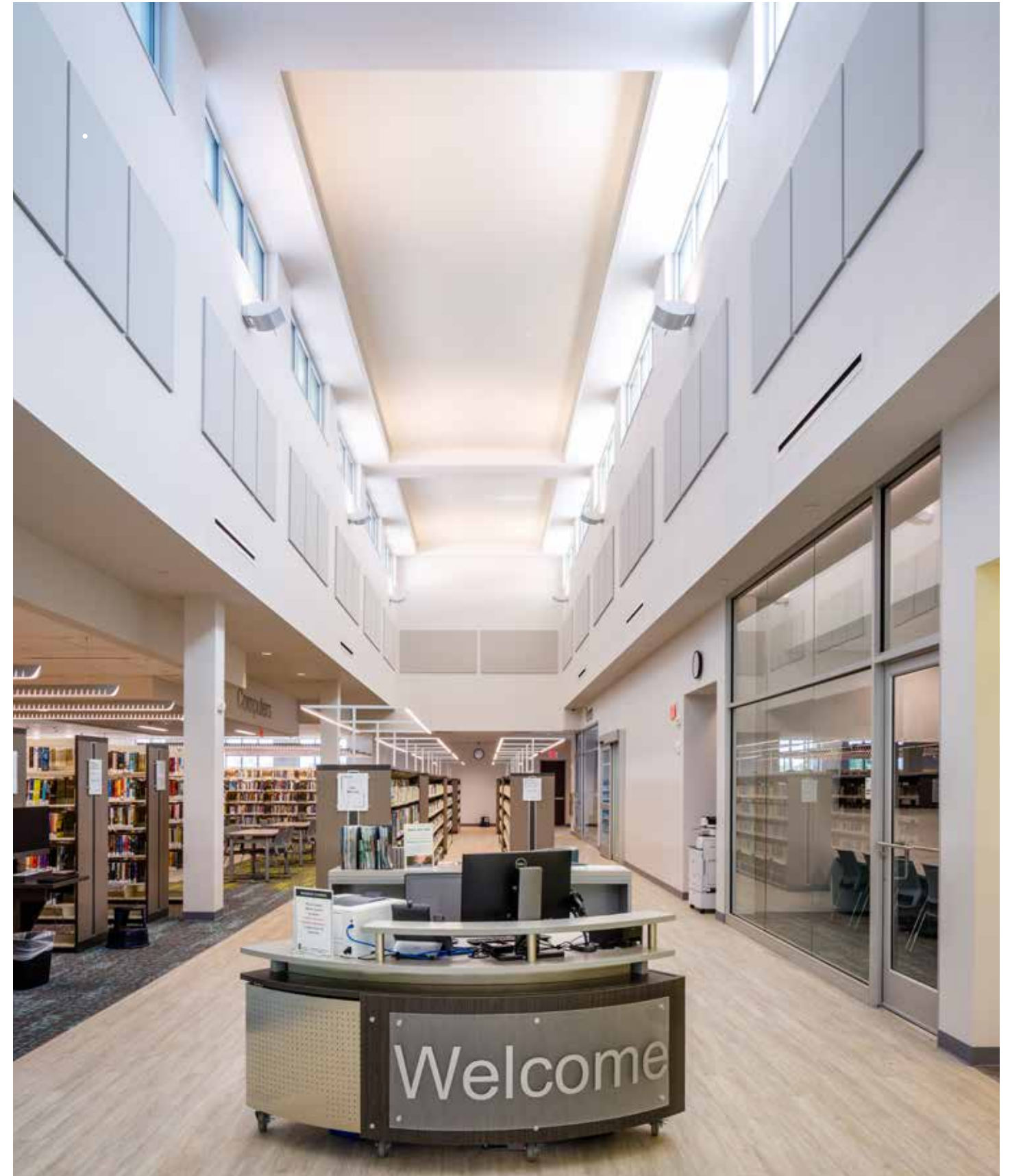

MEDLEY A



Designed for today's energy-efficient environments, Medley A has enough design elements to compliment any interior.

OVERVIEW

INTERIOR LINEAR ARCHITECTURAL LIGHTING (INTEGRAL POWER SUPPLY)

WATTAGES

3.5W/FT, 9W/FT, 17W/FT

CCT

2700K, 3000K, 3500K, 4000K, TUNABLE AND COLOR CHANGING

FIXTURE LENGTHS

24" - 96"

MOUNTING




SURFACE, AIRCRAFT CABLE, PENDANT AND EXTENDED ARM

DIMMING

0-10V AND DMX DIMMING

CERTIFICATIONS

ETL AND CETL APPROVED FOR DRY LOCATION

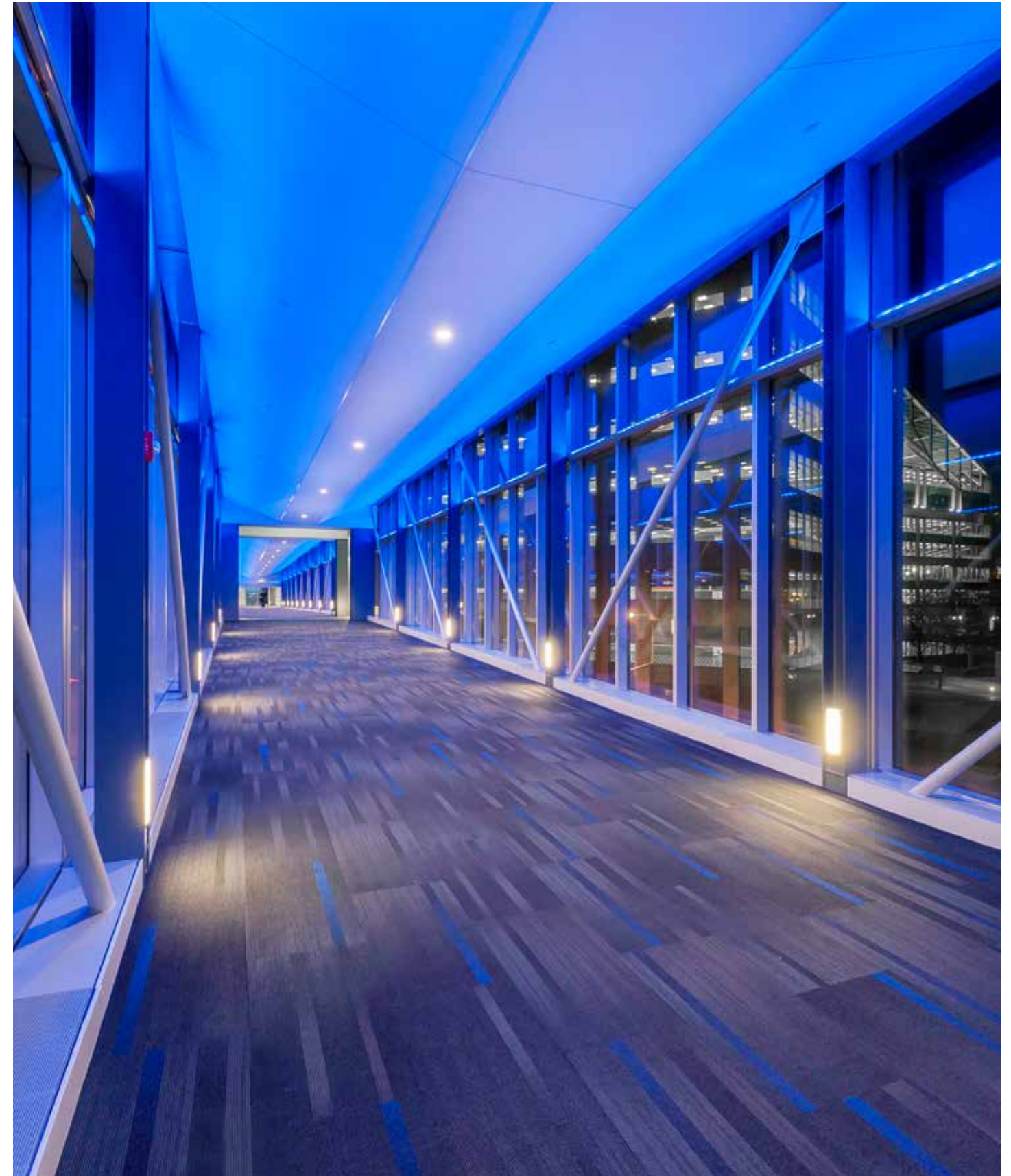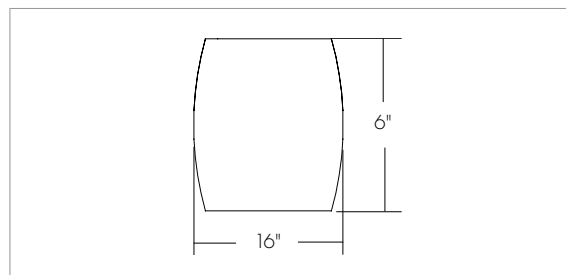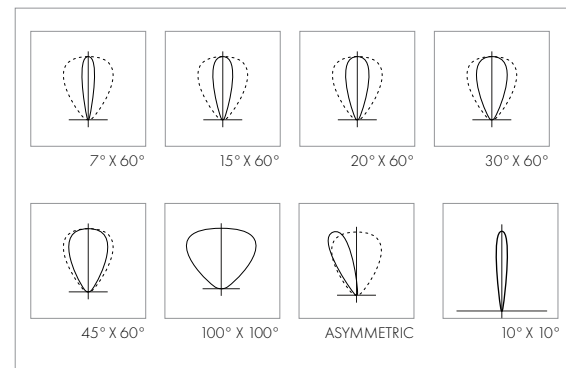

MEDLEY VIEW II



Medley View II's powerful LED engines coupled with Insight's precision optics, allow you to bathe your building in a warm glow.

OVERVIEW

EXTERIOR LINEAR ARCHITECTURAL LIGHTING (INTEGRAL POWER SUPPLY)

WATTAGES

3.5W/FT, 9W/FT, 17W/FT

CCT

2700K, 3000K, 3500K, 4000K, KELVIN TUNABLE AND COLOR CHANGING

FIXTURE LENGTHS

24" - 96"

MOUNTING



SURFACE AND EXTENDED ARM MOUNTINGS WITH PLUG AND PLAY CONNECTION

DIMMING

0-10V, DMX DALI AND LUTRON HI-LUME

CERTIFICATIONS

TESTED TO ANSI STANDARDS FOR 3G VIBRATION TESTING, IK07 IMPACT TESTING, IP67 RATED FOR EXTREME OUTDOOR ENVIRONMENTS

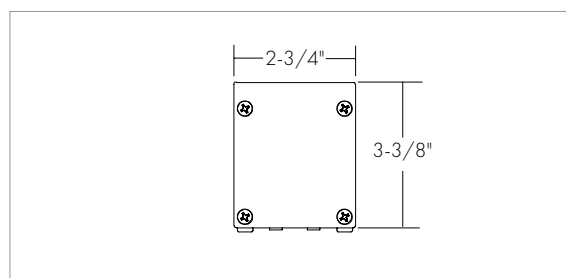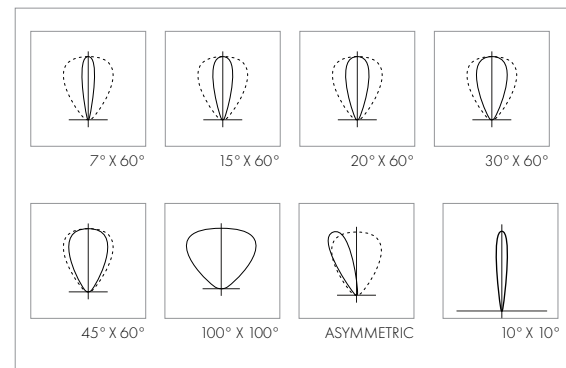

MEDLEY X



Medley-X has a unique architectural styling with a visor shielding built in to the fixture design.

OVERVIEW

EXTERIOR ARCHITECTURAL LINEAR LIGHTING (REMOTE POWER SUPPLY)

WATTAGES

3.5W/FT, 9W/FT, 17W/FT

CCT

2700K, 3000K, 3500K, 4000K, KELVIN TUNABLE AND COLOR CHANGING

FIXTURE LENGTHS

24" - 96"

MOUNTING




SURFACE, EXTENDED ARM AND PENDANT

DIMMING

0-10V AND DMX DIMMING

CERTIFICATIONS

IP67 RATED FOR EXTREME OUTDOOR ENVIRONMENTS

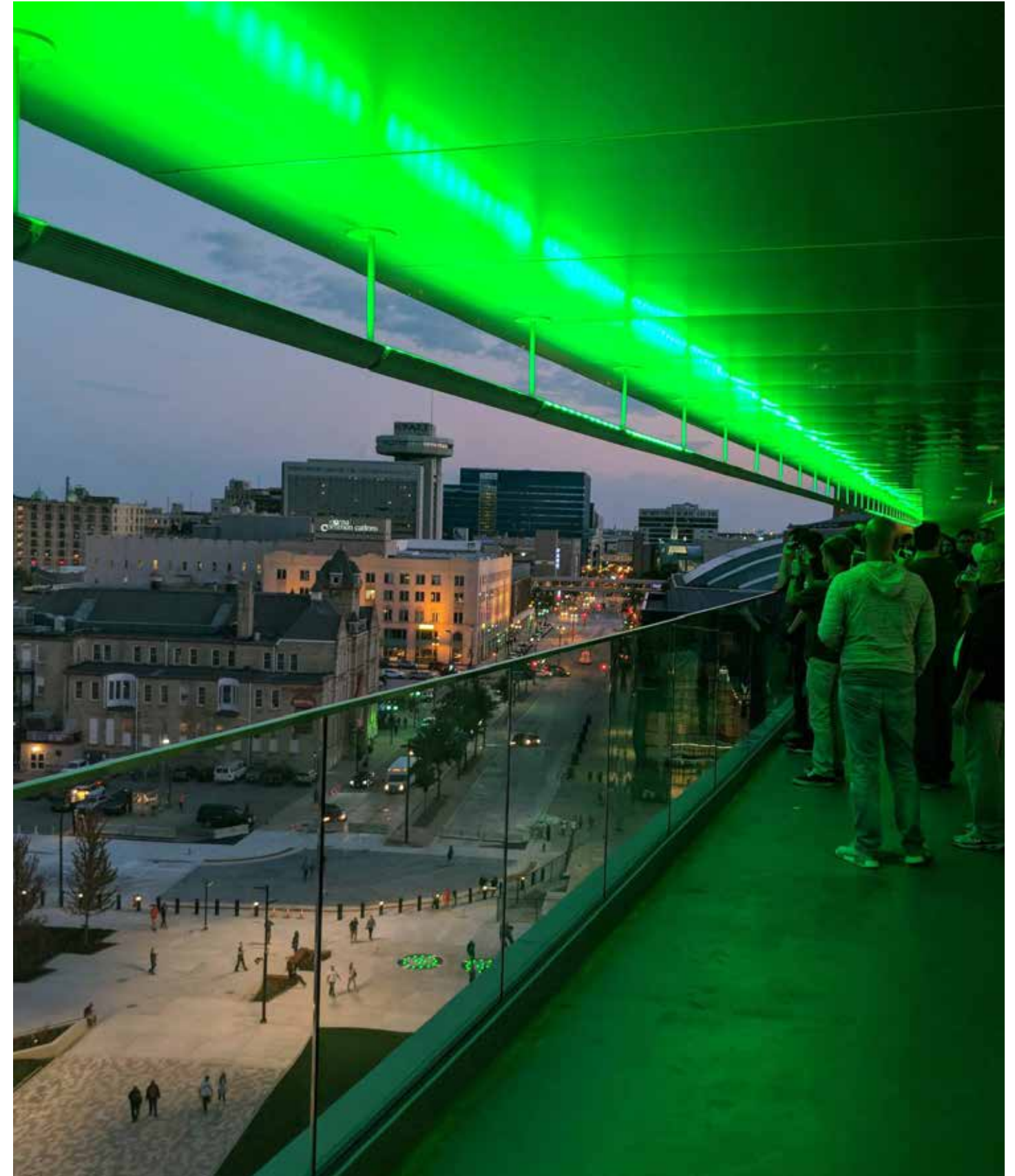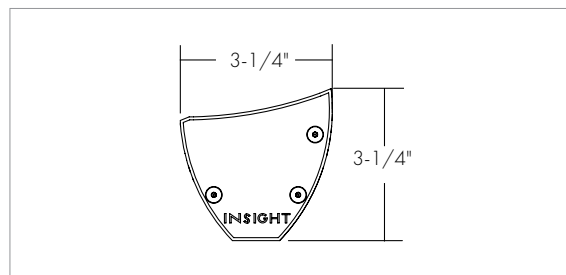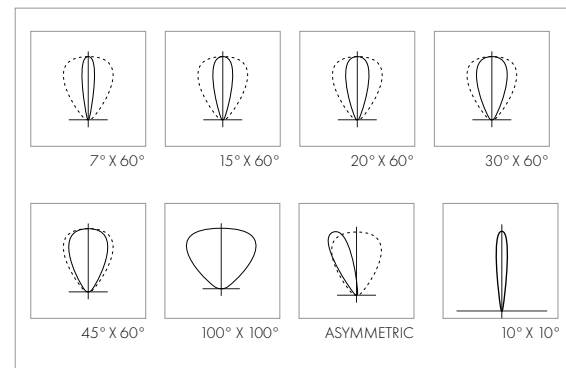

MEDLEY XI



MXi is a simple stand-alone sealed enclosure ideal to fit into small niches or exterior pockets.

OVERVIEW

EXTERIOR LOW PROFILE LINEAR LIGHTING (REMOTE POWER SUPPLY)

WATTAGES

3.5W/FT, 9W/FT, 17W/FT

CCT

2700K, 3000K, 3500K, 4000K, TUNABLE AND COLOR CHANGING

FIXTURE LENGTHS

24" - 96"

MOUNTING




SURFACE

DIMMING


0-10V AND DMX DIMMING

CERTIFICATIONS

IP67 RATED FOR EXTREME OUTDOOR ENVIRONMENTS

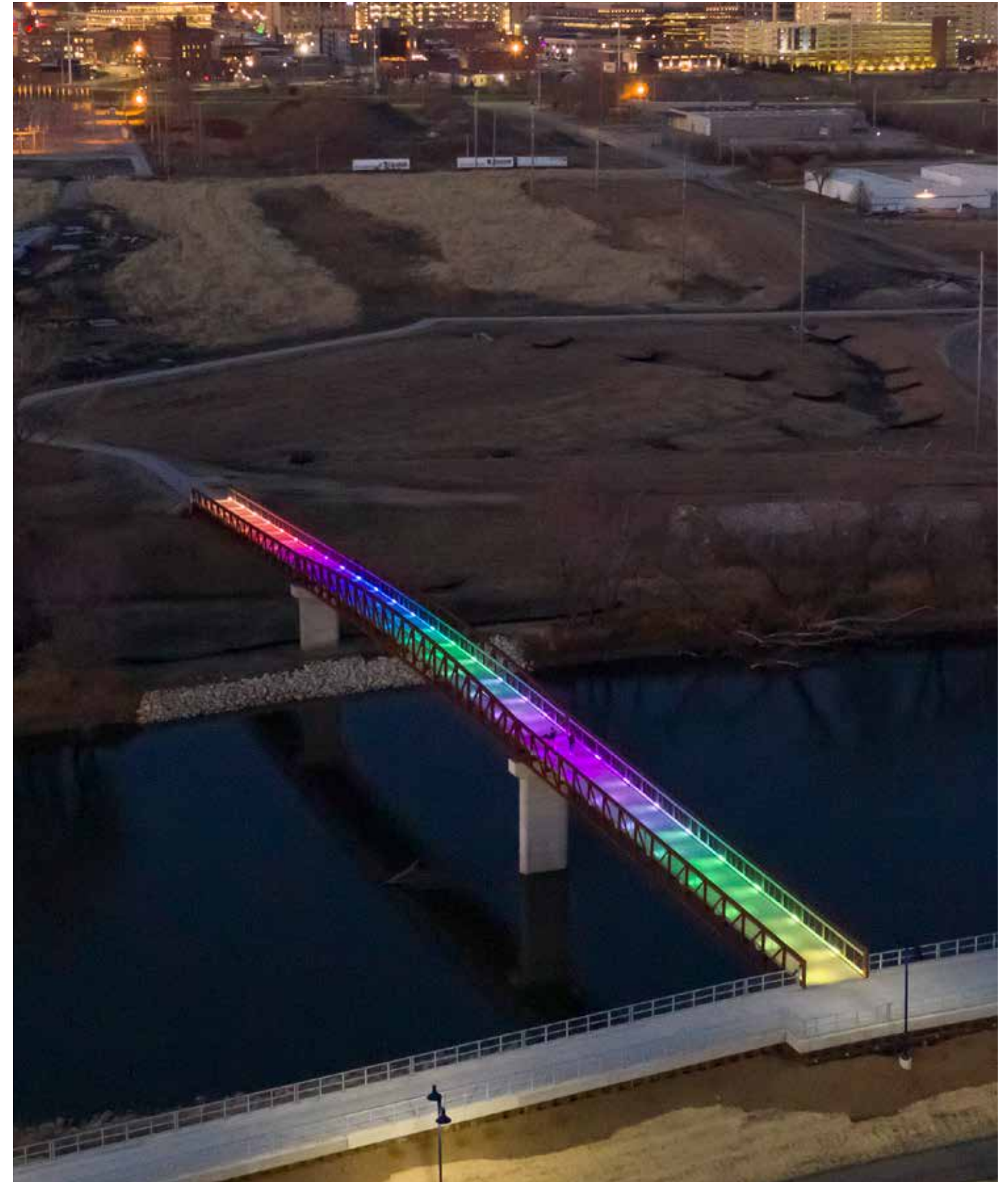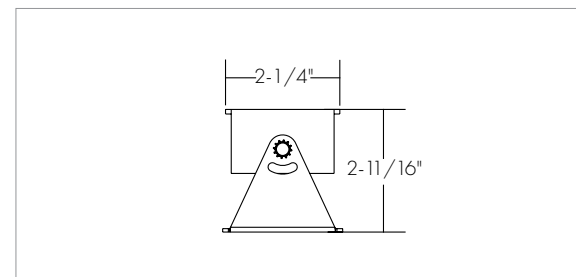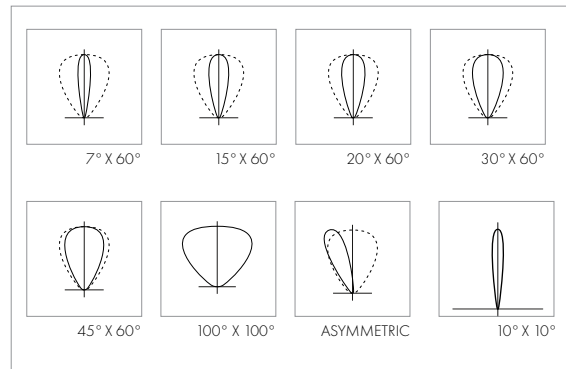

MEDLEY INGRADE

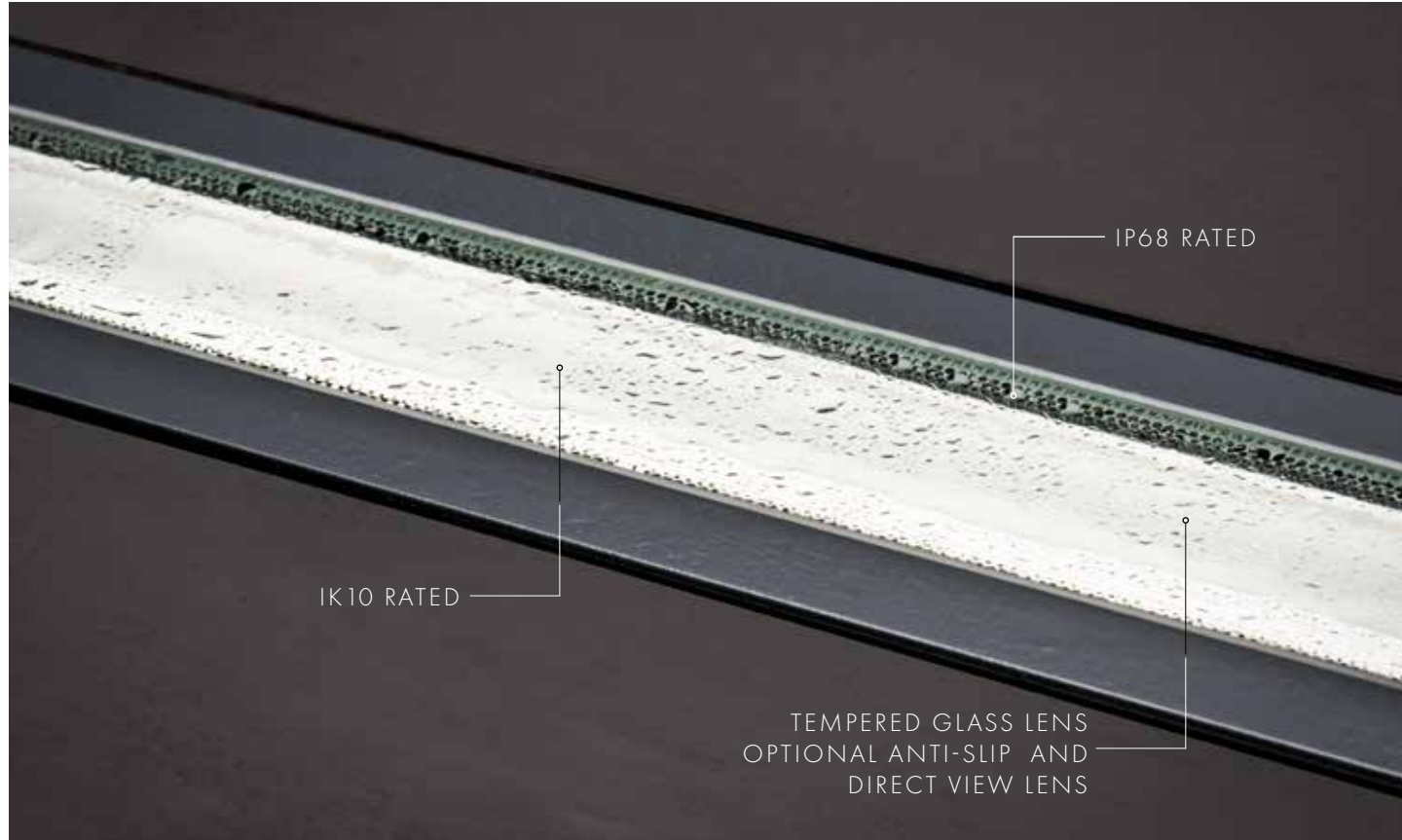

A patented LED linear ingrade luminaire featuring a unique snap-in optical system. Available in lengths of 12", 24", 36", 48". A wide selection of optics and two new high performance asymmetric wallwash distributions.

OVERVIEW

HIGH PERFORMANCE INGRADE LUMINAIRE

WATTAGES

3.5W/FT, 7W/FT, 11W/FT, 15W/FT

CCT

2700K, 3000K, 3500K, 4000K AND COLOR CHANGING

FIXTURE LENGTHS

12", 24", 36", 48"

MOUNTING




INGRADE (IN CONCRETE)

DIMMING

0-10V AND DMX

CERTIFICATIONS

IP68 RATED AND IK10 RATED

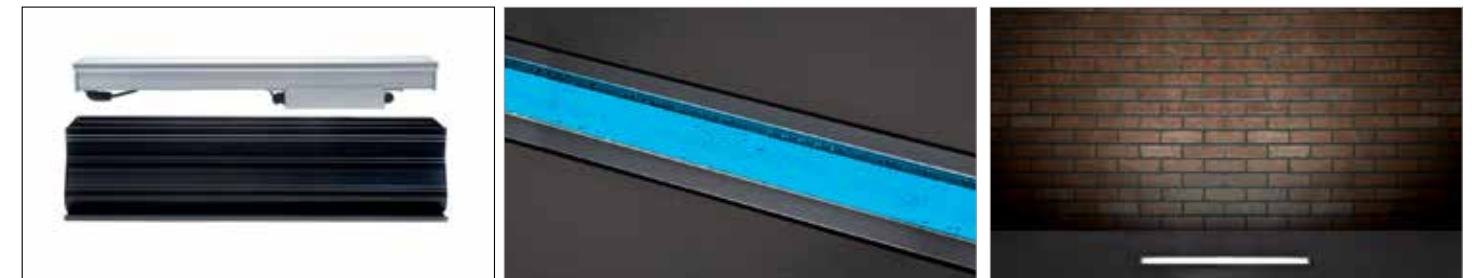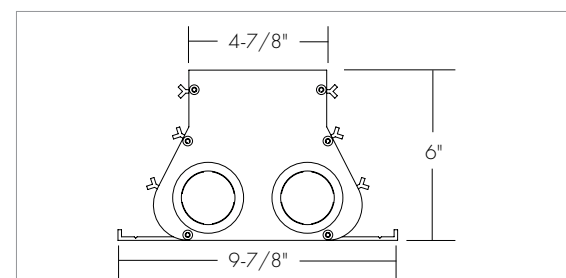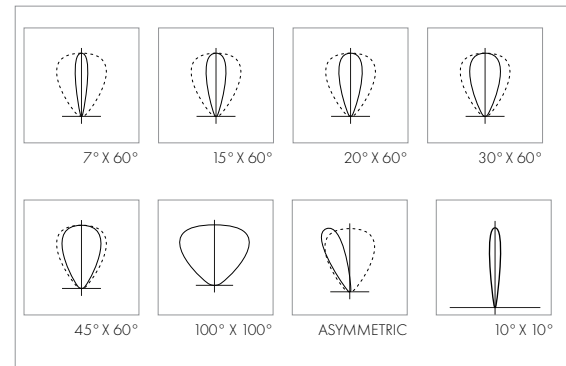

PILOT PCM



Pilot PCM is an AC plug and play cove lighting product that offers high lumen performance at our most competitive price point ever. Offered in CCTs of 2700K, 3000K, 3500K, and 4000K.

OVERVIEW

HIGH PERFORMANCE AC PLUG AND PLAY COVE LIGHTING

WATTAGES

3.5W/FT, 5W/FT, 7W/FT, 10W/FT, 13W/FT

CCT

2700K, 3000K, 3500K, 4000K AND STATIC RED, GREEN, BLUE, GREEN

FIXTURE LENGTHS



12", 48"

DIMMING

0-10V IS STANDARD

CERTIFICATIONS

ETL LISTED FOR DAMP/DRY LOCATIONS

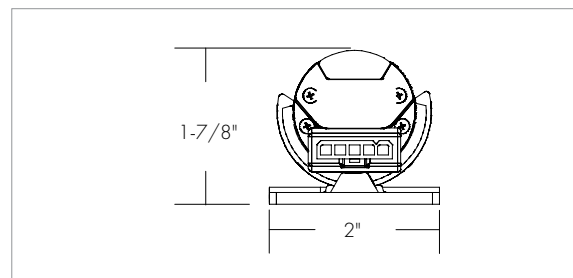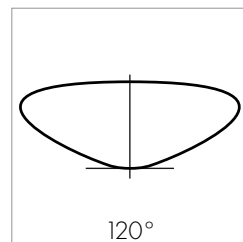

PILOT PGM



Pilot PGM is an AC plug and play wall graze lighting product available in 1' and 4' lengths. It offers industry-leading optical performance despite a total fixture size of under 2.5 inches tall.

OVERVIEW

HIGH PERFORMANCE INTERIOR GRAZE LIGHTING

WATTAGES

4W/FT, 7W/FT, 10W/FT

CCT

2700K, 3000K, 3500K, 4000K, RGBW (12W/FT)

FIXTURE LENGTHS




12", 48", AC PLUG AND PLAY READY

DIMMING


0-10V DIMMING IS STANDARD

CERTIFICATIONS

ETL LISTED FOR DAMP/DRY LOCATIONS

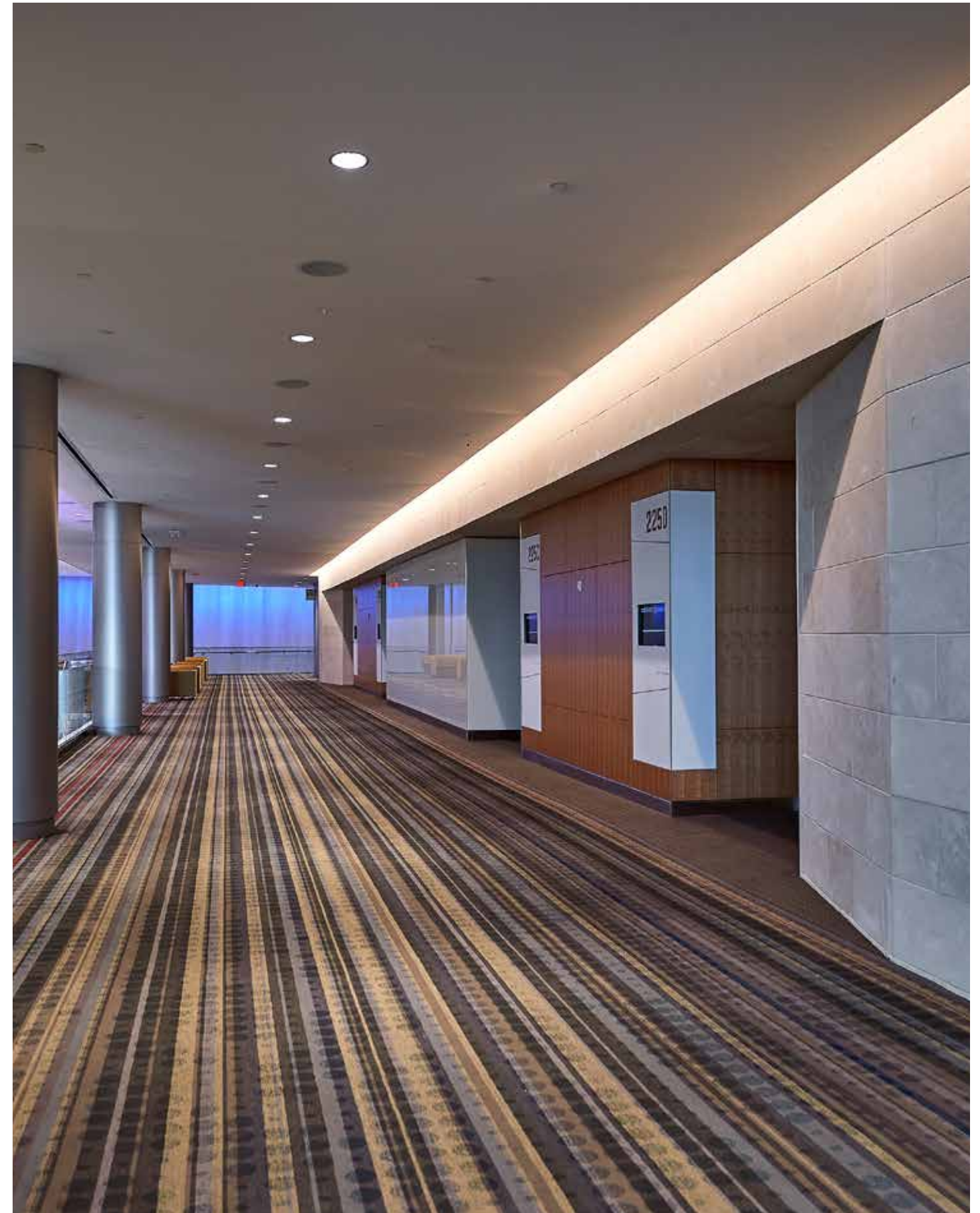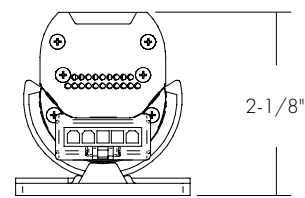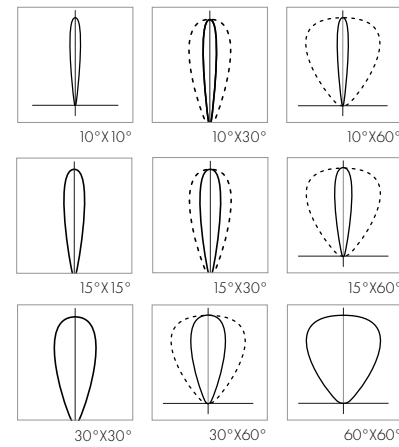

PILOT PAC

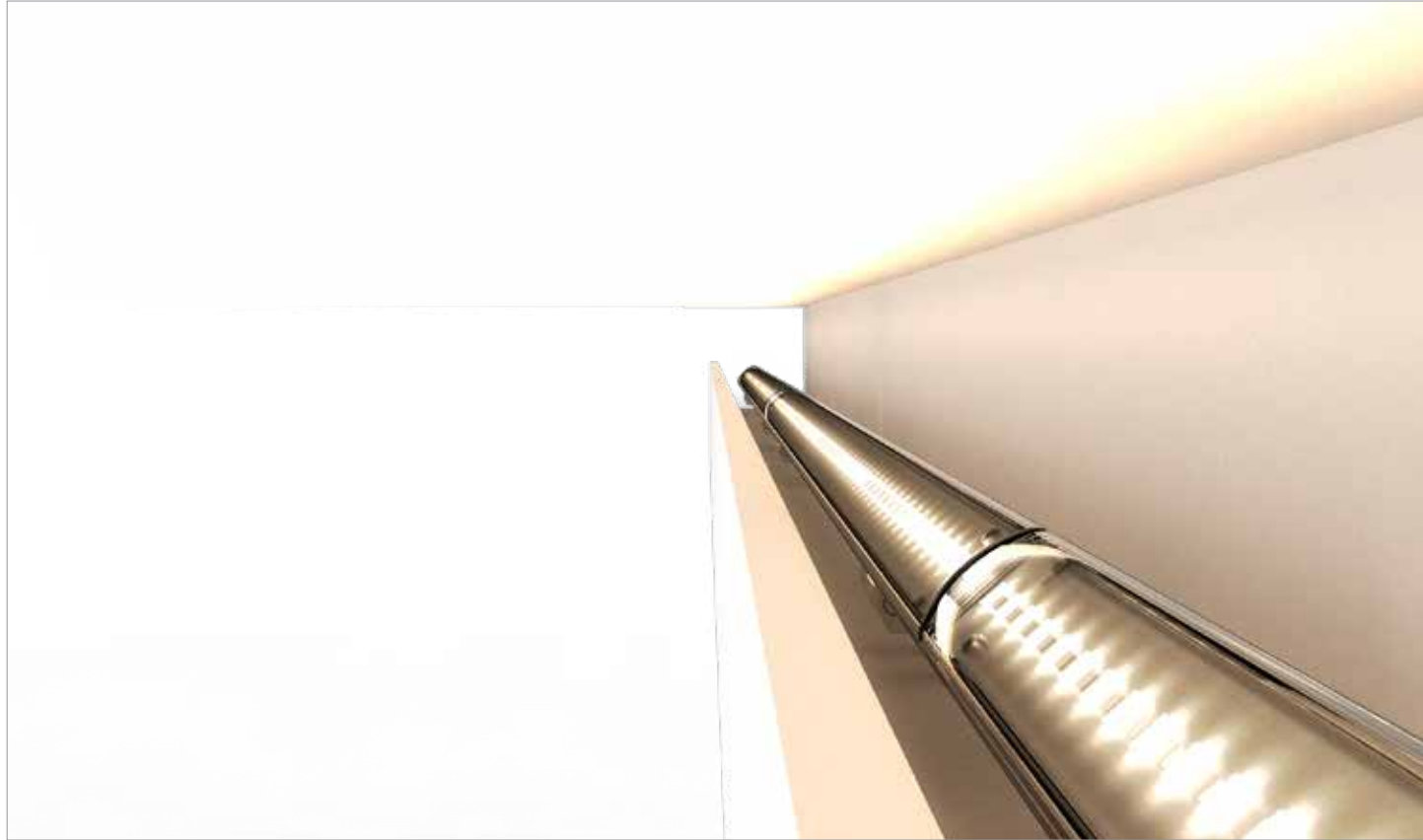

PAC is an ultra low-profile AC line voltage cove lighting product, featuring. PAC features plug and play connections for run lengths up to 100'. PAC does not have a traditional power supply but rather has the 24V conversion on the circuit boards with Triac dimming.

OVERVIEW

AC LINE VOLTAGE COVE LIGHTING

WATTAGES

4W/FT

CCT

2700K, 3000K, 3500K, 4000K (90+ CRI)

FIXTURE LENGTHS





12", 48", SINGLE AND PLUG AND PLAY

DIMMING

TRIAC DIMMING IS STANDARD

CERTIFICATIONS

ETL LISTED FOR DAMP/DRY LOCATIONS

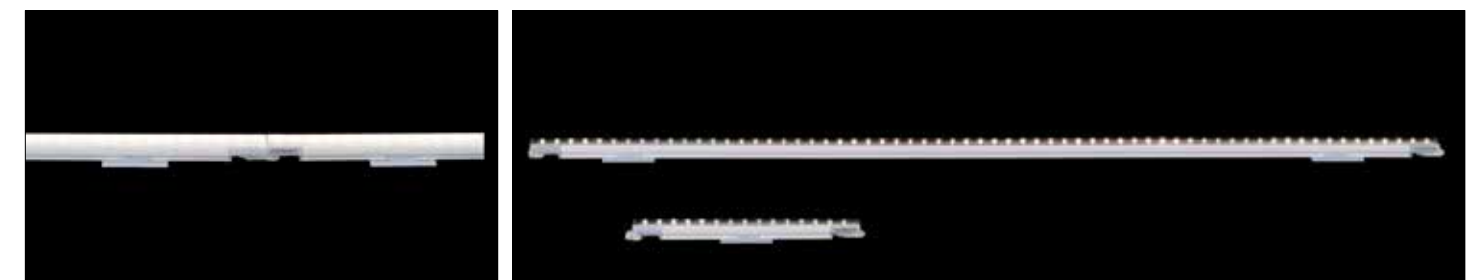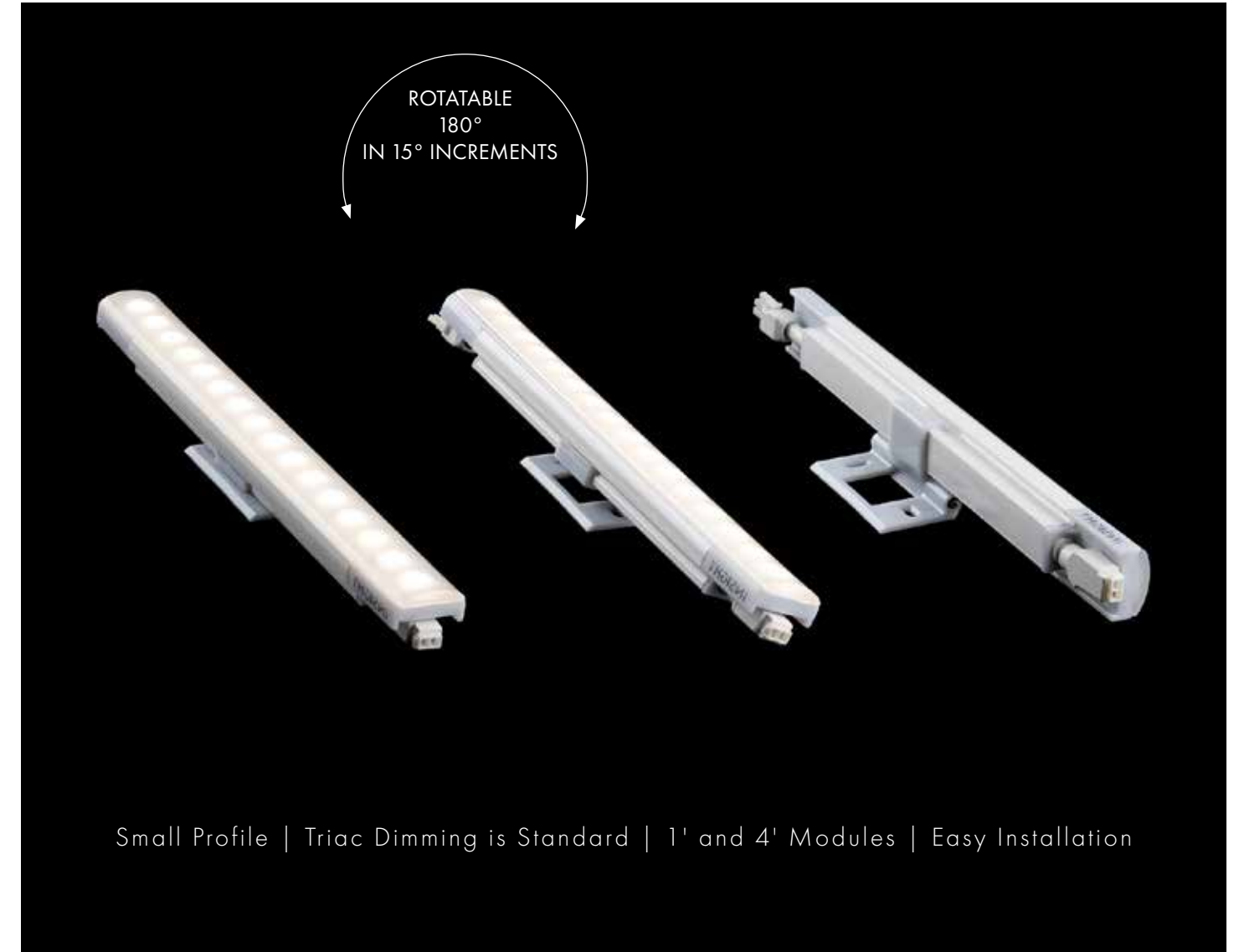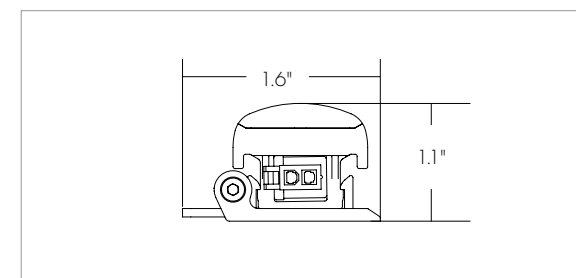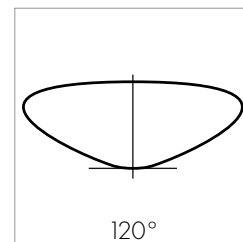

PILOT PEX



The PEX Series, an exterior LED cove and graze luminaire, offering 11 optical distributions in CCT's of 2700K, 3000K, 3500K, 4000K and RGBW. PEX features an integral universal power supply, 1' and 4' modules, plug & play installation and IP67 rated.

OVERVIEW

HIGH PERFORMANCE EXTERIOR GRAZE LIGHTING

WATTAGES

4W/FT, 7W/FT, 10W/FT

CCT

2700K, 3000K, 3500K, 4000K, RGBW (12W/FT)

FIXTURE LENGTHS



12", 48", AC PLUG AND PLAY READY

DIMMING

0-10V DIMMING IS STANDARD, OPTIONAL DMX DIMMING

CERTIFICATIONS

ETL LISTED FOR WET LOCATIONS (IP67 RATING)

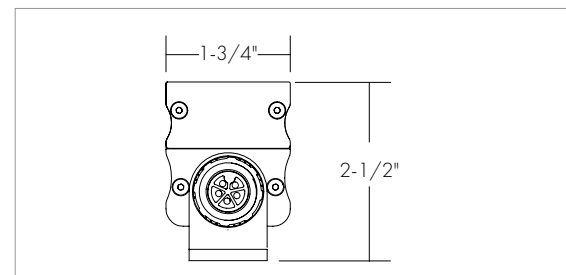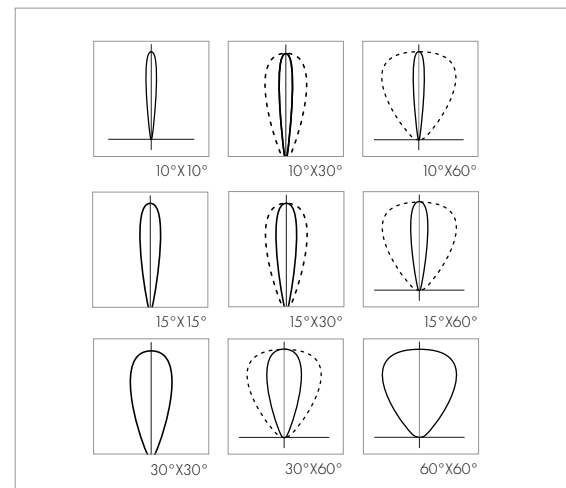

PRO-SPOT



Built for the rugged exterior environment, Pro-Spot features IP66 rated and IK09 protection, making it the perfect choice for monuments, stadiums or any multi story corporate structures. Pro-Spot features a full assortment of simple mounting options.

OVERVIEW

HIGH PERFORMANCE FLOOD, FACADE AND ACCENT LIGHTING

WATTAGES

15W UP TO 275W IN 3 HOUSING SIZES

CCT

2700K, 3000K, 3500K, 4000K, STATIC COLORS AND COLOR CHANGING

MOUNTING

SURFACE, EXTENDED ARM, STANCHION

DIMMING




0-10V, DMX

CERTIFICATIONS

IP66, IP67, IK07, 3G RATING (SUITABLE FOR USE ON BRIDGES)



2018
WINNER
LIGHTING
DESIGN
AWARDS

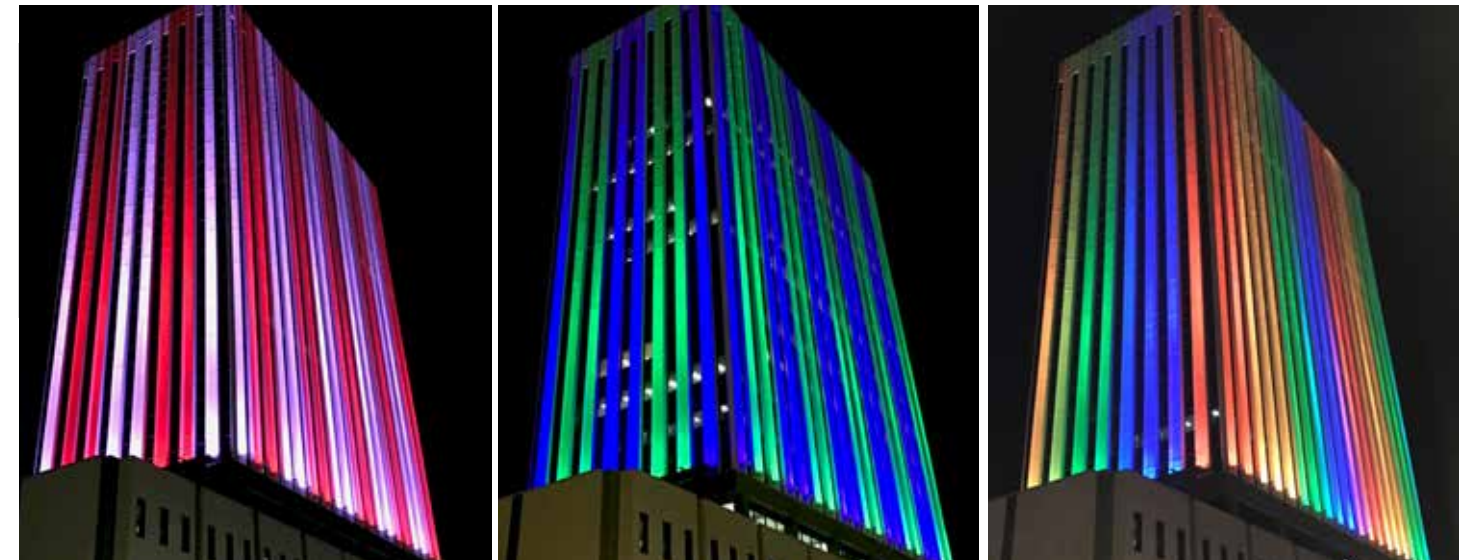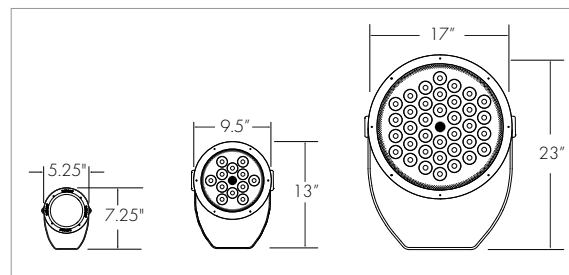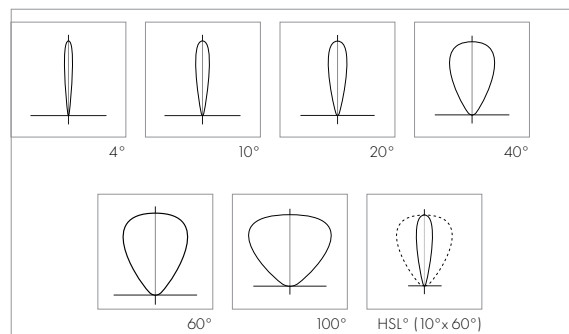

MASQUE



The Masque LED family of facade lighting fixtures is up to the task. Integrating the latest in digital LED platforms for white light and color changing with 6 optical choices of beam performance.

OVERVIEW

HIGH PERFORMANCE ARCHITECTURAL FACADE LIGHTING

WATTAGES

15W, 30W, 50W, 135W , OFFERED IN 3 HOUSING SIZES

CCT

2700K, 3000K, 3500K, 4000K, STATIC COLORS, COLOR CHANGING

MOUNTING



SURFACE, EXTENDED ARM, STANCHION

DIMMING

0-10V

CERTIFICATIONS

ETL WET LOCATION

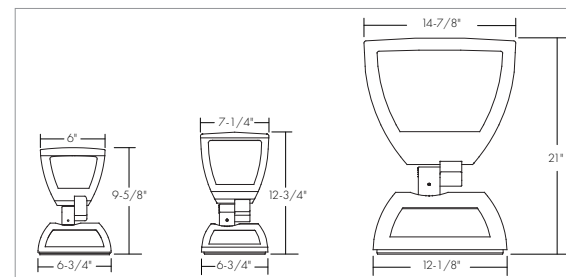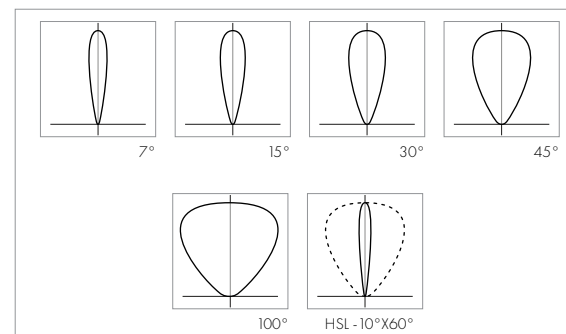

PARALED



ParaLED, a stylish family of architectural and distinctive luminous linear blades. Insight's patent pending technology allows for some of the industry's highest performing linear edge lit systems and allows for a simple and dramatic upgrade to the lighting plan.

OVERVIEW

THIN LUMINOUS BLADES OF VERTICAL ILLUMINATION

WATTAGES

11W/FT IN 4" AND 7" BLADES (1/2" THICKNESS)

CCT

2700K, 3500K, 4000K AND COLOR CHANGING

FIXTURE LENGTHS

24", 36", 48", 96"

MOUNTING



SUSPENDED, SURFACE, RECESSED

DIMMING


0-10V AND DMX

CERTIFICATIONS

ETL AND CETL APPROVED FOR DRY LOCATION

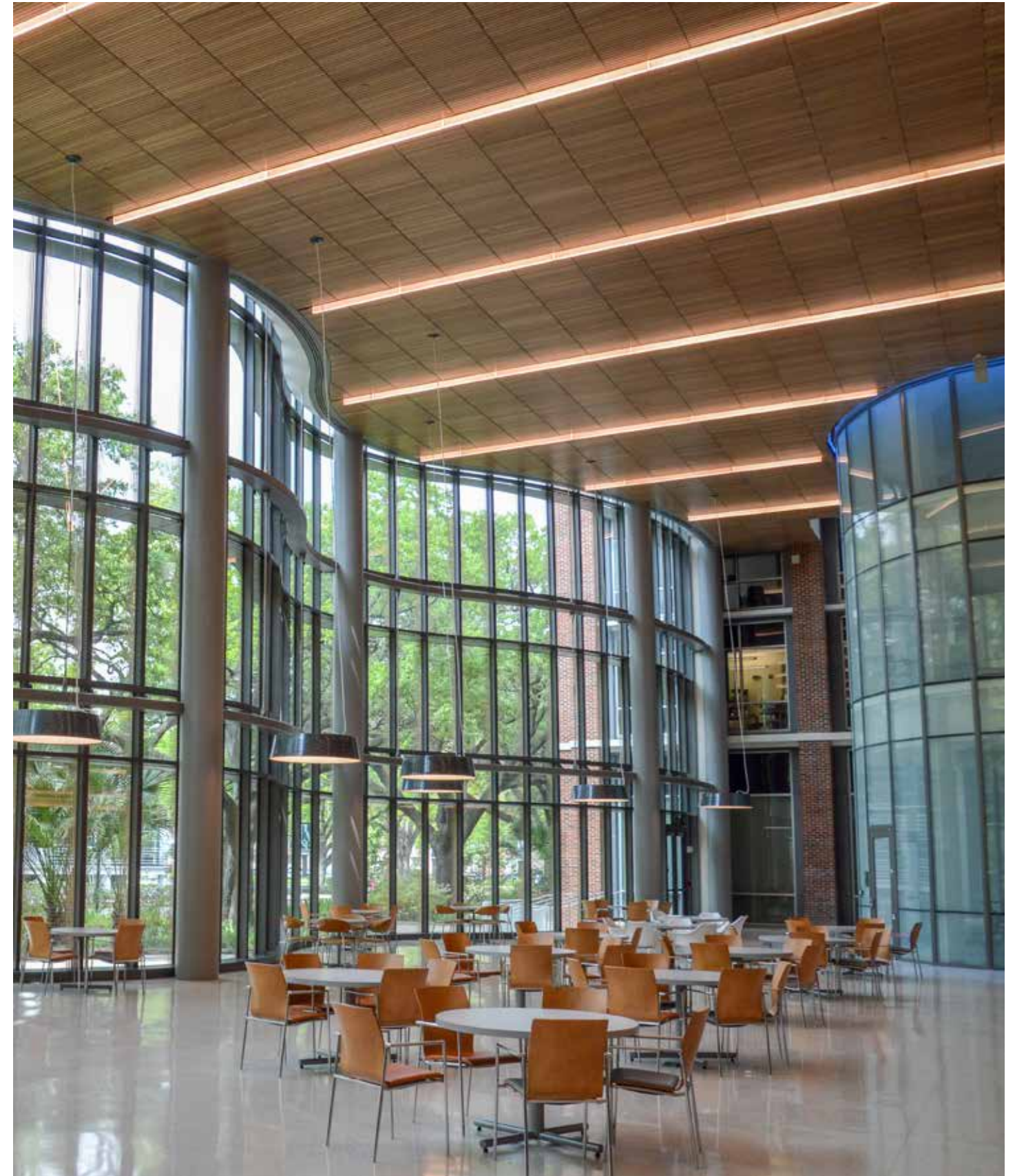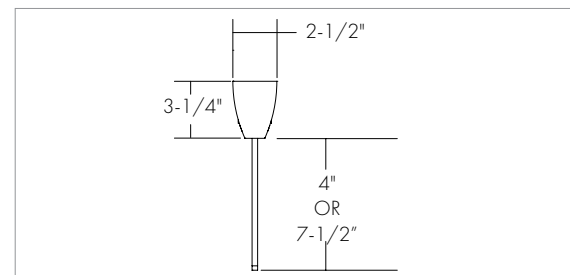

PARASIGN

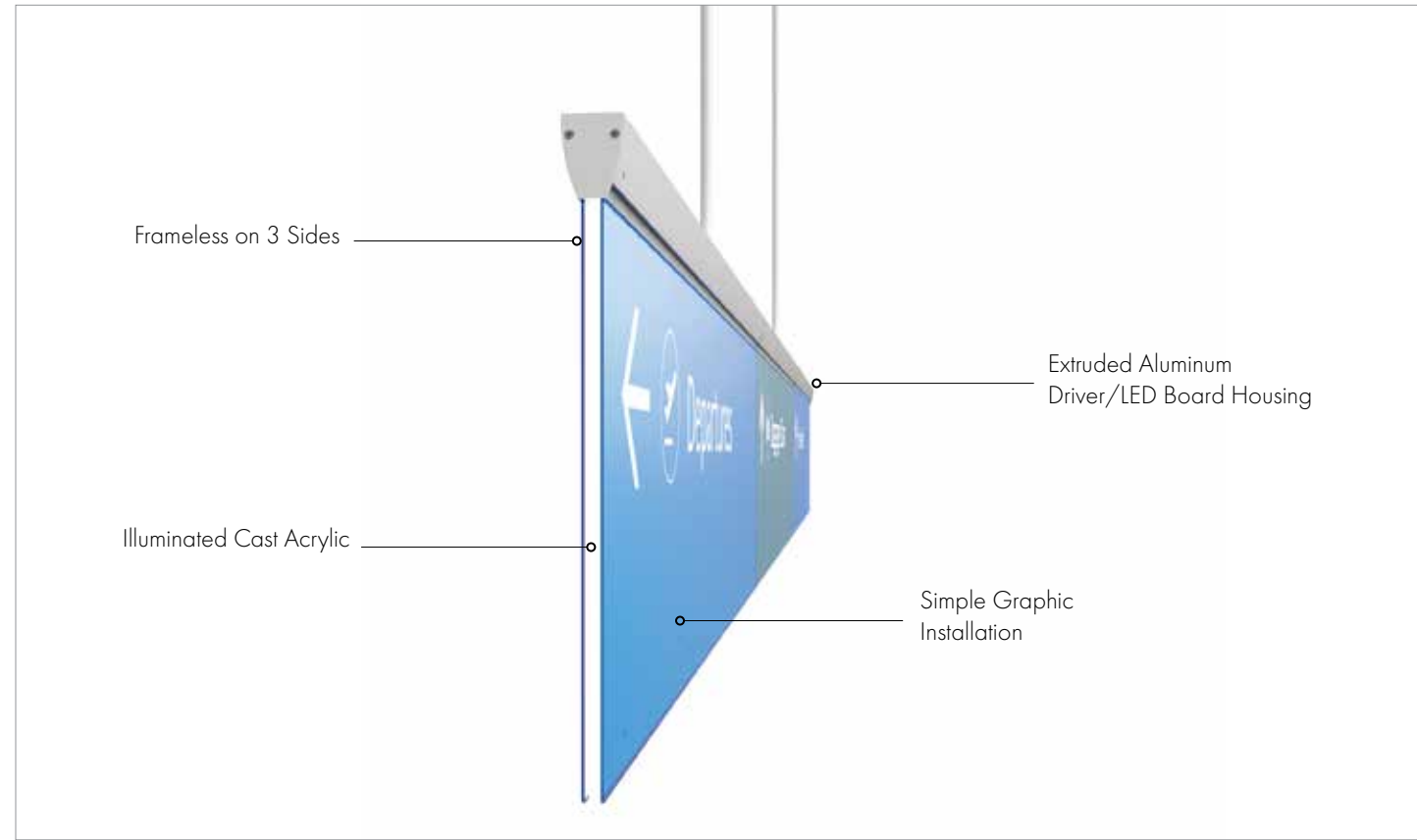

ParaSign's ability to illuminate up to 24" of graphic with one light source located in the sleek housing, the signage architecture can be changed forever. ParaSign is available in standard lengths of 48" and 96" and can be easily specified for standard applications.

OVERVIEW

FRAMELESS LED, DOUBLE SIDED WAYFINDING SYSTEM, DESIGNED FOR SIMPLE GRAPHIC INSTALLATION

WATTAGES

11W/FT IN 12" AND 24" PANEL HEIGHTS

CCT

5000K

SIGN LENGTHS




24", 36", 48", 96"

MOUNTING

SUSPENDED, SURFACE

DIMMING

0-10V

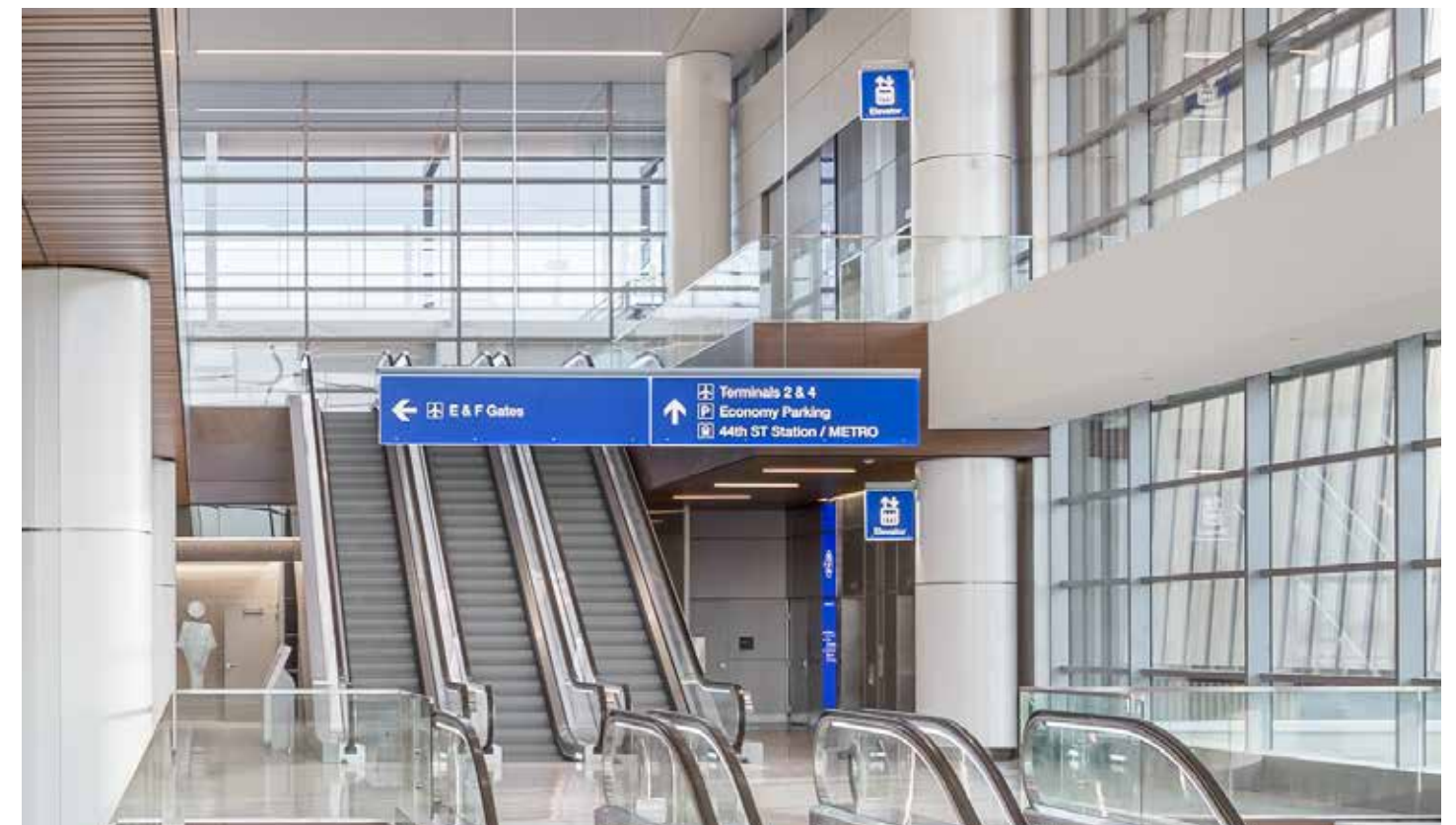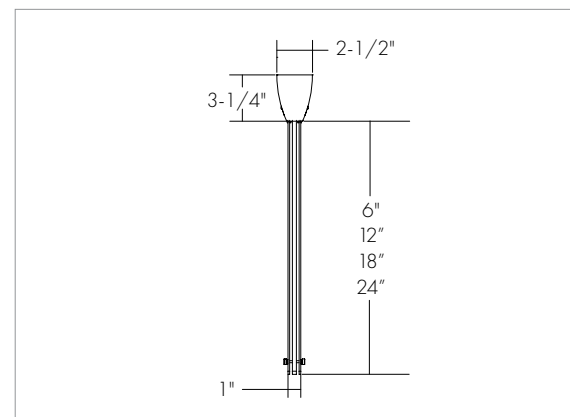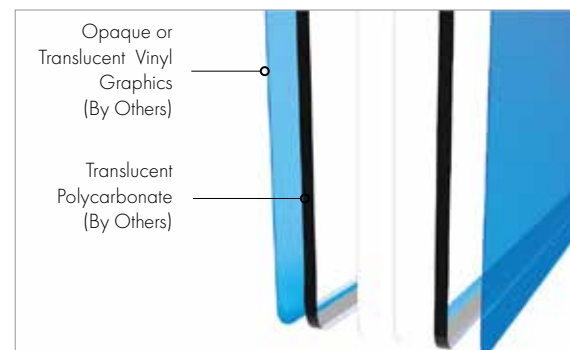

ILLUSIONS



Illusions will not only offer a better solution for new construction but will offer an LED retrofit for all current Illusions light pipe installations. Illusions is available in diameters of 6" and 10" in white light LED, CCTs of 2700, 3000, 3500 and 4000 Kelvin at 250 watts up to 500 watts.

OVERVIEW

LINEAR LIGHT PIPE SYSTEM

WATTAGES

IL6LED: 250W, 6" DIAMETER LIGHT PIPE
IL10LED: 500W, 10" DIAMETER LIGHT PIPE

CCT

3000K, 3500K, 4000K

FIXTURE LENGTHS

IL6LED: 16' - 64'
IL10LED: 24' - 80'

MOUNTING



SUSPENDED, WALL AND CEILING

DIMMING


0-10V IS STANDARD

CERTIFICATIONS

UL AND CUL APPROVED FOR WET LOCATION

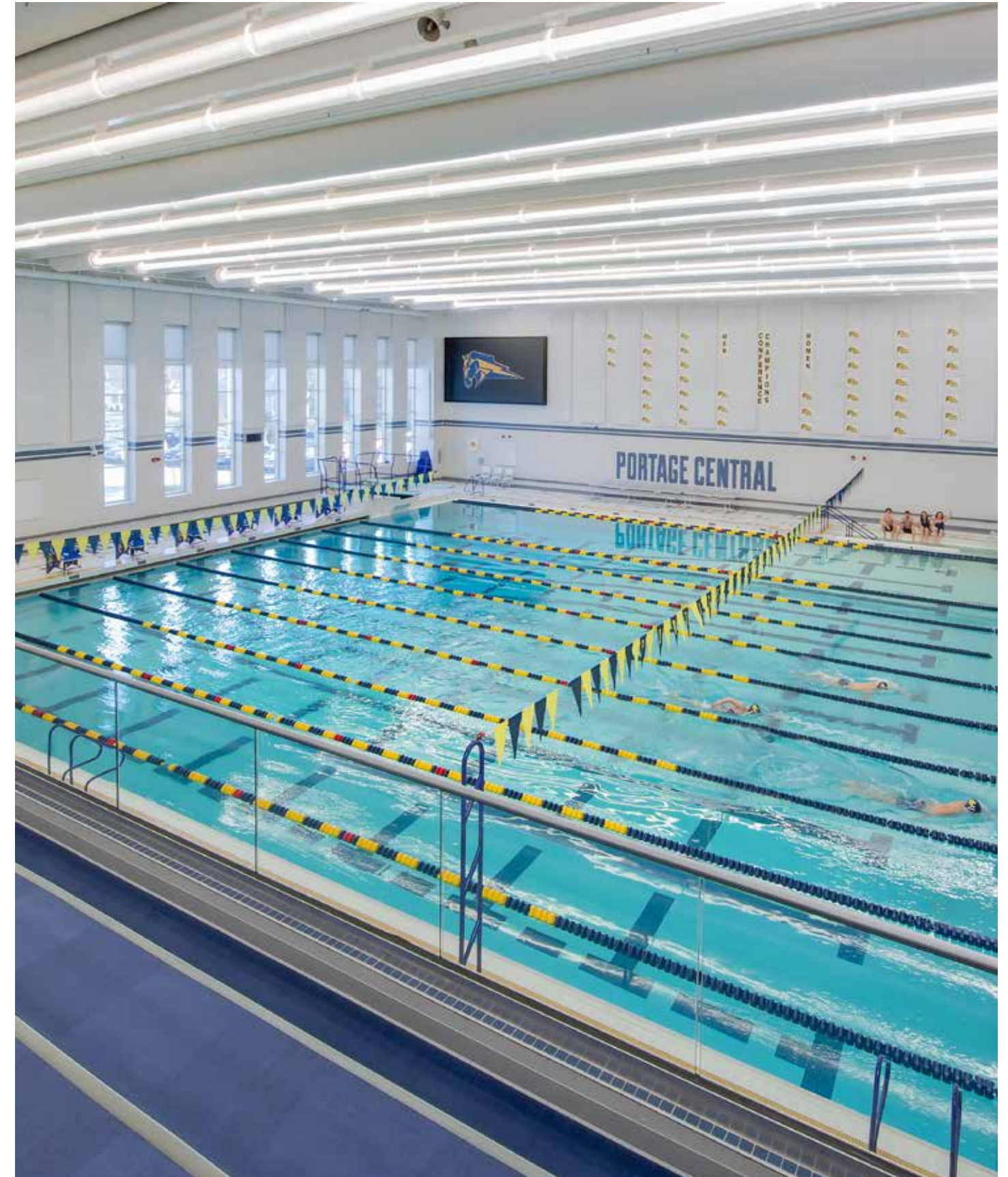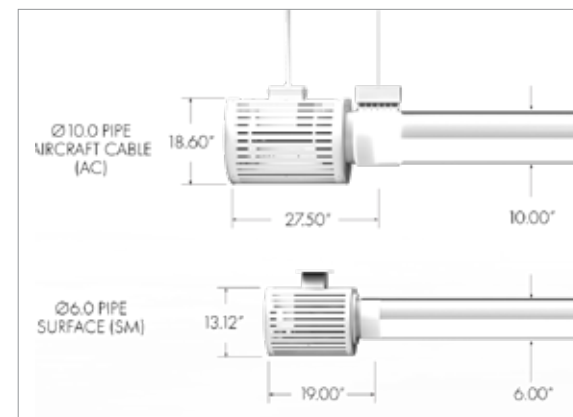

EURO

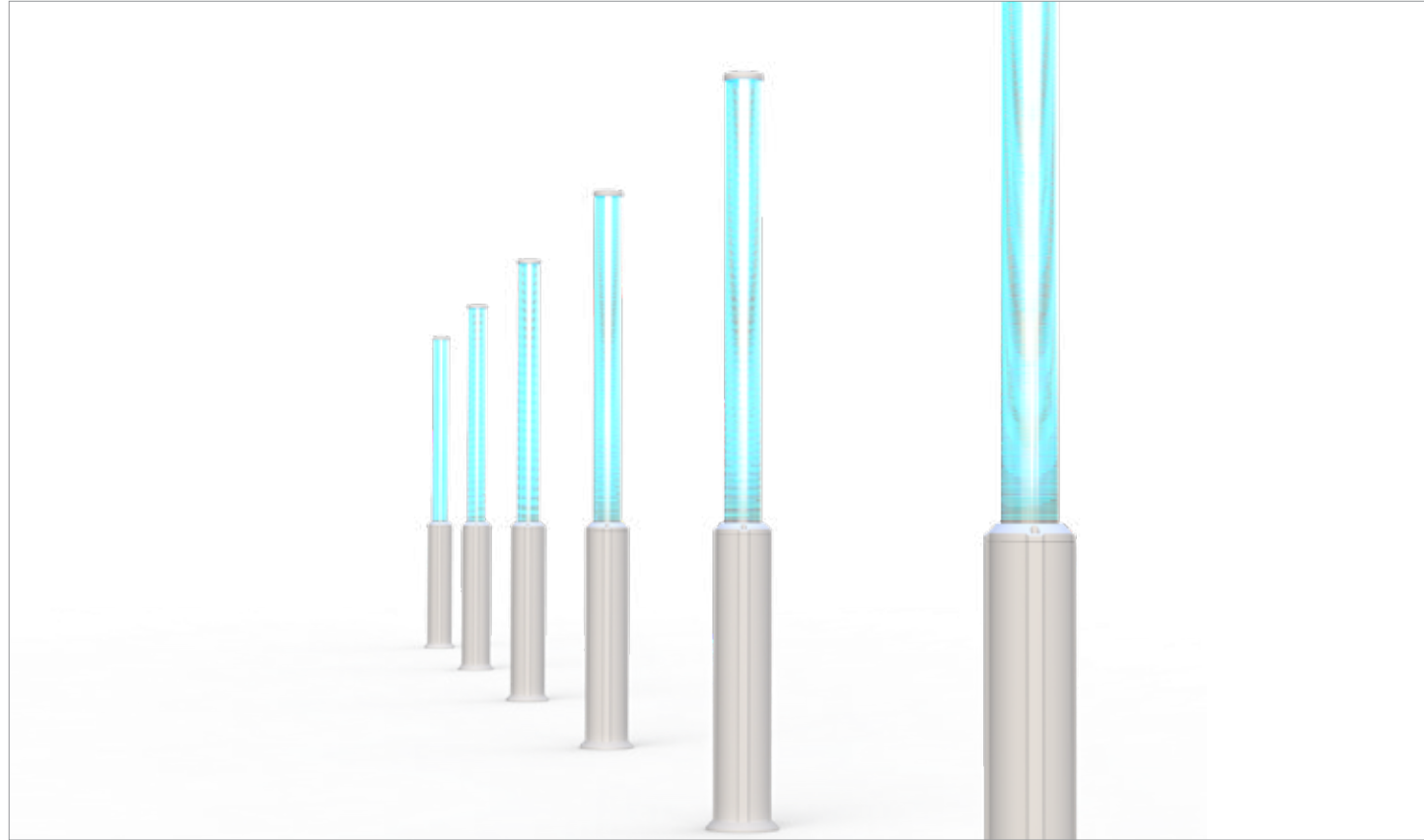

Euro provides crisp and elegant vertical illumination that will enhance any landscape. Utilizing LED illuminators in cast aluminum and extruded pedestals, Euro creates a quality of light without brightness or glare, allowing for true visual comfort in the pedestrian nightscape.

OVERVIEW

VERTICAL LIGHT PIPE SYSTEM. IDEAL FOR PEDESTRIAN WALKWAYS, PARKS AND PLAZAS

WATTAGES

50W

CCT

2700K, 3500K, 4000K

FIXTURE HEIGHTS


10' - 14'

DIMMING

0-10V

CERTIFICATIONS

UL AND CUL APPROVED FOR WET LOCATION
AASHTO RATING: RATED FOR 100MPH SUSTAINED WINDS WITH A 1.3 GUST FACTOR

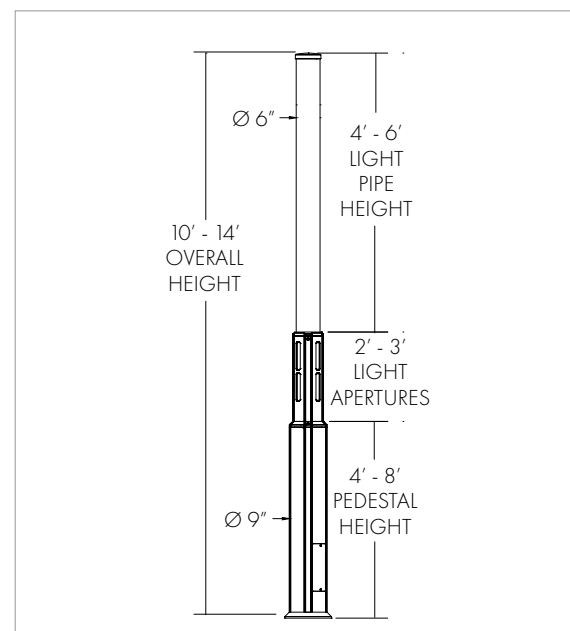

SCOPE



COMING SOON

RELEASE DATE

QTR 2 2020

OVERVIEW

A SIMPLE YET POWERFUL POINT LIGHT THAT BLENDS FUNCTIONAL AND AMBIENT LIGHT WITH A WIDE VARIETY OF SIZES AND FINISHES

WATTAGES

5W LED COB

CCT


2700K, 3000, 3500, 4000K, RGB

FIXTURE SIZES

12", 24", 36" (1.25" DIAMETER)

CERTIFICATIONS

ETL AND CETL APPROVED FOR DRY LOCATION

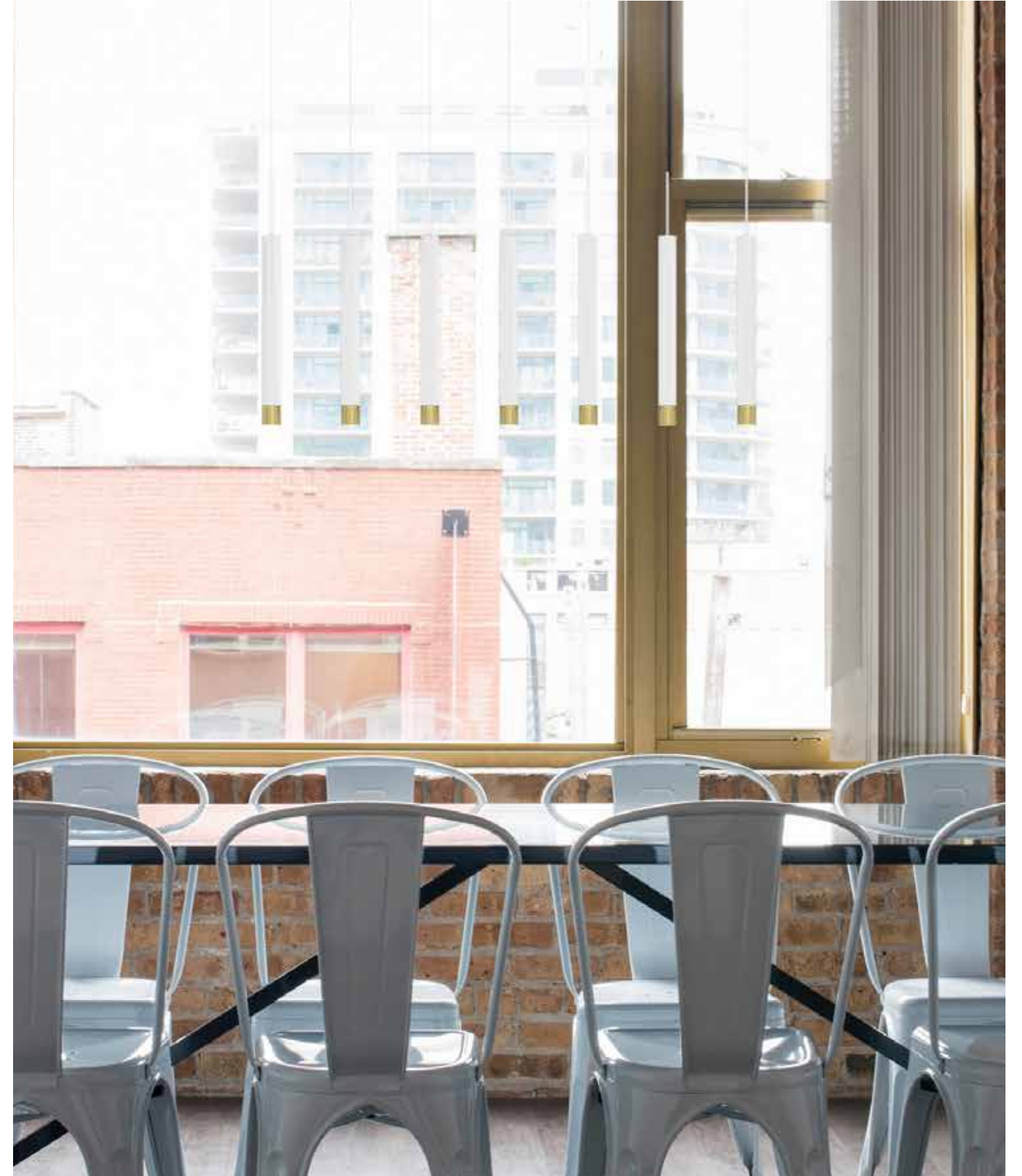

IDEA BOOK 03/09/20

4341 FULCRUM WAY NE
RIO RANCHO, NEW MEXICO 87144
505.345.0888
INSIGHTLIGHTING.COM