

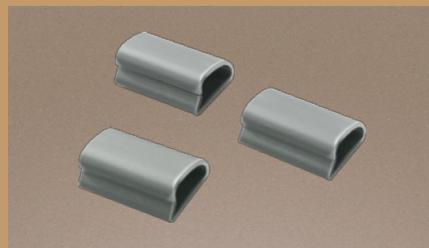
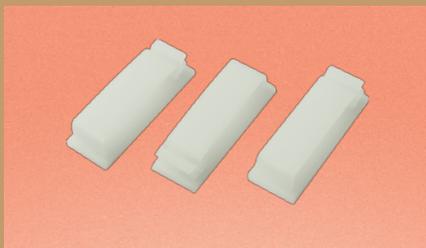
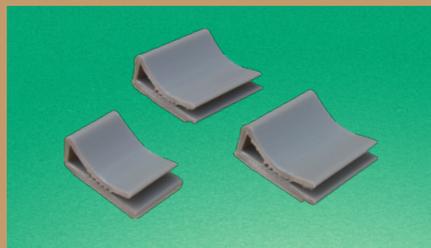
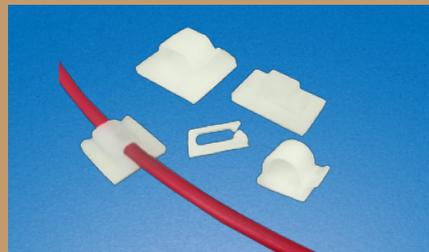
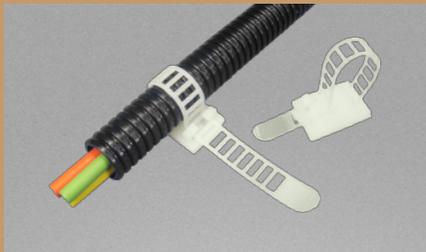
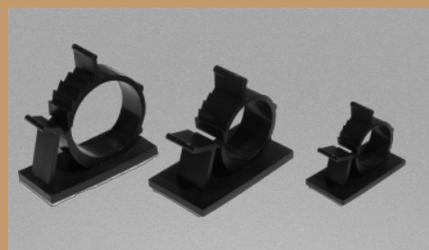
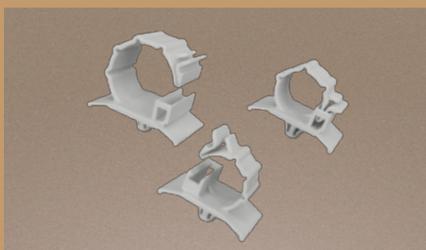
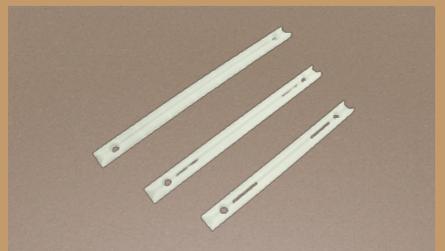
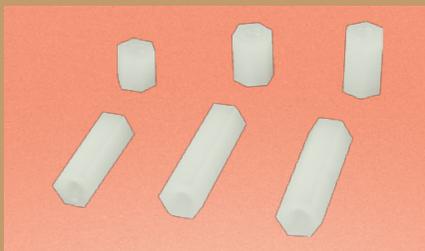
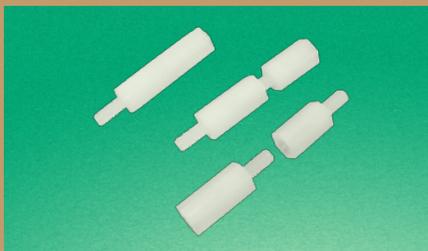
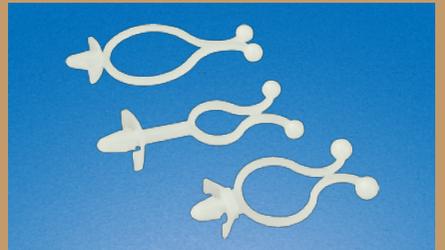
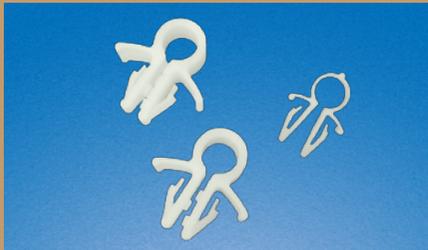
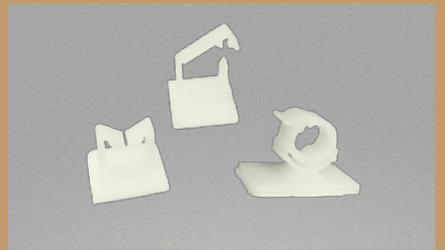



Wire Connectors Cable Lamps

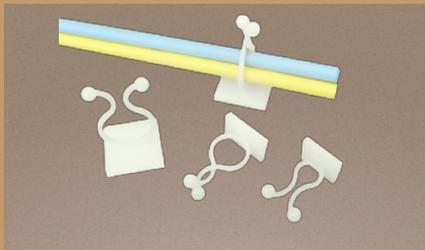

Bushings & Fasteners

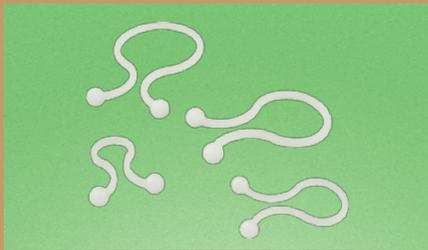

RCCN CE Close-End Wire Connector

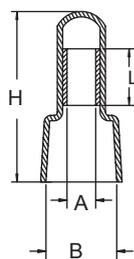



- *Four models cover a wide range of wire combinations from 22 AWG strands through 10 AWG stranded.
- *Compact design fits easily into tight locations.
- *Flared skirt ensures easy wire entry and protects against turned-back strands.
- *UL Listed for 300V maximum building wiring; temperature rated at 105°C (221°F) maximum.
- *P/N with postfix V0 means the shell is UL 94V-0 flame-retardant. Wire Connectors & Terminals Wire Connectors
- *P/N with postfix "-L" means the tube is made of aluminum.
- *Material: UL approved 94V-2 Polyamide 6.6, copper tube or aluminum tube.

Unit:mm

Item No.	L	H	A	B	Sutable Wires			Packing
					Square cable mm ²	AWG	Strang	
CE-1	7.5	18.0	2.6	6.2	1.25	22-18	Min. 2 pcs of #22 cable Max. 2 pcs of #18 cable	1000pcs
CE-2	7.5	19.7	3.0	7.9	2.0	22-14	Min. 2 pcs of #18 cable Max. 3 pcs of #18 cable	
CE-5	8.5	25.5	4.0	10.5	5.5	22-10	Min. 2 pcs of #16 cable Max. 2 pcs of #16 cable	500pcs
CE-8	9.5	27.7	5.3	12.4	8	16-10	Min. 2 pcs of #16 cable Max. 3 pcs of #16 cable	

AWG & mm ²	AWG	2	4	6	8	10	12	14	16	18	20	22	24	26	28	30	32
(square data) referred sheet	mm ²	33.4	20.8	13.2	8.4	5.3	3.3	2.1	1.3	0.83	0.52	0.33	0.21	0.13	0.08	0.05	0.03

RCCN CEV0 Heat Resistant Wire Connector

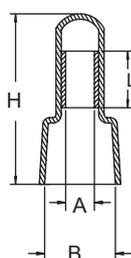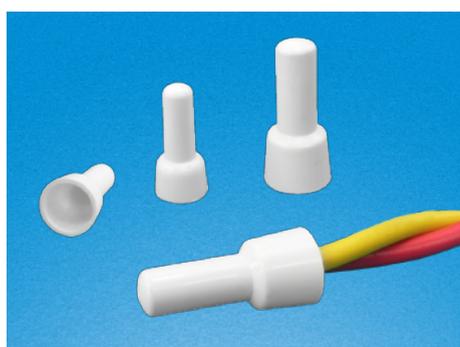


- *Four models cover a wide range of wire combinations from 22 AWG strands through 10 AWG stranded.
- *Compact design fits easily into tight locations.
- *Flared skirt ensures easy wire entry and protects against turned-back strands.
- *UL Listed for 300V maximum building wiring; temperature rated at 105°C (221°F) maximum.
- *P/N with postfix V0 means the shell is UL 94V-0 flame-retardant. Wire Connectors & Terminals Wire Connectors
- *P/N with postfix "-L" means the tube is made of aluminum.
- *Material: UL approved 94V-2 Polyamide 6.6, copper tube or aluminum tube.



Unit:mm

Item No.	L	H	A	B	Sutable Wires			Packing
					Square cable mm ²	AWG	Strang	
CE-1V0	7.5	18.0	2.6	6.2	1.25	22-18	Min. 2 pcs of #22 cable Max. 2 pcs of #18 cable	1000pcs
CE-2V0	7.5	19.7	3.0	7.9	2.0	22-14	Min. 2 pcs of #18 cable Max. 3 pcs of #18 cable	
CE-5V0	8.5	25.5	4.0	10.5	5.5	22-10	Min. 2 pcs of #16 cable Max. 2 pcs of #16 cable	500pcs
CE-8V0	9.5	27.7	5.3	12.4	8	16-10	Min. 2 pcs of #16 cable Max. 3 pcs of #16 cable	

RCCN SWB Screw On Wire Connector

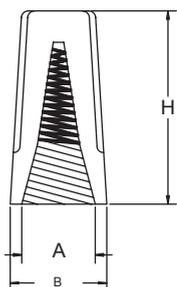


Unit:mm

Item No	A	B	H	Wire combination	Color	Packing
SW-71B	6.7	8.6	15.2	MIN#24X1+#22X1 MAX#16X2	Gray	1000pcs
SW-72B	7.4	9.8	17.6	MIN#20X3 MAX#16X3	Blue	
SW-73B	9.9	12	22.0	MIN#20X3 MAX#16X3+#18X1	Orange	500pcs
SW-74B	11	14.0	24.5	MIN#14X1+#18x1 MAX#14X4+#18X1	Yellow	
SW-76B	13	16.4	26.5	MIN#14X2 MAX#10X2+#12X2	Red	

Material:high temperature resistant plastic,with spring inside ,temperature withstand up to 150°C,voltage 300V/600V.

RCCN SWY Screw On Wire Connector

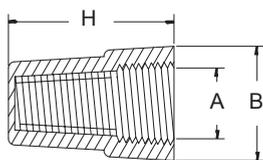


Unit:mm

Item No	A	B	H	Wire combination	Color	Packing
SW-Y71	10	18	25.4	18-10AWG	Yellow	100pcs
SW-Y71	10	17.8	27.7	22-8AWG	Brown	
SW-Y73	12	23.1	30.5	18-8AWG	Red	
SW-Y74	14.6	25.5	32.6	18-8AWG	Gray	
SW-Y76	17.8	31.7	39.5	14-6AWG	Blue	

Material:high temperature resistant plastic,with spring inside, temperature withstand up to 150°C,UL94V-0 fireproof.

RCCN SWHB Heat Resistant Wire Connector

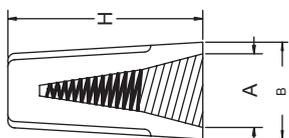


Unit:mm


Item No	A	B	H	Wire combination	Color	Packing
SW-71HB	6.7	8.6	14.8	MIN#24X1+#22X1 MAX#16X2	Black	1000pcs
SW-73HB	9.9	12	22.0	MIN#20X3 MAX#16X3+#18X1	Black	

Material:high temperature resistant plastic,with spring inside ,temperature withstand up to 150°C,UL94V-0 fireproof.

RCCN PA Terminal Blocks

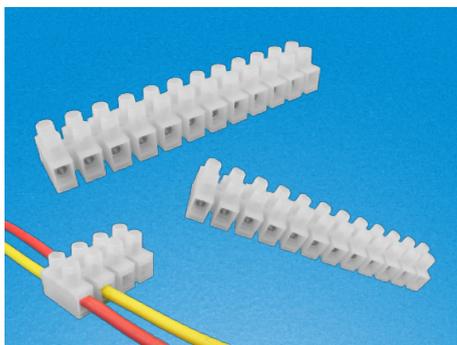

Terminal blocks: 12 pcs/bar

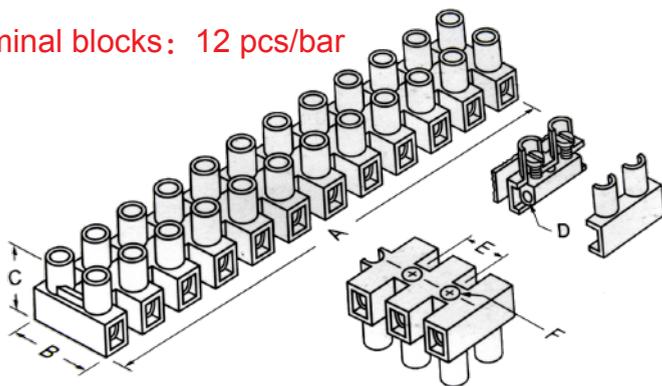



Unit:mm

Item No.	Dimension						Cable range mm ²	Max. current A	Suitable voltage V	Screw	Split cable length	Packing
	A	B	C	D	E	F						
Flat type												
PA-1.5	96.2	16.3	12.7	2.8	8.2	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5	116.5	20.2	15.8	3.2	10	3.6	2.5	24A	450V	M3*6	6.5	
Flat type with flexble												
PA-1.5DS	96.2	16.3	12.7	2.8	8.2	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5DS	116.5	20.2	15.8	3.2	10	3.6	2.5	24A	450V	M3*6	6.5	

Material: UL approved NYLON66(natural), fireproof 94V-2, nickel coated copper bottom, zinc coated steel screw
Operate T:-30°C to 110°C。

Use: Used in electric equipment、lights and so on

RCCN PAH H Terminal Blocks

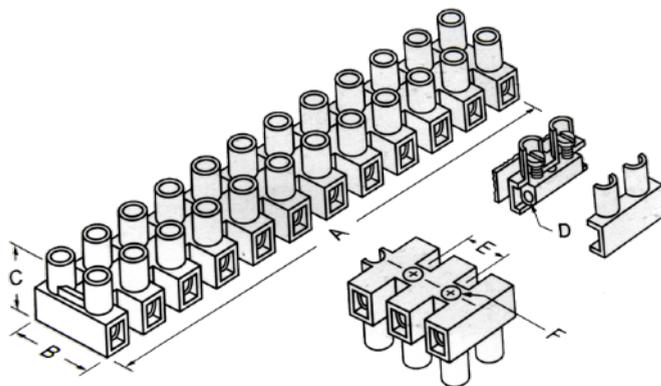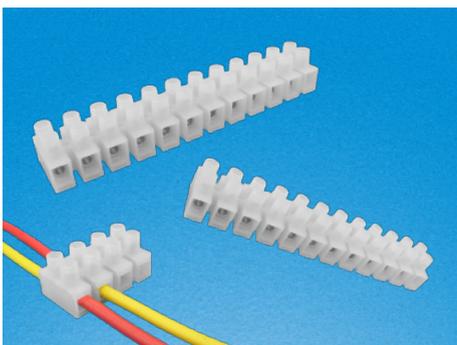

Wire connect: 12 set/pcs


Unit:mm

Item No.	Dimension						Cable range mm ²	Max. current A	Suitable voltage V	Screw	Split cable length	Packing	
	A	B	C	D	E	F							
Higher bottom													
PA-1.5H	96.2	17	14.5	2.8	8	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs	
PA-2.5H	116.5	20.2	16.8	3.4	10	3.6	2.5	24A	450V	M3*6	6.5		
PA-6H	141	23.8	19	4.2	12	3.9	6	41A	500V	M3.5*7	7	10pcs	
PA-10H	158	25.6	25.2	5	13.5	4.4	10	57A	500V	M4*9	9		
PA-16H	170	28.1	23	6	14.5	4.2	16	76A	500V	M4*9	9		
PA-25H	194	37	28.7	7.5	16.5	4.2	25	101A	500V	M4*11	11	50pcs	
Higher bottom with shrapnel													
PA-1.5HDS	96.2	17	14.5	2.8	8	2.9	1.5	17.5A	450V	M2.6*5	5		
PA-2.5HDS	116.2	20.2	16.8	3.4	10	3.6	2.5	24A	450V	M3*6	6.5		
PA-6HDS	141	23.8	19	4.2	12	3.9	6	41A	500V	M3.5*7	7		
PA-10HDS	158	25.6	25.2	5	13.5	4.4	10	57A	500V	M4*9	9		


Material: UL approved NYLON66(natural), fireproof 94V-2, nickel coated copper bottom, zinc coated steel screw
Operate temperate:-30°C-110°C。

Note: H type, its bottom added height is about 1-2.5mm

RCCN PAV0 V0 Terminal Blocks

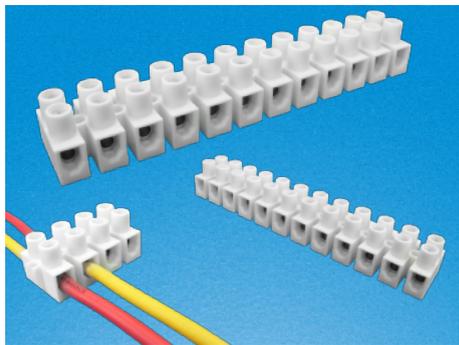

Terminal blocks: 12 pcs/bar

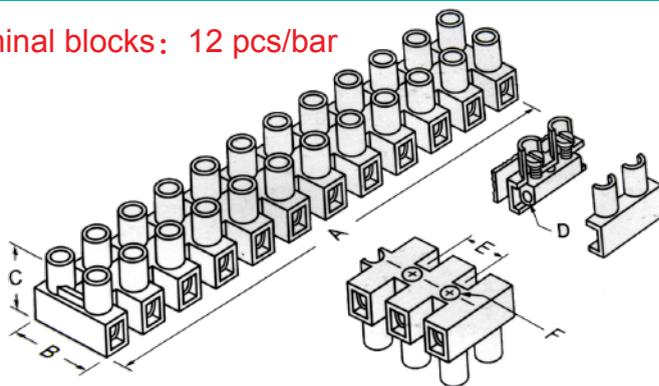

Unit:mm

Item No.	Dimension						Cable range mm ²	Max. current A	Suitable voltage V	Screw	Split cable length	Packing
	A	B	C	D	E	F						
smooth bottom												
PA-1.5V0	96.2	16.3	12.7	2.8	8.2	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5V0	116.5	20.2	15.8	3.2	10	3.6	2.5	24A	450V	M3*6	6.5	
smooth bottom with shrapnel												
PA-1.5DSV0	96.2	16.3	12.7	2.8	8.2	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5DSV0	116.5	20.2	15.8	3.2	10	3.6	2.5	24A	450V	M3*6	6.5	
higher bottom												
PA-1.5HV0	96.2	17	14.5	2.8	8	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5HV0	116.5	20.2	16.8	3.4	10	3.6	2.5	24A	450V	M3*6	6.5	
PA-6HV0	141	23.8	19	4.2	12	3.9	6	41A	500V	M3.5*7	7	10pcs
PA-10HV0	158	25.6	25.2	5	13.5	4.4	10	57A	500V	M4*9	9	
PA-16HV0	170	28.1	23	6	14.5	4.2	16	76A	500V	M4*9	9	10pcs
PA-25HV0	194	37	28.7	7.5	16.5	4.2	25	101A	500V	M4*11	11	
higher bottom with shrapnel												
PA-1.5HDSV0	96.2	17	14.5	2.8	8	2.9	1.5	17.5A	450V	M2.6*5	5	50pcs
PA-2.5HDSV0	116.2	20.2	16.8	3.4	10	3.6	2.5	24A	450V	M3*6	6.5	
PA-6HDSV0	141	23.8	19	4.2	12	3.9	6	41A	500V	M3.5*7	7	10pcs
PA-10HDSV0	158	25.6	25.2	5	13.5	4.4	10	57A	500V	M4*9	9	

Material: UL approved NYLON66(natural), fireproof 94V-0, nickel coated copper bottom, zinc coated steel screw, Operate T.: -30°C-110°C.


RCCN KW Mid-Way Wire Connector

Unit:mm




Item No.	Wire combination	Packing
KW-1	18AWG-14AWG	100pcs (1000pcs)
KW-2	18AWG-14AWG	
KW-3	22AWG-18AWG	
KW-4	18AWG-14AWG	
KW-5	12AWG-10AWG	
KW-6	22AWG-20AWG	
KW-6L	18AWG-14AWG	
KW-10	22AWG-18AWG	
KW-11	16AWG-14AWG	
KW-12	12AWG-10AWG	

Material: UL approved NYLON66, fireproof 94V-2.

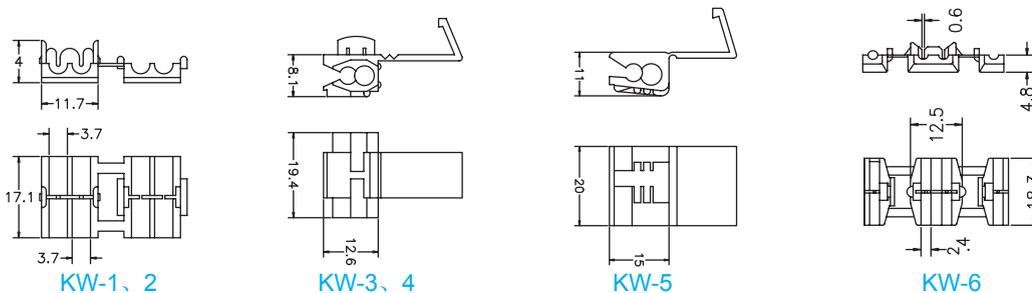


RCCN HC Self Adhesive Backed Mounts

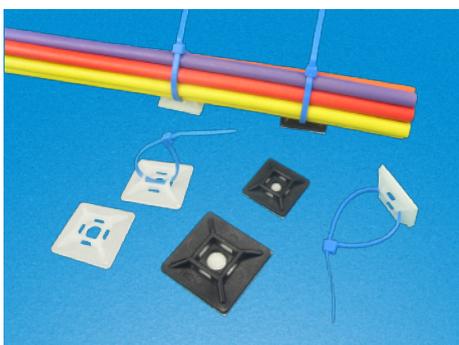

Unit:mm

Item No		L	W	H	B	Cable tie with hole T	Packing
Natural	Black						
HC-100	-	12.5	12.5	3.2	3.2	3.2	100pcs or 500pcs
HC-101	HC-101B	19.5	19.5	3.9	3.2	4.5	
HC-102	HC-102B	29	29	6.0	7.0	6.0	
HC-101/3M	HC-101B/3M	19.5	19.5	3.9	3.2	4.5	
HC-102/3M	HC-102B/3M	29	29	6.0	7.0	6.0	

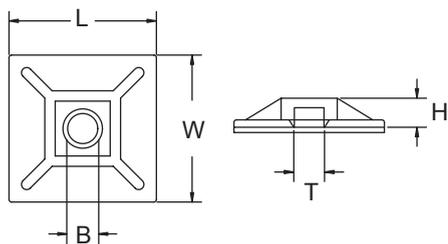

*Available in either "screw mount" or "self adhesive mounting". This range offers a safe and secure mount.

*Simple to install with a screw or bolt, the tie mounts give excellent security, particularly in areas of high vibration.


*Designed to offer the maximum surface area, and in conjunction with the specially developed adhesive ensures that a very high pull-off force is achieved.

*The tie mounts offer a '4-way' entry for the cable tie enabling quicker and more flexible installation.

*Designed specifically for holding heavier cable bundles. These mounting bases can be used in many industries from agriculture to truck manufacture. They offer a very secure fixing and can be used with a wide variety of heavy duty cable ties up to 5.5mm wide.

*Material: Polyamide 6.6, UL94 V2


RCCN HC Saddle Tie Mounts

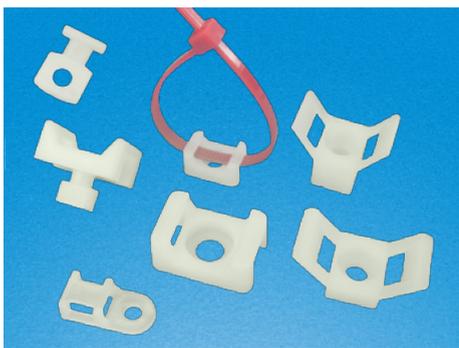


Unit:mm

Item No	L	W	H	B	T	Packing
* HC-0	19.6	9.5	5	3.7	5.2	100pcs or 500pcs
* HC-1	15.0	10.0	7.0	3.3	5.1	
* HC-1L	15.0	9.5	7.0	4.5	5.1	
HC-2S	21.2	15.3	9.4	4.5	9.0	
HC-2A	23	16	9.8	6.0	9.0	
* HC-2	20.5	17.1	10.4	5.0	10.4	
HC-2L	23	16	9.8	6.5	9.0	
HC-3	23	13.8	17.5	9.5	5.3	
HC-4	30	14.7	11.6	9.5	5.0	
HC-5	21.5	16.0	10.0	7.8	5.8*9.7	
HM-0	10.2	8.1	2.5	3.5	2.8	
HM-1	18.9	12.7	3.0	4.4	5.0	

* With big stock items



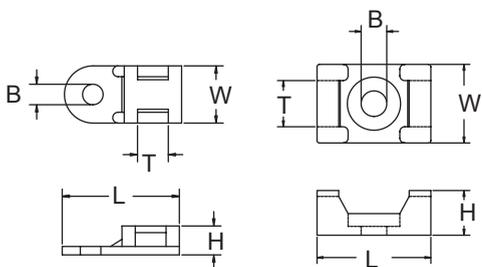


HC-1,2

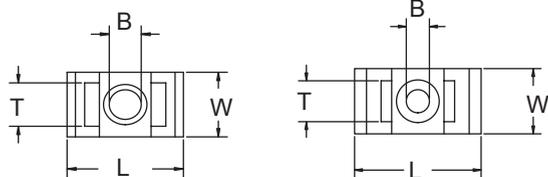

HC-3

HC-4

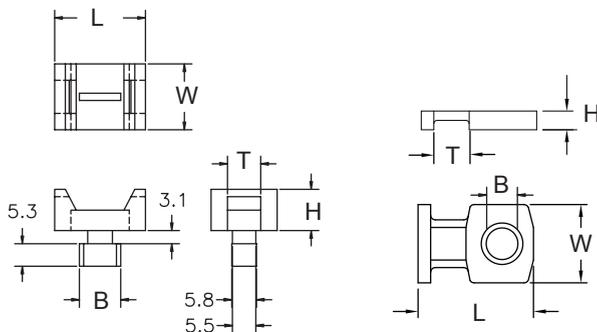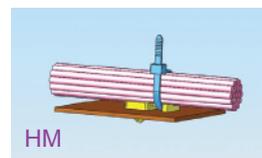
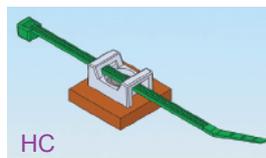


HC-5

HM

Material: UL approved NYLON 66(natural), fireproof 94V-2
Part no. of black:HC-0B,HC-1B,HC-1LB,HC-2B

RCCN PHC Push Tie Mounts

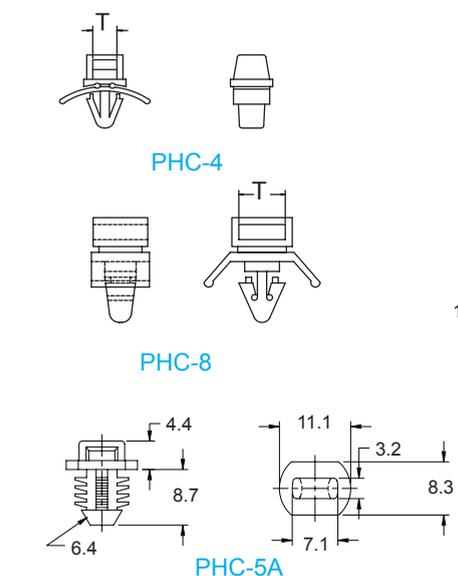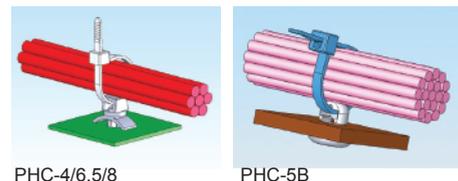

Unit:mm

Item No.	T	Fiting	Packing
* PHC-4	4.0	4.8	100pcs
PHC-5	5.0	7.6	
* PHC-5A	5.0	6.4	
* PHC-5B	5.0	6.4	
* PHC-6.5	6.5	8.5	
* PHC-8	8.1	6.2	
PHC-9	9.4	7.9	
PHC-1105	11	4.5	
PHC-1509	7.8	4.5	

Material: UL approved NYLON 66(natural), fireproof 94V-2 good insulation

part no. of black:PHC-4B,PHC-6.5B,PHC-8B Three different design
* means common items


RCCN UC Cable Clamp





Unit:mm

Item No.	Thread hole A	B	Width C	Band dia.(inner)	Length E	Thickness F	Packing
UC-0	4.8	8.0	9.6	3.1(1/8")1mm	17	1.2	Pcs/bag 100pcs
UC-0.5	4.8	9.2	9.6	5.0(3/6")Half	18.6	1.2	
UC-1	4.6	10.0	10.0	6.35(1/4")2mm	20.0	1.4	
UC-1.5	4.6	12.0	10.0	7.9(5/16")2Half	22.0	1.5	
UC-2	4.6	12.5	12.0	9.5(3/8")3mm	24.0	1.5	
UC-3	5.0	15.2	12.0	12.7(1/2")4mm	31.0	1.5	
UC-4	4.6	18.2	12.0	15.8(5/8")5mm	34.3	1.5	
UC-5	4.6	18.2	12.0	19.4(3/4")6mm	35.0	1.5	
UC-6	4.6	22.0	12.0	25.4(1")1inch	43.0	1.8	
UC-6.5	4.6	24.0	12.0	27.5(1 1/16")	50	1.8	
UC-7	4.6	26.2	12.0	31.8(1 1/4")1inch2mm	50	1.8	
UC-9	4.6	30.0	12.0	36.7(1 1/2")1inch4mm	50	1.8	

Material: UL approved NYLON 66(natural), fireproof 94V-2

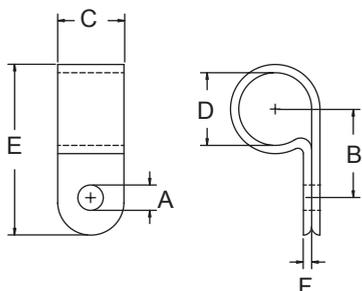

RCCN AC Adjustable Cable Clamp

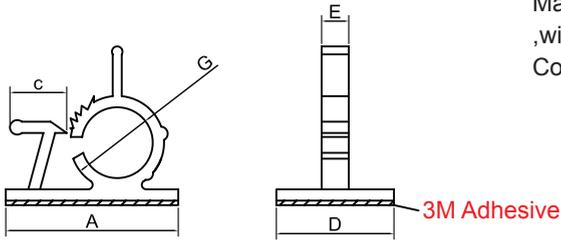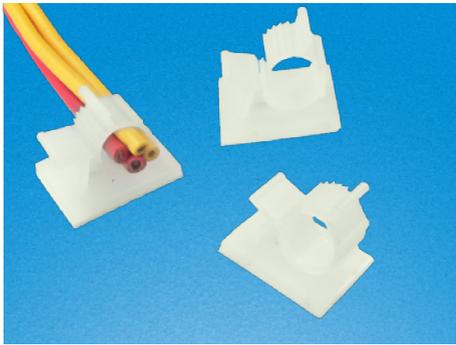


Unit:mm

Item No.	Wire harness range G	Dimension					Packing
		A	B	C	D	E	
AC-0810	7.5-9.5	24.6	10.2	8.0	18.5	10.0	100pcs
AC-1113	11-13.5	24.9	12.2	7.25	14.9	10.0	
AC-1518	15-18	34.3	15.0	8.8	18.5	12.7	
AC-1621	16-21	35.8	17.1	10.1	18.7	12.7	
AC-1925	19-25	39.4	19.8	10.2	19.4	13.0	

Material: UL approved NYLON 66(natural), fireproof 94V-2
 ,with 3M tape
 Color: natural

RCCN JS Self-Adhesive Cable Clamp


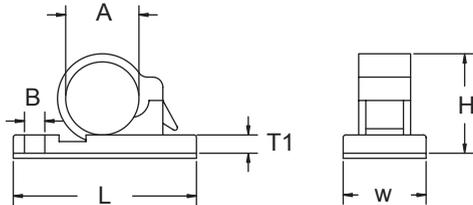


Unit:mm

Item No.	Dimension						Packing
	A	B	T1	L	W	H	
4J-S	5.5	5.0	3.0	25.8	13.4	12.2	100pcs
6J-S	7.5	5.0	3.2	28.8	13.4	14.5	
8J-S	12	5.3	3.0	34.8	16.5	18.5	
10J-S	14	5.0	3.2	36.5	16.4	19.5	
11J-S	15	5.0	2.7	38.2	16.0	20.3	
12J-S	17	4.8	3.1	41.3	15.6	24.0	

Material: UL approved NYLON 66(natural), fireproof 94V-2

RCCN PFS Push Tie Mount

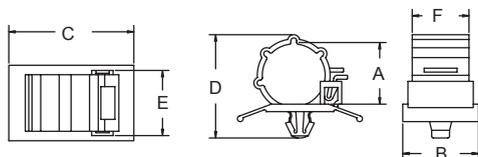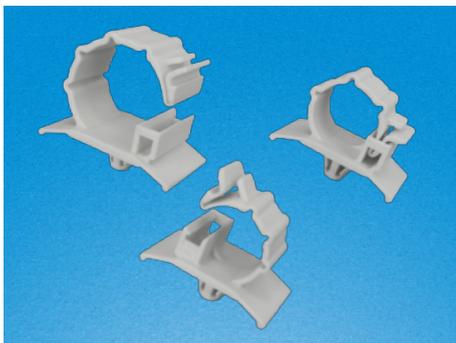


Unit:mm

Item No.	Dimension						Packing
	A	B	C	D	E	F	
PFS-10	10.1	17.2	28.4	20.7	11.9	14.3	100pcs
PFS-15	14.9	19.3	31.8	27.1	14	16.3	
PFS-18	17.3	21.2	35	29	15.9	18.3	

Material: UL approved NYLON 66(natural), fireproof 94V-2


RCCN AP Adjustable Cable Clamp

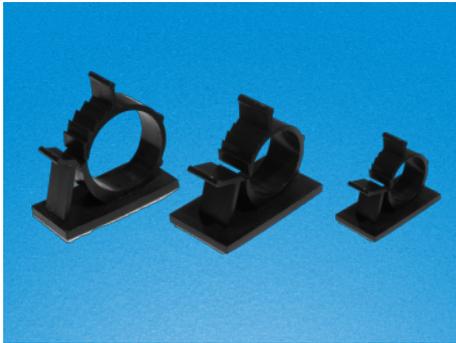

Unit:mm

Item No.	Wire harness A	B	C	D	E	F	Packing
AP-0810	7.9-10.3	25.4	22.2	19.1	1.6	10.2	100pcs
AP-1013	10.0-12.5	31.8	27.8	19.1	1.6	10.2	
AP-1316	12.6-15.4	37.0	31.8	18.4	3.0	12.1	
AP-1720	16.5-20.1	42.0	37.0	25.0	3.0	12.7	
AP-2225	22.2-25.4	41.8	43.5	21.5	3.0	11.3	

Material: UL approved NYLON 66(black), fireproof 94V-2 with adhesive tape
Color: black

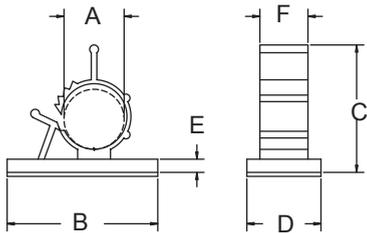

With double adhesive

RCCN TS Adjustable Cable Clamp




Unit:mm

Item No.		Wire harness A	B	C	Packing
Paster type	Hosel type				
TS-0607	PTS-0607	6-7	20	25	100pcs
TS-0708	PTS-0708	7-8	20	25	
TS-0910	PTS-0910	9-10	24.5	30	
TS-1214	PTS-1214	12-14	24.5	30	
TS-1618	PTS-1618	16-18	24.5	30	

Hosel type's panel hole is 4.8mm

Material: UL approved NYLON 66(natural), fireproof 94V-2

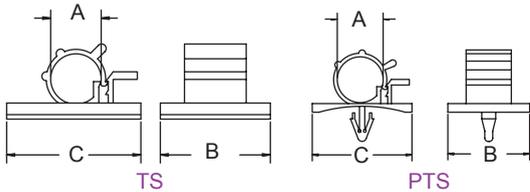

RCCN ATC Adjustable Cable Clamp




3M Adhesive


Unit:mm

Item No.	A mm	B mm	C mm	Max.BundleDia. (mm)	Packing
ATC-17	25.0	18.0	7.9	17.0	100pcs
ATC-22	30.5	21.0	12.0	22.0	
ATC-26	30.5	21.0	12.0	26.0	

Material: UL approved NYLON 66(natural), fireproof 94V-2

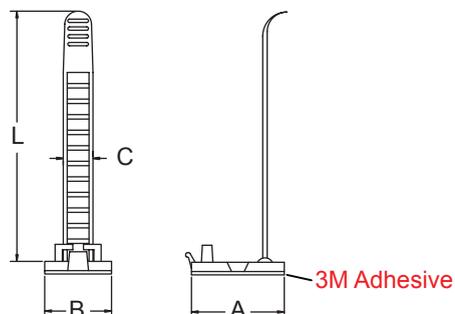


RCCN FC Self-Adhesive Wire Clip

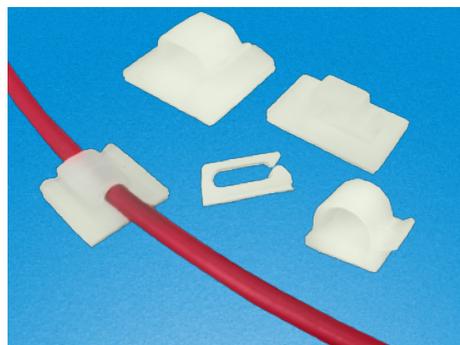


Material: UL approved NYLON 66(natural), fireproof 94V-2

Unit:mm

Item No.	L	L1	W	W1	H	H1	Packing
FC-1	13	8	9.5	6.5	5.2	2.8	100pcs
FC-2	16	4	15.5	9	6.8	4.0	
FC-3	16	12.5	16	7.2	6.8	3.7	
FC-4	27	14.8	17	7.3	8.7	5.5	
FC-0605	19	5.9	19	10	7.2	4.9	
FC-1001	11.9	9.3	6.0	-	3.5	1.0	
FC-1206	16	11.9	15.8	8.9	9	5.8	
FC-1208	26.8	11.9	26.5	12.3	11.7	8.3	
FC-1813	25.6	17.8	25.5	15.8	17.2	13.3	
FC-2211	32.5	22.2	28.3	18.7	15.2	11.1	
FC-0903	12.8	8.9	9.8	6.6	5	2.8	

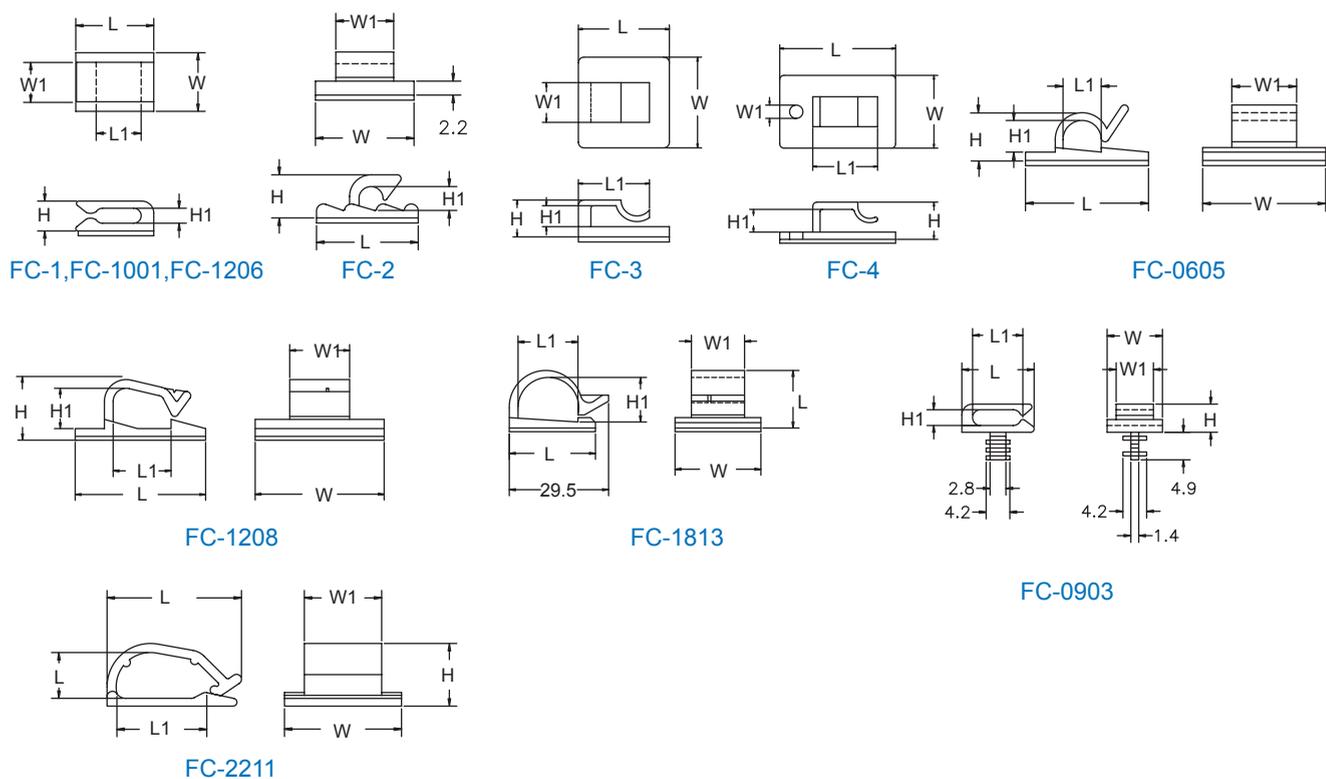


RCCN FC Self-Adhesive Wire Clip

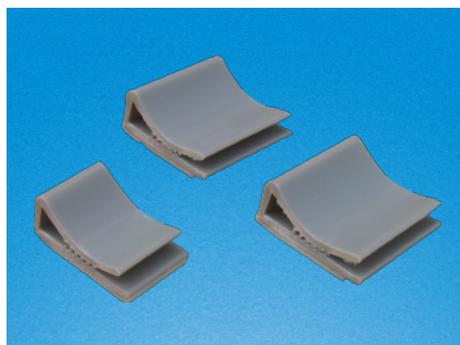


Unit:mm

Item No.	A	B	C	Packing
FC-15	15	24	9	100pcs
FC-20	20	24	9	
FC-25	25	24	9	
FC-28	28	24	9	
SFC-15	15	13	6	
SFC-20	20	13	6	
SFC-25	25	13	6	
SFC-28	28	13	6	

Material:PVC(gray),with adhesive tape.
Use:fixing and wiring

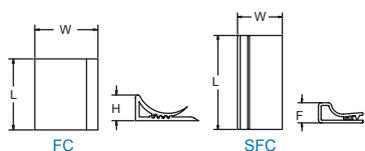


RCCN PC Flat Cable Clamp

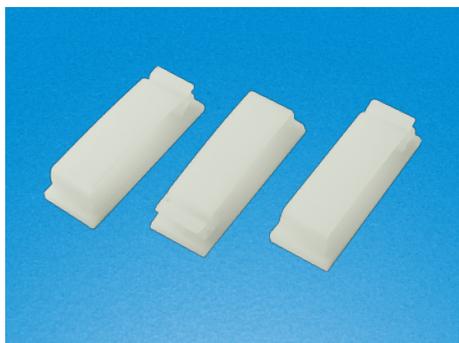



Unit:mm

Item No.	A	B	C	PIN	Packing
粘贴式	mm	mm	mm		
FC-30	32.0	6.2	45.8	-	100pcs
FC-40	39.5	6.2	53.3	-	
FC-50	63.5	6.0	77.5	50PIN	
FCT-30	31.8	11.3	45.1	30PIN	
FCT-40	54	11.3	67	40PIN	
FCT-50	65	11.3	78.4	50PIN	
FC-635	63.5	6.4	76.2	50PIN	
FC-776	77.6	6.4	90.0	60PIN	
FPC-315	31.4	7.6	44.7	30PIN	


Material: UL approved NYLON 66(natural), fireproof 94V-2

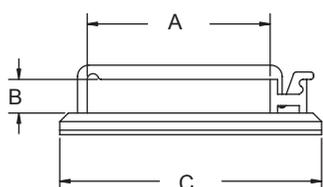



FC-30,40,50

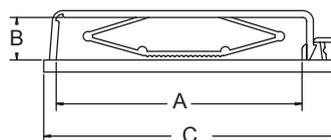 


FCT-30,40,50

 


FC-635.776

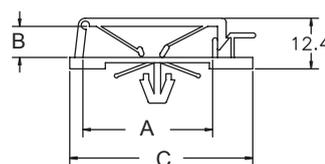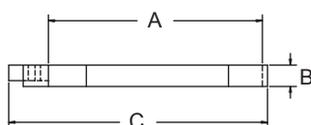

FPC-315

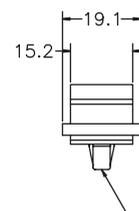



RCCN CL Cable Clamp

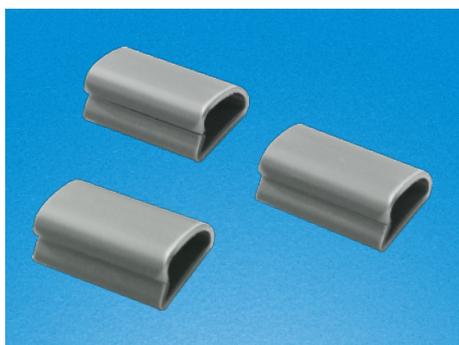



Unit:mm

Item No.	L	W1	W2	Packing
CL-15	15	18.5	16	100pcs
CL-20	20	18.5	16	
CL-25	25	18.5	16	
CL-28	28	18.5	16	

Material:PVC(gray),with adhesive tape.

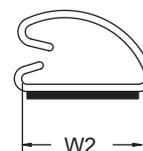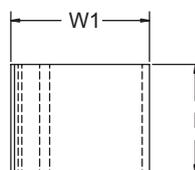

RCCN SR Strain Relief Bushings

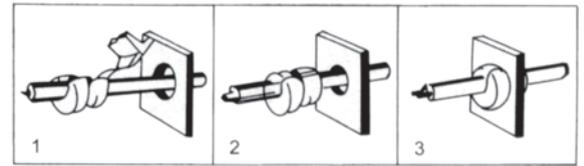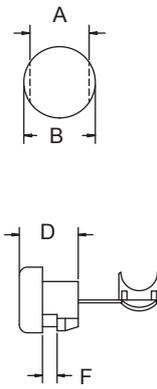

Material: UL approved NYLON 66(black), fireproof 94V-2
 Use: according to the pictures above



Unit:mm




Item No.	Style	UL Wires	Approx.wireSize	MountingHole		Length D	Thickness F	Packing
				A	B			
SR-2P-4		SPT-1#18	3X5.6	9.5	8.7	10.3	0.5-1.6	1000pcs
SR-3P-4	(for flat cable)	SPT-1#18	3.0X5.6	11.0	9.9	10.3	1.0-1.6	
SR-3W-1	FLAT	SPT-1#18	3.0X5.6	11.0	9.9	10.3	1.9-2.5	
SR-4N-4		SPT-2#18	3.0X7.1	12.7	11.8	10.3	0.5-1.6	
SR-4K-4		SPT-2#18	3.0X7.1	12.7	11.8	10.3	1.8-2.5	
SR-5N-4		SVI,SVT3C#18	6.2~7.4	12.7	11.5	11.0	0.5-1.6	
SR-5P-4		SVI,SVT3C#18	6.2~7.4	12.7	11.5	11.0	1.8-2.5	
SR-6N-4		SJC3C#18	7.4~8.2	15.9	14.0	14.8	0.5-1.6	
SR-6P-4	(for round cable)	SJC3C#18	7.4~8.2	15.9	14.0	14.8	1.9-3.2	500pcs
SR-6N3-4	ROUND	SJ,SJT,3C#16	8.2~9.2	15.9	14.0	14.8	0.5-1.6	
SR-6P3-4		SJ,SJT,3C#16	8.2~9.2	15.9	14.0	14.8	1.9-3.2	
SR-7N-2		SJT,3C#14	9.2~10.5	19.8	16.5	19.0	0.5-1.6	
SR-7P-2		SJT,3C#14	9.2~10.5	19.8	16.5	19.0	1.9-3.2	

RCCN KT Strain Relief Bushings Assembly Tool



Part no.:KT-1
 Features:handing
 Use:to install bushings

 RCCN SR Strain Relief Bushings

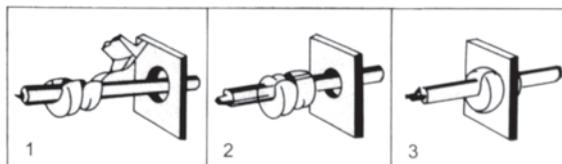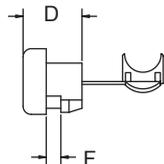


Material: UL approved NYLON 66(black), fireproof 94V-2
 Use: according to the pictures above



Unit:mm


Item No.	Style	UL Wires	Approx.wireSize	MountingHole		Length D	Thickness F	Packing
				A	B			
SR-F21	FLAT 	SPT-1#18	2.3X4.5or2.8X5.3	9.5	8.7	10.3	0.5-1.6	Pcs/bag100
SR-F23		SPT-1#18	2.3X4.5or2.8X5.3	9.5	8.7	10.3	1.8-3.2	
SR-F31		SPT-1#18	3.0X5.6	11.0	9.9	10.3	1.0-1.6	
SR-F32		SPT-1#18	3.0X5.6	11.0	9.9	10.3	1.9-2.5	
SR-F41		SPT-2#18	3.0X7.1or3.8X7.6	12.7	11.8	10.3	0.5-1.6	
SR-F42		SPT-2#18	3.0X7.1or3.8X7.6	12.7	11.8	10.3	1.8-2.5	
SR-F51		SPT-3#18	5X10.4	14.3	12.9	15.2	0.5-1.6	
SR-F53		SPT-3#18	5X10.4	14.3	12.9	15.2	1.8-3.5	
SR-F83		Wire 3C 2mm2	6X15.2	21.6	21.3	20.4	2.0-3.4	
SR-5R1		ROUND 	SVI,SVT3C#18	6.2~7.4	12.8	11.5	11.0	
SR-5R2	SVI,SVT3C#18		6.2~7.4	13.0	11.5	11.0	1.8-2.5	
SR-6W2	SVI3C#18		7.6	12.8	11.8	11.0	1.8-2.3	
SR-6P1	SJC3C#18		7.4~8.2	15.9	14.0	14.8	0.5-1.6	
SR-6P3	SJC3C#18		7.4~8.2	15.9	14.0	14.8	1.9-3.2	
SR-6R1	SJ,SJT,3C#16		8.2~9.2	15.9	14.0	14.8	0.5-1.6	
SR-6R3	SJ,SJT,3C#16		8.2~9.2	15.9	14.0	14.8	1.9-3.2	
SR-7R1	SJT,3C#14		9.2X10.5or11	19.9	17.0	19.0	0.5-1.6	
SR-7R3	SJT,3C#14		9.2X10.5or11	19.7	17.0	19.0	1.9-3.2	
SR-8R3	SJT,3C#12		12~15.2	21.6	21.3	20.6	1.9-3.2	
SR-9R1	#1820-30pcs	11~15	15	19	17.5	0.5-1.6		
SR-9R7	SJT,3C#10	15.2X16.3or17.5	$\frac{28.0}{30.2}$	25.5	25.2	1.0-3.2		

RCCN HP Hole Plug




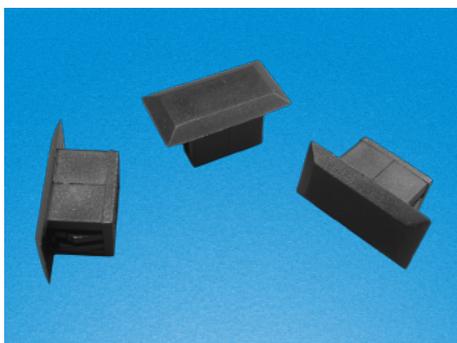


Unit:mm

Item No.	Mounting Hole A	Head cover scope	Suit thickness	Packing
HP-0913	9.5X13	21.5*11.5	0.8-3.2	100pcs

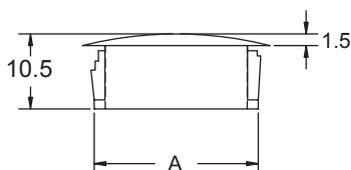

RCCN SB Snap Bushing

 
 
 
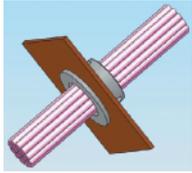


Note: special size is unavailable in stock, come with MOQ. * Unit:mm

Item No.	Mounting Hole A	Max. cable range B	Covering C	Height L	Packing
* SB-7S	7.0	5.8	8.8	6.1	100pcs
SB-8	7.8	5.8	10.5	8.0	
SB-10	9.5	6.4	12.0	10.3	
* SB-12S	11.9	9.2	13.7	6.3	
SB-13	12.7	8.0	15.0	10.3	
* SB-14	14.0	11.4	17.0	10.3	
SB-16	15.9	12.7	18.6	10.3	
SB-19	19.0	14.3	21.7	10.3	
SB-22	22.2	17.5	24.2	11.5	
SB-26	25.5	19.1	28.5	11.5	
SB-28	28.0	23.0	30.7	11.5	
SB-30	30.0	24.1	33.3	11.5	
* SB-32	32.0	23.8	34.6	11.5	
SB-38	38.1	29.0	42.1	11.4	
SB-45	44.5	35.4	47.8	11.6	
SB-50	50.1	41.6	54.6	11.8	

Material: UL approved NYLON 66(black), fireproof 94V-2

RCCN HP Hole Plug

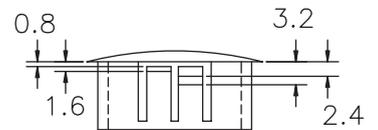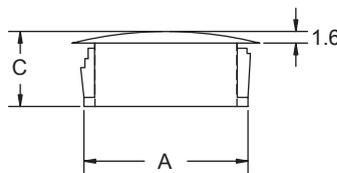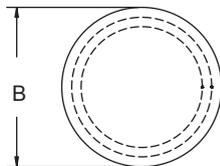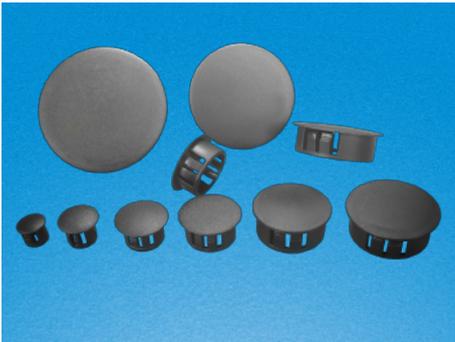


Unit:mm

Item No.	Mounting Hole A	Covering C	Height L	Packing
HP-5	4.5	6.3	5.9	100pcs
HP-8	7.9	10.3	8.1	
HP-10	9.5	13.0	10.5	
HP-13	12.7	16.5	10.9	
HP-15	14.3	16.7	10.3	
HP-16	15.9	19.8	10.0	
HP-19	19.0	22.9	10.0	
HP-22	22.2	25.8	11.3	
HP-25	25.3	29.0	11.6	
HP-30	30.0	34.2	12.0	
HP-38	38.1	42.1	11.2	
HP-45	44.5	49.7	11.8	

Material: UL approved NYLON 66(black), fireproof 94V-2, oil and rot resistant


RCCN OSB Snap Bushing (Open/Closed)

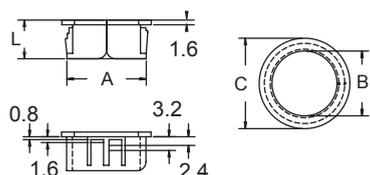

Item No.	Mounting Hole A	Max. cable range B	Covering C	Height L	Unit:mm	
					Packing	
OSB-10	9.0	6.0	11.8	9.8	100PCS	
OSB-13	12.5	7.5	15.1	10.3		
OSB-16	15.5	11.2	18.5	10.3		
OSB-19	18.4	12.5	21.0	10.3		
OSB-22	22.0	17.0	24.6	10.3		
OSB-26	25.5	20.0	28.0	10.6		

Material: UL approved NYLON66(black), fireproof 94V-2

RCCN RSB Snapbu Shing

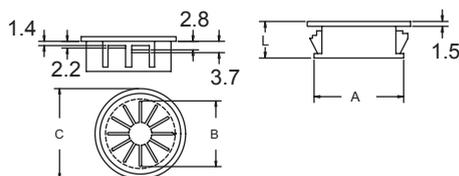

Item No.	Mounting Hole A	Max. cable range B	Covering C	Height L	Unit:mm	
					Packing	
RSB-16	15.9	11.1	18.3	10.3	100PCS	
RSB-19	18.8	12.7	21.8	9.9		
RSB-21	20.6	12.7	22.6	9.9		
RSB-22	22.2	14.3	23.8	11.5		
RSB-25	25.3	20.4	28.5	11.3		
RSB-28	27.6	22.4	30.8	11.3		
RSB-35	34.2	29.3	37.5	11.3		
RSB-38	38.0	31.0	31.0	11.0		


Material: UL approved NYLON66(black), fireproof 94V-2

RCCN GM/GMC Grommet(Open/Closed)

GM TYPE




GMC TYPE


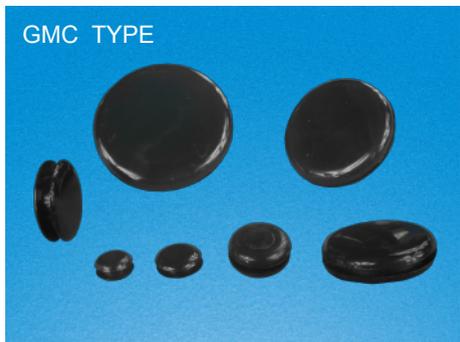


ItemNo.		A	B	C	D	E	Unit:mm	
OPEN	CLOSED						Packing	
GM-0603	GMC-0603	8.5	6.0	3.0	4.7	1.7	100PCS	
GM-0705	GMC-0705	10.2	7.2	5.0	4.4	1.7		
GM-1006	GMC-1006	13.3	10.0	6.4	6.3	1.7		
GM-1108	GMC-1108	15.5	11.0	10.8	9.0	3.0		
GM-1410	GMC-1410	19.5	13.9	10.5	6.4	3.4		
GM-2015	GMC-2015	23.7	20.1	15.5	6.1	1.7		
GM-2518	GMC-2518	29.9	25.1	18.9	7.2	1.5		
GM-3225	GMC-3225	38.1	31.7	25.0	7.8	1.5		

Material: Rohs approved silicon rubber(soft),black,transparent can be produced,part no. is:GM-1006W

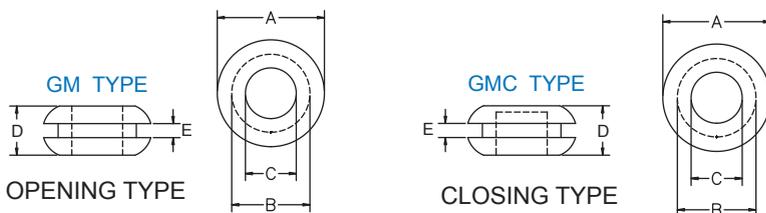

RCCN KG Movable Bushings

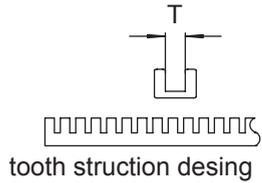
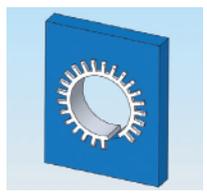


Unit:mm

ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
KG-008	KG-008B	0.8	0.7-0.8	Pcs/bag10M
KG-010	KG-010B	1.0	0.8-1.0	
KG-012	KG-012B	1.2	1.0-1.2	
KG-016	KG-016B	1.6	1.0-1.6	
KG-020	KG-020B	2.0	1.6-2.0	
KG-024	KG-024B	2.4	2.0-2.4	
KG-032	KG-032B	3.2	2.4-3.2	
KG-045	KG-045B	4.5	3.2-4.5	
* KG-060	KG-060B	6.0	5.6-6.0	
* KG-080	KG-080B	8.0	7.7-8.0	

Material:soft PE,tooth struction
Note: *means come with MOQ

RCCN KGS Movable Bushings


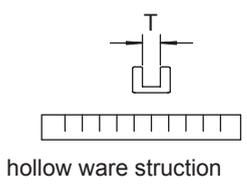
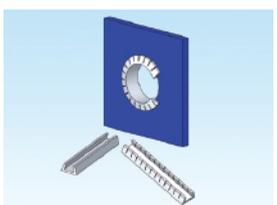


Unit:mm

ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
KGS-008	KGS-008B	0.8	0.7-0.8	Pcs/bag10M
KGS-010	KGS-010B	1.0	0.8-1.0	
KGS-012	KGS-012B	1.2	1.0-1.2	
KGS-016	KGS-016B	1.6	1.0-1.6	
KGS-020	KGS-020B	2.0	1.6-2.0	
KGS-024	KGS-024B	2.4	2.0-2.4	
KGS-032	KGS-032B	3.2	2.4-3.2	
KGS-045	KGS-045B	4.5	3.2-4.5	
* KGS-060	KGS-060B	6.0	5.6-6.0	
* KGS-080	KGS-080B	8.0	7.7-8.0	

Material:soft PE,slice struction
Note: * means come with MOQ

 RCCN ED Movable Bushings

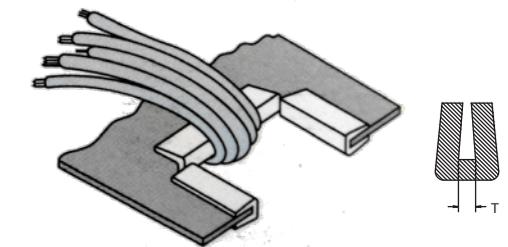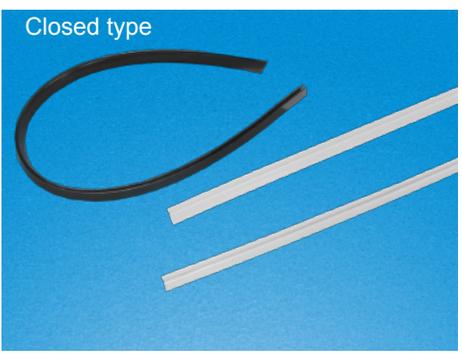


Unit:mm

ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
ED-008	ED-008B	0.8	0.7-0.8	Pcs/bag10M
ED-010	ED-010B	1.0	0.8-1.0	
ED-012	ED-012B	1.2	1.0-1.2	
ED-016	ED-016B	1.6	1.0-1.6	
ED-020	ED-020B	2.0	1.6-2.0	
ED-024	ED-024B	2.4	2.0-2.4	
ED-024L	ED-024LB	2.4	2.0-2.4	
ED-032	ED-032B	3.2	2.4-3.2	
* ED-045	ED-045B	4.5	3.2-4.5	
* ED-060	ED-060B	6.0	5.6-6.0	
ED-080	ED-080B	8.0	7.7-8.0	

Material:soft PE,U struction design


RCCN KGV0 Movable Bushings

Unit:mm

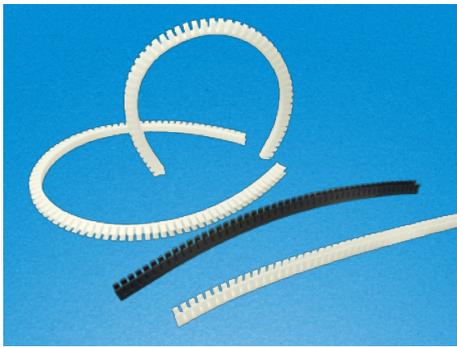

ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
KG-008V0	KG-008V0B	0.8	0.7-0.8	Pcs/bag10M
KG-010V0	KG-010V0B	1.0	0.8-1.0	
KG-012V0	KG-012V0B	1.2	1.0-1.2	
KG-016V0	KG-016V0B	1.6	1.0-1.6	
KG-020V0	KG-020V0B	2.0	1.6-2.0	
KG-024V0	KG-024V0B	2.4	2.0-2.4	
KG-032V0	KG-032V0B	3.2	2.4-3.2	
KG-045V0	KG-045V0B	4.5	3.2-4.5	

 Material:soft PE,tooth struction



KGS Opening type



Tooth type:interval slot in both side

KG

Fireproof type

RCCN KGSV0 Movable Bushings

Unit:mm



ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
KG-008V0	KG-008V0B	0.8	0.7-0.8	Pcs/bag10M
KG-010V0	KG-010V0B	1.0	0.8-1.0	
KG-012V0	KG-012V0B	1.2	1.0-1.2	
KG-016V0	KG-016V0B	1.6	1.0-1.6	
KG-020V0	KG-020V0B	2.0	1.6-2.0	
KG-024V0	KG-024V0B	2.4	2.0-2.4	
KG-032V0	KG-032V0B	3.2	2.4-3.2	
KG-045V0	KG-045V0B	4.5	3.2-4.5	

Material:soft PE,slice struction



KGS Cutting in bar



Cutter type:concave cut in bar

KGS

Fireproof type

RCCN EDV0 Movable Bushings



Unit:mm



ED Closed type



ItemNo.		Slot dia. T	Suitable board Thickness	Packing
Transparency	Black			
ED-008V0	ED-008V0B	0.8	0.7-0.8	Pcs/bag10M
ED-010V0	ED-010V0B	1.0	0.8-1.0	
ED-012V0	ED-012V0B	1.2	1.0-1.2	
ED-016V0	ED-016V0B	1.6	1.0-1.6	
ED-020V0	ED-020V0B	2.0	1.6-2.0	
ED-024V0	ED-024V0B	2.4	2.0-2.4	
ED-032V0	ED-032V0B	3.2	2.4-3.2	
ED-045V0	ED-045V0B	4.5	3.2-4.5	
* ED-060V0	ED-060V0B	6.0	5.6-6.0	
* ED-080V0	ED-080V0B	8.0	7.7-8.0	

Material:soft PE,U struction design

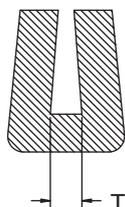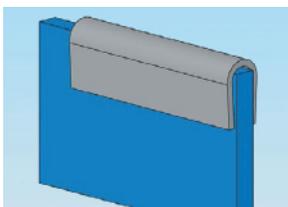

Fireproof type

RCCN KGN Nylon Movable Bushings

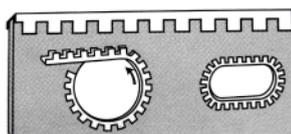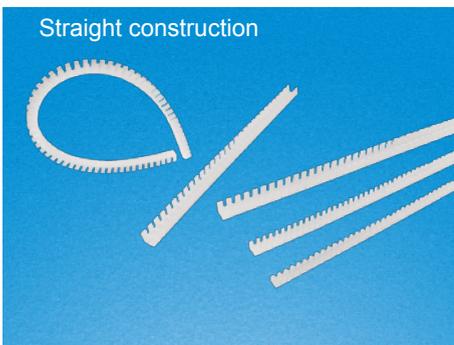

Unit:mm



ItemNo.	T	Thickness	Packing
KG-010N	1.0	1.0以下	100支 每支长25CM
KG-012N	1.2	1.2-1.3	
KG-016N	1.6	1.2-1.6	
KG-020N	2.0	1.6-2.0	
KG-024N	2.4	2.0-2.4	
KG-032N	3.2	2.4-3.2	
KG-045N	4.5	3.2-4.5	

Material: UL approved NYLON66(black), fireproof 94V-2, oil and rot resistant



Tooth type:interval slot in both side

 RCCN KGNT Nylon Movable Bushings


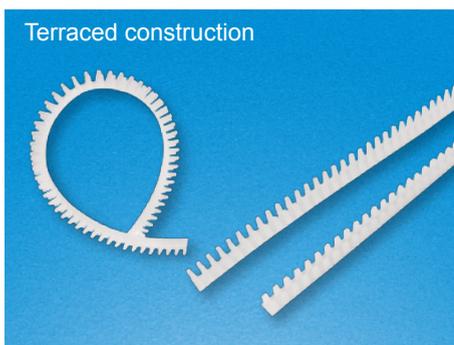


Unit:mm

ItemNo.	T	Thickness	Packing
KG-010NT	1.0	1.0-1.1	100 pcs 25cm per pcs
KG-012NT	1.2	1.2-1.3	
KG-016NT	1.6	1.5-1.7	
KG-024NT	2.4	2.3-2.5	

Material: UL approved NYLON66(black), fireproof 94V-2, oil and rot resistant

 RCCN KGNT2 Nylon Movable Bushings

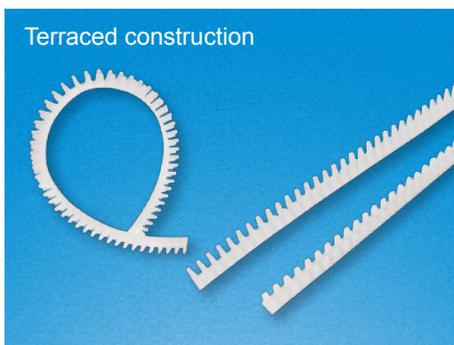

Unit:mm


ItemNo.	T	Thickness	Packing
KG-006NT2	0.6	0.5-0.7	100 pcs 25cm per pcs
KG-008NT2	0.8	0.7-0.9	
KG-010NT2	1.0	0.9-1.1	
KG-012NT2	1.2	1.1-1.3	
KG-014NT2	1.4	1.3-1.5	
KG-016NT2	1.6	1.4-1.7	
KG-020NT2	2.0	1.8-2.0	
KG-030NT2	3.0	2.5-3.0	

Material: UL approved NYLON66(black), fireproof 94V-2, oil and rot resistant

RCCN Right Angle Strain Relief Bushing





Material: UL approved NYLON66(black),
fireproof 94V-2
Installed it according to following pictures

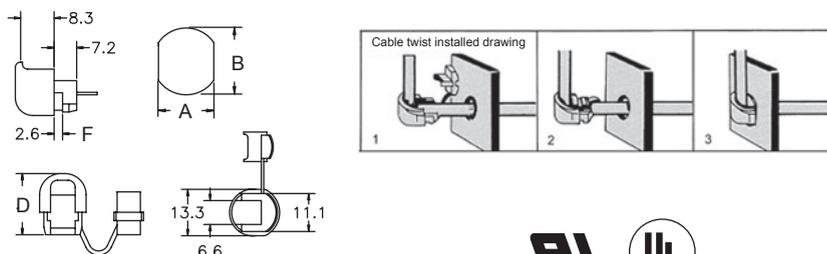

Unit:mm

temNo.	Style	ULWires	Approx. wireSize	Mounting Hole		PartL. D	Thickness F	Packing
				A	B			
SR-F42L	(Use for flat cable)	SPT-1orSPT-2	3.0X6.6or3.8X7.1	12.7	11.8	17.7	1.8-2.6	100pcs

RCCN Flexible Strain Relief Bushing

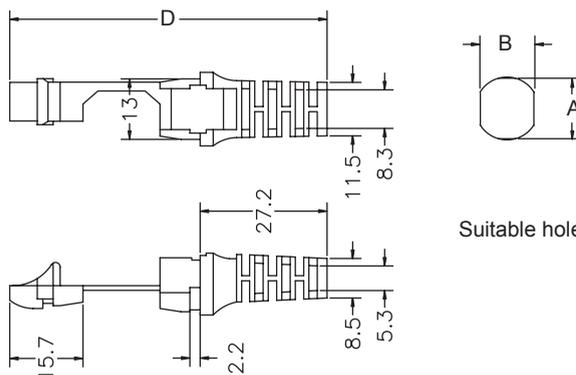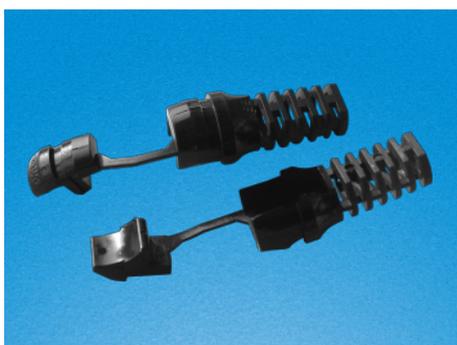


Unit:mm

Material: UL approved NYLON66(black), fireproof 94V-2

temNo.	Style	ULWires	Approx. wireSize	Mounting Hole		PartL. D	Thickness F	Packing
				A	B			
SR-F52F	(Use for flat cable)	SPT-2#18	4.6X8	14.3	13.2	36	0.8-2.3	100pcs

RCCN Flexible Strain Relief Bushing

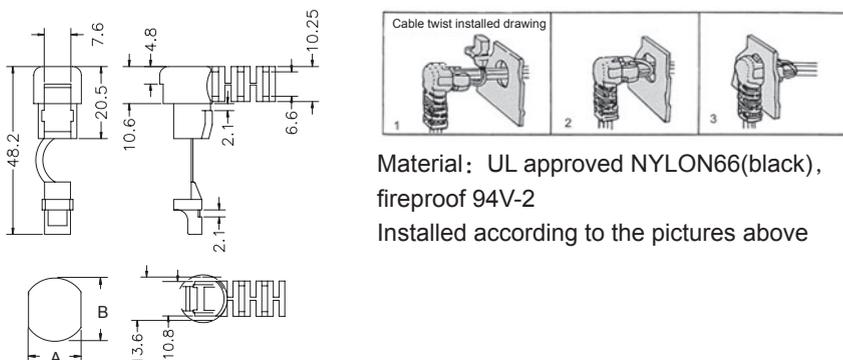

Material: UL approved NYLON66(black),
fireproof 94V-2
Installed according to the pictures above

Unit:mm


temNo.	Style	ULWires	Approx. wireSize	Mounting Hole		PartL. D	Thickness F	Packing
				A	B			
SR-F42LF	(Use for flat cable)	SPT-2#18	3.3X6.6or3.6X7.2	12.7-13.2 13.2-13.7	10.9	20.5	1.5-2.0	100pcs

RCCN TT Twist Tie




Unit:mm

Item No.	Size			Bundls Dimension	Packing
	A	B	C		
TT-05	5.1	20.6	1.8	4-7	100pcs (1000pcs)
TT-08	8.0	25.4	1.8	7-10	
TT-11	11.3	29.3	1.8	10-13	
TT-15	15.0	34.0	2	13-16.5	
TT-18	18.6	40.0	2	16.5-20	
TT-24	24.0	45.5	2	20-27	

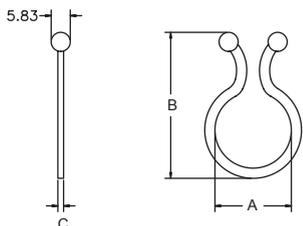


Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

RCCN TTB Mounting Twist Tie

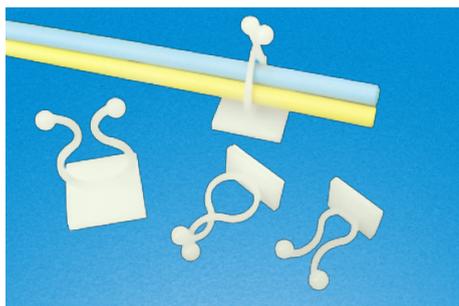

Unit:mm

Item No.	Size			Bundls Dimension	Packing
	A	B	C		
TTB-08	7.9	27.5	17.4	7-10	100pcs (1000pcs)
TTB-15	14.8	35.2	22	10-15	
TTB-20	20.6	40	25.5	15-20	

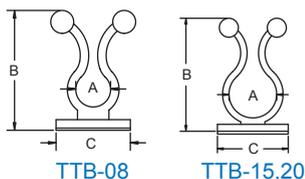

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant


RCCN AWS Adhesive Wire Saddle





Unit:mm

tem No.	A	B	C	D	Packing
AWS-11	11.2	11	20	19.8	100pcs (1000pcs)
AWS-9R	8.5	13.6	29.8	16	
AWS-1210	11.3	10	20.7	18.3	
AWS-0912	9	11.6	15.8	9.5	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

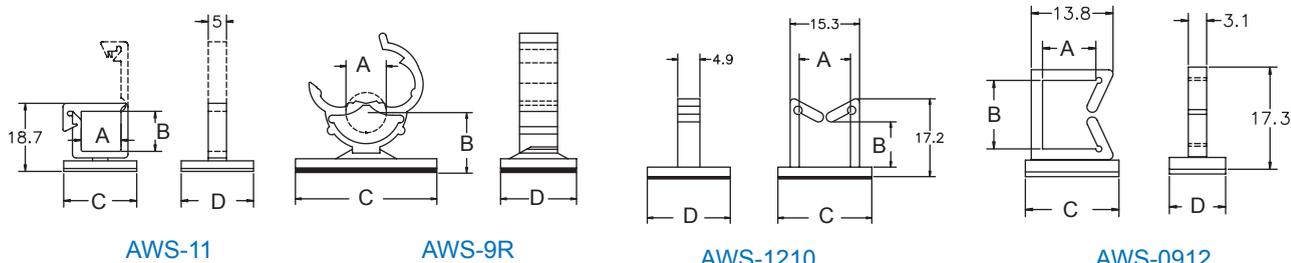


RCCN RH Wir Saddle

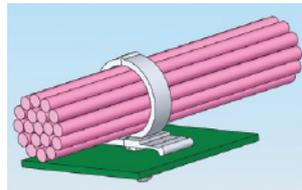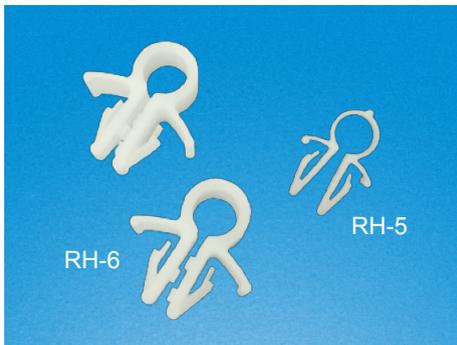

Unit:mm

Item No.	Dimension				Packing
	A	B	Panel hole	Suitable panel thickness	
RH-5	5.1	8.0	5.5	2.0	100pcs (1000pcs)
RH-6	6.2	9.5	8	1.8	
RH-8	7.5	11.5	6.2	2.0	
RH-9	9.6	18.0	9.5	2.0	

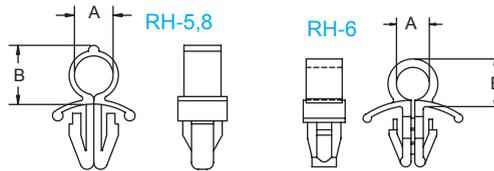

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation

Unit:mm

Item No.	Dimension				Packing
	A	H	Panel hole	Suitable panel thickness	
RH-51	8.8	19	6.0	3.0-3.3	100pcs (1000pcs)
RH-496	6.3	21.6	6.5	1.2-4.4	
RH-497	9.5	24	6.2	1.3-5.0	
RH-498	12.7	27.0	5.5	1.2-4.2	
RH-487	5.0	15.2	5.0	2.5	
RH-667	6.0	17.5	7.0	4.0	


Unit:mm

Item No.	Dimension				Packing
	A	H	Panel hole	Suitable panel thickness	
RH-52	14.0	36.0	7.0	5.0	100pcs (1000pcs)
RH-53	20.0	44.0	6.5	4.5	
RH-54	12.0	35.0	7.5	4.5	
RH-59	10.0	34.0	7.0	5.0	
RH-648	7.5	40.0	7.0	4-10	

This series can be produced into opening design,it need to open and check the cables after installing

Unit:mm

Item No.	Dimension				Packing
	A	H	Panel hole	Suitable panel thickness	
RH-50	14.0	24.0	7.0	3.0	100pcs
RH-502	7.0	22.5	5.0	2.0	
RH-488	8.0	29.0	6.5	2.5	
RH-549	7.0	19.0	7	2.0	

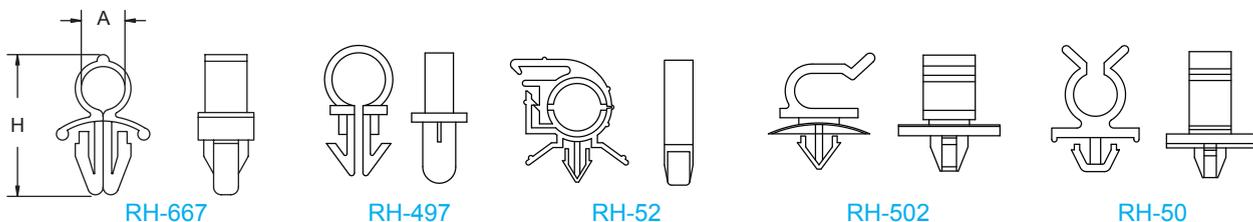

RCCN KWS Locking Wires Addle




Unit:mm


Item No.	Dimension						Packing
	H	A	B	W	Panel hole	Thickness	
KWS-0	9.0	13.0	4.0	11.0	4.8	2.0	100pcs (1000pcs)
KWS-1	14.2	19.0	10.5	11.0	4.8	2.0	
KWS-2	23.0	27.0	19.0	11.0	4.8	2.0	
KWS-2L	15.0	18.0	12.0	10.4	4.8	4.0	
KWS-3	31.1	35.8	28.0	11.0	4.8	2.0	
KWS-1522	Like pictures				4.5	2.0	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant


this is old design, for new design, please check LWS series/page B94

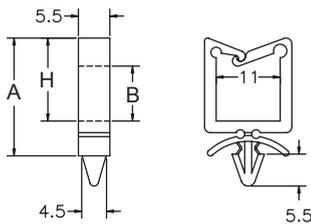

KWS-0,1,2,3

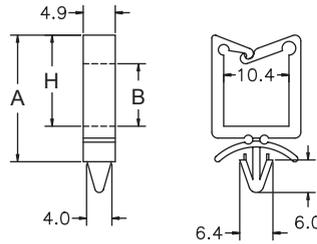


KWS-2L

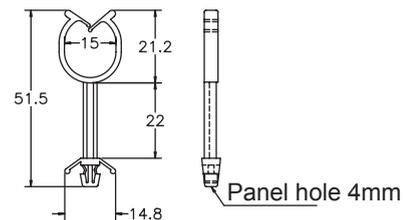

KWS-1522


RCCN KWSN Locking wires addle

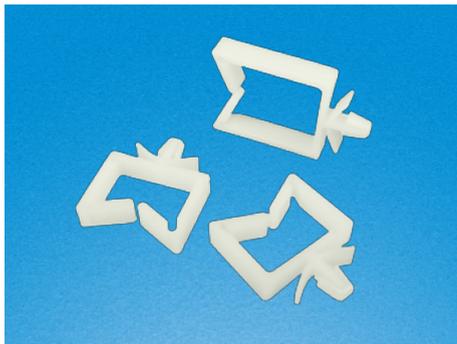

Unit:mm

Item No.	Dimension						Packing
	H	A	B	W	Panel hole	Thickness	
KWS-0N	9.2	12.7	4.0	11.0	4.8	2.0	100pcs (1000pcs)
KWS-1N	11.4	17.9	8.6	11.0	4.8	2.0	
KWS-2N	23.4	26.9	18.2	11.0	4.8	2.0	
KWS-3N	31.3	34.8	26.2	11.0	4.8	2.0	
KWS-1114	17.8	21.2	13.7	10.7	4.8	2.4	


This is old design, for new design, Please check NWS series/page B94

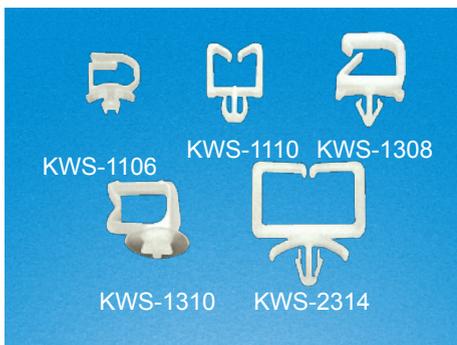


Unit:mm

Item No.	Dimension					Packing
	H	A	B	Panel hole	Thickness	
KWS-0506	5.4	5.0	9.0	4.8	3.0	100pcs (1000pcs)
KWS-1106	5.4	10.5	13.0	4.8	1.6	
KWS-1110	9.8	10.9	14.4	如图	2.2	
KWS-1308	8.5	12.7	17.2	5.8	1.6	
KWS-1310	9.9	13.0	18.8	如图	如图	
KWS-2314	13.6	22.9	28.3	4.8	3.4	


Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

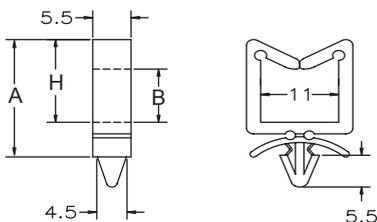


KWS-0,1,2,3N

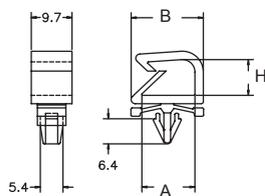

KWS-1308

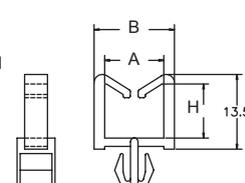


KWS-1110

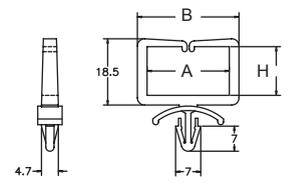


KWS-2314

RCCN ST Standoff Twist Tie





Unit:mm

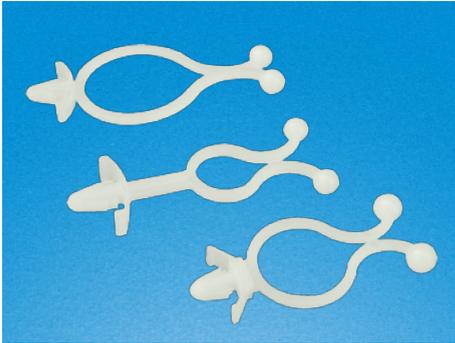

Item No.	Dimension					Packing
	H1	H2	W	Panel hole	Suitable panel thickness	
ST-1	19.5	31.7	6.0	4.6-4.8	1.0-2.8	100pcs (1000pcs)
ST-2	27.8	21.2	11.0	4.8-5.0	1.0-2.8	
ST-3	27.3	4.7	10.4	4.6-4.8	1.0-2.8	
ST-3B	28.0	5.0	11.0	6.2-6.6	0.5-2.0	
ST-3C	32.0	5.0	15.0	4.6-4.8	0.5-1.6	
ST-3D	36.2	5.3	18.0	4.4-4.8	1.0-2.4	
ST-4S	27.9	13.0	11.0	4.2-4.8	1.0-2.4	
ST-4	31.3	11.1	15.0	4.6-4.8	1.0-2.0	
ST-0560	20.5	60.9	5.0	4.6-5.0	1.6-3.0	
ST-0605	19.3	5.3	6.1	4.0-4.4	2.4	
ST-0701	22.0	1.3	7.0	4.6-4.8	1.0-2.8	
ST-1112	26.8	15.3	11	4.6-4.8	1.6-3.0	
ST-1247	27.2	50.5	11	4.6-4.8	1.6-3.0	
ST-1303	45.0	3.0	13.5	6.6	1.8-3.6	
ST-1602	31.7	5.1	16.0	4.4-4.6	0.5-1.6	
ST-2005	36.5	5.1	20	7.2-7.6	1.8-3.6	
ST-2403	44.2	3.2	23.5	4.8-5.0	0.5-2.6	

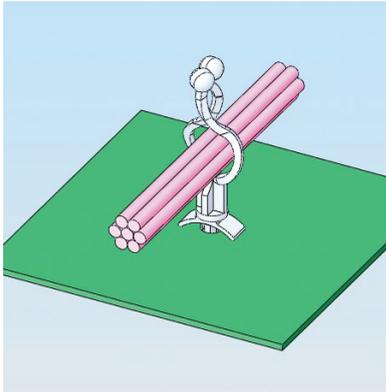

Item No.	Dimension					Packing
	D	H2	W	Panel hole	Suitable panel thickness	
ST-0703A	10.6	3.1	7.1	4.8-5.0	1.0-3.2	100pcs (1000pcs)
ST-0720A	10.6	20.0	7.1	4.8-5.0	1.0-3.2	
ST-0735A	10.6	35.3	7.1	4.8-5.0	1.0-3.2	
ST-1003A	10.6	2.8	10.8	4.8-5.0	1.0-3.2	
ST-1020A	10.6	20.0	10.8	4.8-5.0	1.0-3.2	
ST-1035A	10.6	35.2	10.8	4.8-5.0	1.0-3.2	
ST-1503A	10.6	3.0	15	4.8-5.0	1.0-3.2	
ST-1520A	10.6	20.4	15	4.8-5.0	1.0-3.2	
ST-1535A	10.6	35.8	15	4.8-5.0	1.0-3.2	
ST-2016A	10.6	16.0	20	4.8-5.0	1.0-3.2	
ST-2503A	10.0	3.0	24.3	4.8-5.0	1.0-3.2	
ST-1115A	10.6	15.3	11.0	4.8-5.0	1.0-3.2	
ST-2005A	10.6	5.0	20.3	4.8-5.0	1.0-3.2	
ST-0810A	10.6	10.5	8	4.8-5.0	1.0-3.2	
ST-0906A	10.6	5.6	8.8	4.8-5.0	1.0-3.2	
ST-1021C	7.5	21.0	10.4	4.6-4.8	0.8-2.2	
ST-0534C	7.5	34.0	5.0	4.6-4.8	0.8-2.2	
ST-1005C	7.5	4.5	10.4	4.6-4.8	0.8-2.2	
ST-0703C	5.5	3.0	7.2	4.6-4.8	0.8-2.2	
ST-1043C	8.0	43.5	10.1	4.6-4.8	0.8-2.2	

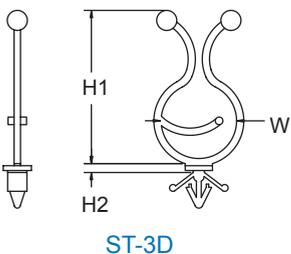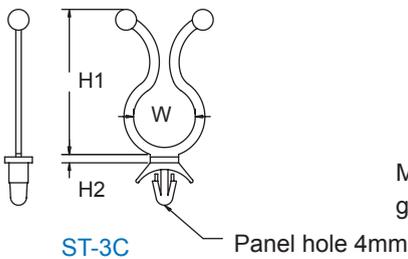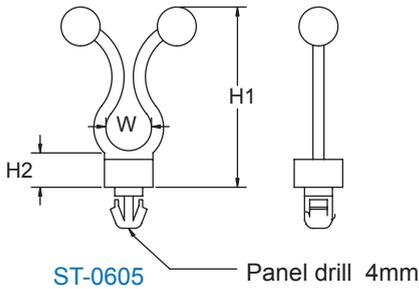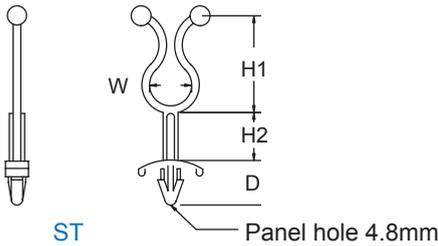

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

RCCN RS Reverse Locking Circuit Board Support


Unit:mm



this is old design, for new design, please check LCBSC series/page B91

Item No.	Distance A	Up hole size	Up panel thickness	below hole size	Helow hole thickness	Packing
RS-3	3.5	3.5	1.8	5.5	1.4	1000pcs
RS-5	5.0	5.0	1.8	5.5	1.8	
RS-6	6.4	6.0	1.8	5.5	1.8	
RS-8	8.0	8.0	1.8	5.5	1.8	
RS-8S	8.0	6.1	1.6	5.5	1.8	
RS-10	9.6	9.8	1.8	5.5	1.8	
RS-10L	10.8	9.8	1.6	5.5	1.8	
RS-12	12.0	12.0	1.8	5.5	1.8	
RS-14	14.0	14.0	1.8	5.5	1.8	
RS-18	18.0	18.0	1.8	5.5	1.8	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

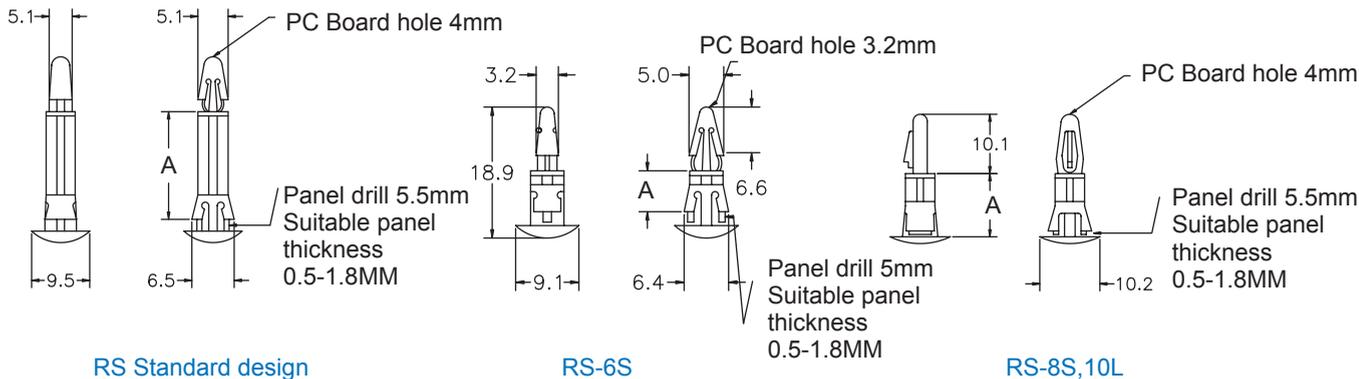

RS Standard design

RS-6S

RS-8S,10L

RCCN CS Circuit Board Support


Unit:mm



Thickness:1.8,Hole 4.0


Item No.	Distance A	Packing
CS-0305	4.8(3/16")	1000pcs
CS-0406	6.4(1/4")	
CS-0610	9.6(3/8")	
CS-0813	12.7(1/2")	
CS-1016	15.9(5/8")	
CS-1219	19.1(3/4")	
CS-1422	22.2(7/8")	
CS-1625	25.4(1")	
CS-1828	28.5(1 1/8")	
CS-2236	35.0(1 3/8")	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

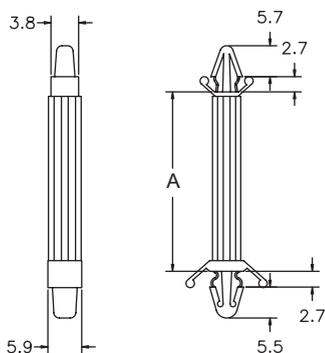

Thickness:2.5,Hole 4.8

RCCN PS Push Circuit Board Supports

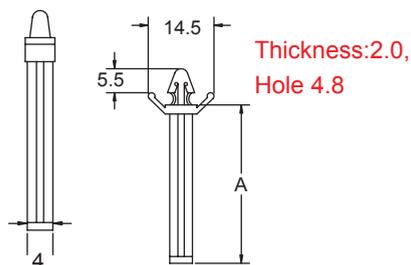



Unit:mm

Item No.	Distance		Packing
	A		
PS-5	4 8(3/16")		1000pcs
PS-6	6.4(1/4")		
PS-10	9.6(3/8")		
PS-13	12.7(1/2")		
PS-16	15.9(5/8")		
PS-19	19.1(3/4")		
PS-22	22.2(7/8")		
PS-25	25.4(1")		
PS-28	28.5(1 1/8")		
PS-36	35.0(1 3/8")		

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

This is our old design, new design part no. is MPS series/pageB82

RCCN CS Screw Push Spacer

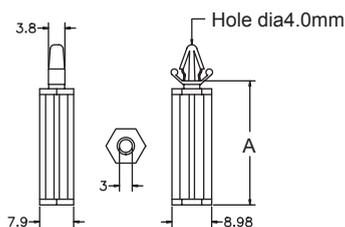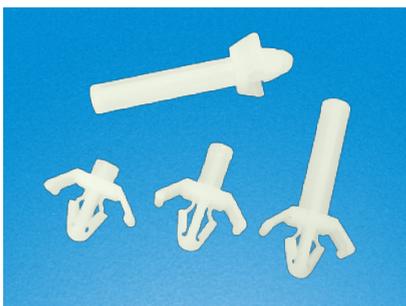

Unit:mm



Item No.	Distance		Packing
	A		
CS-5	5.0(3/16")		1000pcs
CS-10	9.6(3/8")		
CS-13	12.7(1/2")		
CS-19	19.1(3/4")		
CS-28	28.5(1 1/8")		
CS-35	35.0(1 3/8")		

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

This is our old design, new design part no. is HCBS series/pageB82

M2 screw or #6 screw Thickness:2.0,Hole 4.0

RCCN SP Miniature Support Post

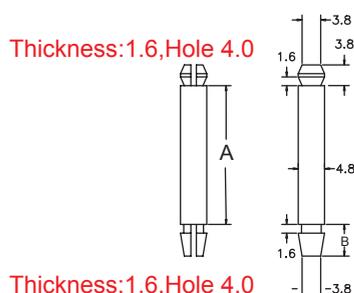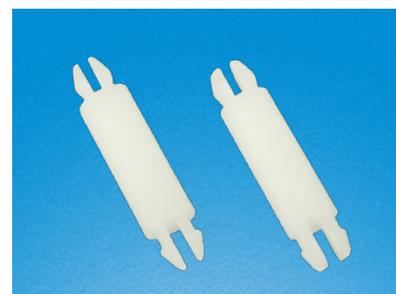

Unit:mm



Item No.	Distance		Packing
	A	B	
SP-3	3.2	3.8	1000pcs
SP-6	6.3	3.8	
SP-8	8.0	3.8	
SP-10	10.5	3.8	
SP-13	12.7	5.6	
SP-16	15.9	5.6	
SP-17	16.5	5.6	
SP-19	19.1	5.6	
SP-22	22.2	5.6	
SP-25	25.4	5.6	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

This is our old design, new design part no. is CBP series/pageB81

RCCN HTS Hexagonal Tapped Spacer

Unit:mm

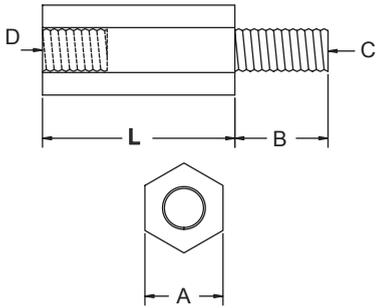
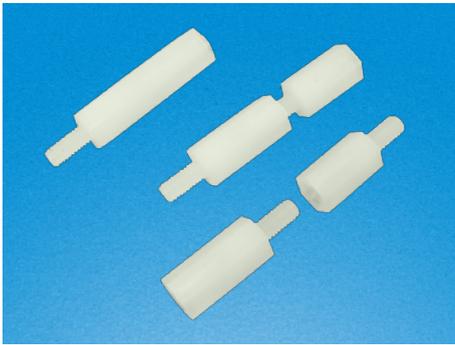


Item No.	A	B	C/D	L	Packing
HTS-306	5.6	6		6	1000pcs
HTS-308	5.6	6		8	
HTS-310	5.6	6		10	
HTS-312	5.6	6		12.7	
HTS-315	5.6	6		15	
HTS-318	5.6	6		18	
HTS-320	5.6	6		20	
HTS-322	5.6	6		22	
HTS-325	5.6	6		25	
HTS-330	5.6	6		30	
HTS-410	7	6		10.1	
HTS-413	7	6		13.0	
HTS-415	7	6		15.0	
HTS-419	7	6		19.0	
HTS-425	7	6		25.0	
HTS-430	7	6		30.0	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

RCCN HTP Hexagonal Tapped Spacer

Unit:mm

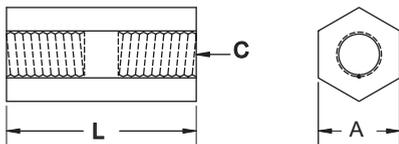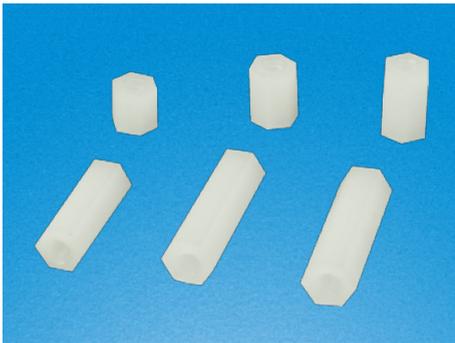


Item No.	L	A	C	Packing
HTP-306	6.0	5.5	3	1000pcs
HTP-308	8.0	5.5	3	
HTP-310	10.0	5.5	3	
HTP-312	12.7	5.5	3	
HTP-315	15.0	5.5	3	
HTP-318	18.0	5.5	3	
HTP-320	20.0	5.5	3	
HTP-322	22.0	5.5	3	
HTP-325	25.0	5.5	3	
HTP-330	30.0	5.5	3	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

RCCN BMS Slide Secure Circuit Board Support

Unit:mm

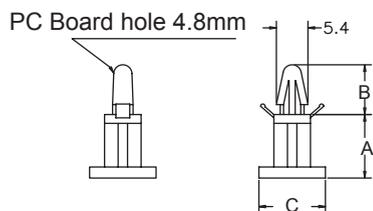

Thickness:2.0 Hole:4.0

Item No.	A	B	C	Packing
BMS-5	5.6	9.5	11.8	1000pcs
BMS-5L	5.6	9.5	11.8	
BMS-5L7	5.6	9.5	7.1	
BMS-8	8.0	9.5	11.8	
BMS-11	11.0	9.0	12.0	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant



RCCN BT PC Circuit Board Track





Unit:mm

Item No.	A	B	C	D	E	F	G	Packing
BT-90A	89	77	1.9	4.5	9.5	1.5	3	100pcs
BT-90	89	64.5	1.9	4.5	9.5	1.5	3	
BT-120	119	94.5	1.9	4.5	9.5	1.5	3	
BT-140	140	115.0	1.9	4.5	9.5	1.5	3	
BT-155A	154	140	1.9	4.6	6.5	1.3	3.3	
BT-160	160	134.5	1.9	4.5	9.5	1.5	3	
BT-160A	163	149.5	1.9	6.5	9.5	2.2	2.3	

 

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

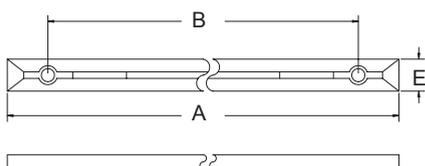

BT-90,120,140,160

 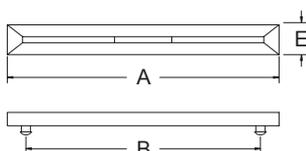

BT-90A,155A

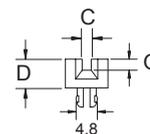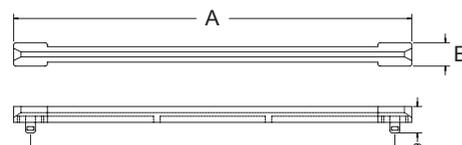

BT-160A



RCCN RCG PC Rack Card Guide



Unit:mm

Item No.	A	B	Packing
RCG-64A	63.5	50.8	500pcs
RCG-76A	76	63.5	
RCG-89A	89	77	
RCG-101A	101.6	88.9	250pcs
RCG-114A	114.3	101.6	200pcs
RCG-127A	127.0	114.3	
RCG-140A	139.7	127	
RCG-152A	152.4	139.7	

Material: UL approved NYLON66(natural), fireproof 94V-2, good insulation, good aging resistant

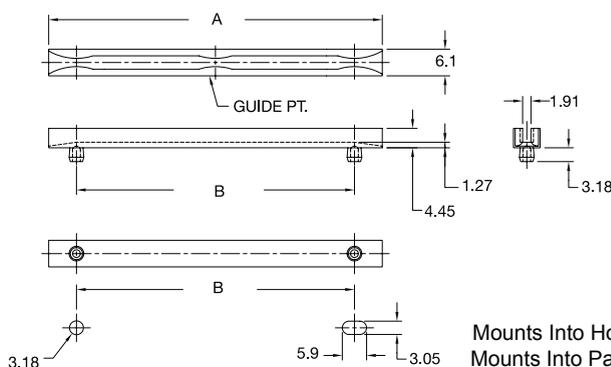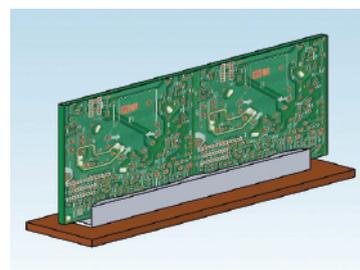

Mounts Into Holes Above
Mounts Into Panel: 1.6